


SANKO M35 スプロケット

(単位：mm)

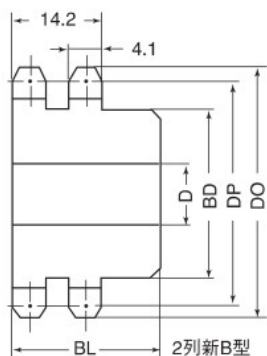

2列新B型

40Tまで機械構造用炭素鋼
ヤキ入鍛造品
42T～SS400 溶接品

歯 数	外 径 O.D.	ピッチ径 P.C.D.	歯底円 直 径	2列新B型				概略重量 (kg)
				軸孔径B		ボ ス		
				下孔	最大	径B.D	長さB.L	
10	34	30.82	25.74	9	13	20	30	0.10
11	38	33.81	28.73	10	13	20	30	0.11
12	40	36.80	31.72	10	17	27	30	0.14
13	44	39.80	34.72	10	20	27	30	0.17
14	47	42.80	37.72	10	20	32	30	0.21
15	50	45.81	40.73	10	25	35	30	0.25
16	53	48.82	43.74	10	25	38	30	0.29
17	56	51.84	46.76	10	25	41	30	0.34
18	59	54.85	49.77	10	28	44	35	0.45
19	62	57.87	52.79	10	30	47	35	0.51
20	65	60.89	55.81	12	32	50	40	0.64
21	68	63.91	58.83	12	32	50	40	0.64
22	71	66.93	61.85	12	35	55	40	0.67
23	75	69.95	64.87	12	35	60	40	0.78
24	78	72.97	67.89	15	38	60	40	0.82
25	81	76.00	70.92	15	38	60	40	0.92
26	84	79.02	73.94	15	42	65	45	0.96
27	87	82.05	76.97	15	42	65	45	1.22
28	90	85.07	79.99	15	42	65	45	1.26
29	93	88.10	83.02	15	42	65	45	1.30
30	96	91.12	86.04	15	42	65	45	1.34
31	99	94.15	89.07	15	42	65	45	1.39
32	102	97.18	92.10	15	42	65	45	1.43
33	105	100.20	95.12	15	42	65	45	1.48
34	108	103.23	98.15	15	42	65	45	1.53
35	111	106.26	101.18	15	42	65	45	1.58
36	114	109.29	104.21	15	42	65	45	1.80
37	117	112.32	107.24	15	42	65	45	1.90
38	120	115.34	110.26	15	42	65	45	2.00
39	123	118.37	113.29	15	42	65	45	2.15
40	126	121.40	116.32	15	42	65	45	2.30
42	132	127.46	122.38	15	55	83	45	
44	138	133.52	128.44	15	55	83	45	
45	142	136.55	131.47	15	55	83	45	
46	144	139.58	134.50	15	55	83	45	
48	151	145.64	140.56	15	55	83	45	
50	157	151.69	146.61	15	55	83	45	
52	163	157.75	152.67	15	55	83	45	
54	169	163.82	158.74	15	55	83	45	
56	175	169.88	164.80	15	65	93	50	
58	181	175.94	170.86	15	65	93	50	
60	187	182.00	176.92	15	65	93	50	
62	193	188.06	182.98	15	65	93	50	
64	199	194.12	189.04	15	65	93	50	
65	202	197.15	192.07	15	65	93	50	
66	205	200.18	195.10	15	65	93	50	
68	211	206.24	201.16	15	65	93	50	
70	218	212.30	207.22	15	65	93	50	
72	223	218.37	213.29	15	65	93	50	
74	229	224.43	219.35	15	65	93	50	
75	233	227.46	222.38	15	65	93	50	
76	236	230.49	225.41	15	65	93	50	
78	242	236.55	231.47	15	65	93	50	
80	248	242.61	237.53	15	65	93	50	

○上表の着色部分は歯先硬化を施しています。