

トーションばね

Torsion Springs


左巻規格
追加

■右巻の場合 製品番号: T□□□(A・B・C)
■左巻の場合 製品番号: TL□□□(A・B・C)

RoHS指令適合品

CADデータ: 2D / 3D

アーム角度が3種類ありますのでお選びください

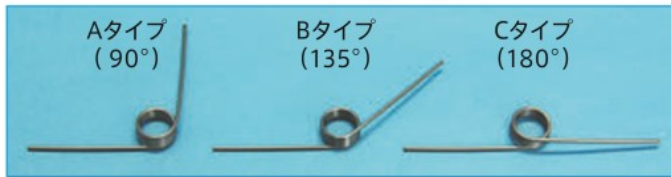

材質 SUS304WPB 1袋価格 1,500円

製品番号	内径 (ID) mm	線径 (d) mm	アーム長 (α) mm	巻数 (n)	ばね定数 N・mm/deg	許容変位量 deg	1袋内個数
T001	3.0	0.3	12	2	0.05	56	20
T002				3	0.04	82	20
T003				4	0.03	108	20
T004				5	0.02	135	20
T005	3.0	0.4	12	2	0.15	43	20
T006				3	0.11	63	20
T007				4	0.09	84	20
T008				5	0.07	104	20
T009	3.0	0.5	12	2	0.36	36	20
T010				3	0.26	52	20
T011				4	0.20	69	20
T012				5	0.17	86	20
T013	4.0	0.4	16	2	0.12	56	20
T014				3	0.08	82	20
T015				4	0.07	108	20
T016				5	0.05	135	20
T017	4.0	0.5	16	2	0.28	44	20
T018				3	0.20	64	20
T019				4	0.16	84	20
T020				5	0.13	105	20
T021	4.0	0.6	16	2	0.57	37	20
T022				3	0.41	55	20
T023				4	0.32	72	20
T024				5	0.26	89	20
T025	5.0	0.5	20	2	0.23	53	20
T026				3	0.16	78	20
T027				4	0.13	103	20
T028				5	0.10	128	20
T029	5.0	0.6	20	2	0.47	45	20
T030				3	0.34	66	20
T031				4	0.26	88	20
T032				5	0.21	109	20
T033	5.0	0.8	20	2	1.44	33	20
T034				3	1.03	49	20
T035				4	0.80	65	20
T036				5	0.65	80	20

製品番号	内径 (ID) mm	線径 (d) mm	アーム長 (α) mm	巻数 (n)	ばね定数 N・mm/deg	許容変位量 deg	1袋内個数
T037	6.0	0.6	24	2	0.40	53	10
T038				3	0.28	78	10
T039				4	0.22	103	10
T040				5	0.18	128	10
T041	6.0	0.8	24	2	1.23	39	10
T042				3	0.87	57	10
T043				4	0.68	76	10
T044				5	0.56	94	10
T045	6.0	1.0	24	2	2.91	32	10
T046				3	2.08	47	10
T047				4	1.62	62	10
T048				5	1.32	78	10
T049	7.0	0.7	28	2	0.63	51	10
T050				3	0.45	74	10
T051				4	0.35	98	10
T052				5	0.29	122	10
T053	7.0	0.9	28	2	1.69	40	10
T054				3	1.21	59	10
T055				4	0.94	78	10
T056				5	0.77	97	10
T057	7.0	1.2	28	2	5.17	30	10
T058				3	3.69	44	10
T059				4	2.86	58	10
T060				5	2.34	72	10
T061	8.0	0.8	32	2	0.94	51	10
T062				3	0.67	74	10
T063				4	0.52	98	10
T064				5	0.43	122	10
T065	8.0	0.9	32	2	1.49	45	10
T066				3	1.07	67	10
T067				4	0.83	88	10
T068				5	0.68	110	10
T069	8.0	1.2	32	2	4.59	33	10
T070				3	3.28	49	10
T071				4	2.55	65	10
T072				5	2.09	80	10

●仕様は予告なく変更する場合があります。 ●必要数量が多い場合には別冊のロット別価格表をご覧ください。