


ユニファイ・フリータイプ

RoHS指令適合品

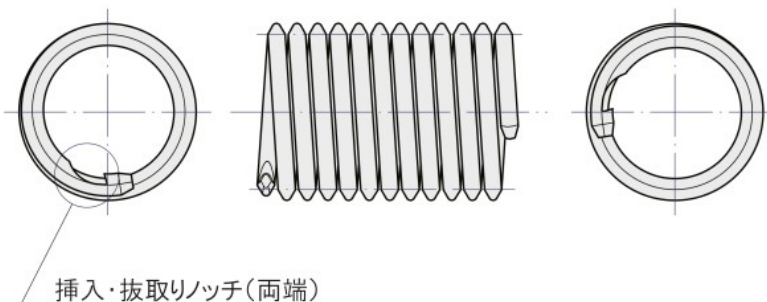

商品名 タングレス・インサート

材質:SUS304

区分	サイズ	呼び長さ	品番	NAS品番(参考記載)
並目	U2-56	1D	2TNC-2-56×1D	NAS1130-02-10
		1.5D	2TNC-2-56×1.5D	NAS1130-02-15
		2D	2TNC-2-56×2D	NAS1130-02-20
	U4-40	1D	2TNC-4-40×1D	NAS1130-04-10
		1.5D	2TNC-4-40×1.5D	NAS1130-04-15
		2D	2TNC-4-40×2D	NAS1130-04-20
	U6-32	1D	2TNC-6-32×1D	NAS1130-06-10
		1.5D	2TNC-6-32×1.5D	NAS1130-06-15
		2D	2TNC-6-32×2D	NAS1130-06-20
	U8-32	1D	2TNC-8-32×1D	NAS1130-08-10
		1.5D	2TNC-8-32×1.5D	NAS1130-08-15
		2D	2TNC-8-32×2D	NAS1130-08-20
	U10-24	1D	2TNC-10-24×1D	NAS1130-3C-10
		1.5D	2TNC-10-24×1.5D	NAS1130-3C-15
		2D	2TNC-10-24×2D	NAS1130-3C-20
	U1/4-20	1D	2TNC-1/4-20×1D	NAS1130-4-10
		1.5D	2TNC-1/4-20×1.5D	NAS1130-4-15
		2D	2TNC-1/4-20×2D	NAS1130-4-20
U5/16-18	1D	2TNC-5/16-18×1D	NAS1130-5C-10	
	1.5D	2TNC-5/16-18×1.5D	NAS1130-5C-15	
	2D	2TNC-5/16-18×2D	NAS1130-5C-20	
U3/8-16	1D	2TNC-3/8-16×1D	NAS1130-6C-10	
	1.5D	2TNC-3/8-16×1.5D	NAS1130-6C-15	
	2D	2TNC-3/8-16×2D	NAS1130-6C-20	

※NAS品番は参考記載。この品番でのご注文は不可です。

区分	サイズ	呼び長さ	品番	NAS品番(参考記載)
細目	U10-32	1D	2TNF-10-32×1D	NAS1130-3-10
		1.5D	2TNF-10-32×1.5D	NAS1130-3-15
		2D	2TNF-10-32×2D	NAS1130-3-20
	U1/4-28	1D	2TNF-1/4-28×1D	NAS1130-4F-10
		1.5D	2TNF-1/4-28×1.5D	NAS1130-4F-15
		2D	2TNF-1/4-28×2D	NAS1130-4F-20
	U5/16-24	1D	2TNF-5/16-24×1D	NAS1130-5F-10
		1.5D	2TNF-5/16-24×1.5D	NAS1130-5F-15
		2D	2TNF-5/16-24×2D	NAS1130-5F-20
	U3/8-24	1D	2TNF-3/8-24×1D	NAS1130-6F-10
		1.5D	2TNF-3/8-24×1.5D	NAS1130-6F-15
		2D	2TNF-3/8-24×2D	NAS1130-6F-20

※NAS品番は参考記載。この品番でのご注文は不可です。