


K2-0.68Ⅲ Series for 1.27mm [50mil] Pitch


K2-0.68Ⅲ Series Plunger Tip Styles

Pin Length: 24.6mm [0.969inch.]


Unit: mm [inch]

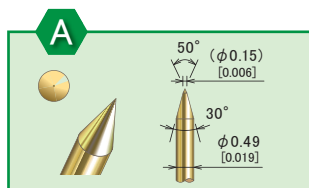


K2-0.68ⅢA-6.3M-3

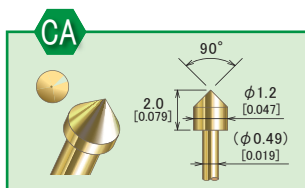


K2-0.68ⅢCA-6.5M1.2-3

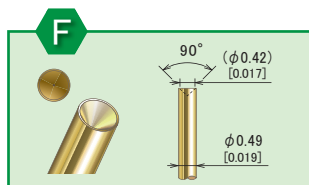


K2-0.68ⅢF-6.3M-4

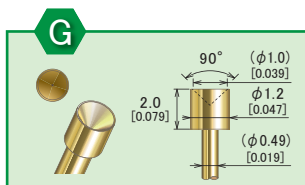


K2-0.68ⅢG-6.3M1.2-3

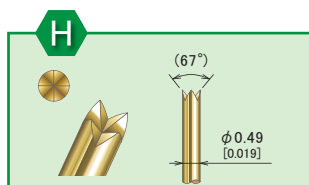


K2-0.68ⅢH-6.3M-3

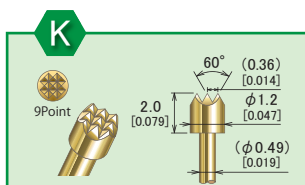


K2-0.68ⅢK-6.3M1.2-3

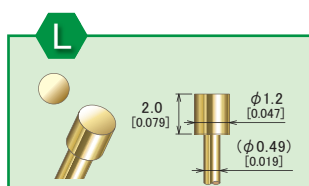

K2-0.68ⅢL-6.3M1.2-3

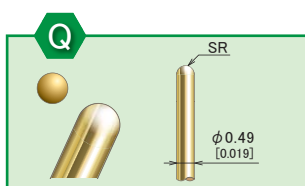


K2-0.68ⅢQ-6.3M-4

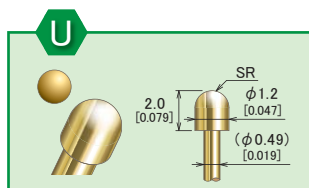

K2-0.68ⅢU-6.3M1.2-3

Spring Pin

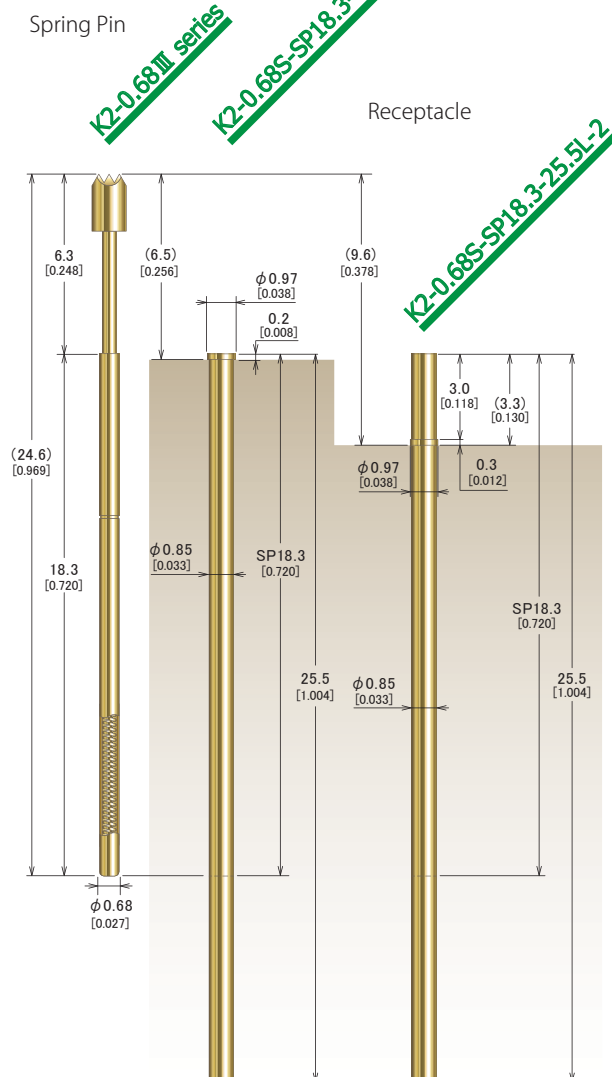

スプリングピン仕様 Spring Pin Specifications

推奨ストローク Operating Travel	2.87mm [0.113 inch]
荷重 Spring Force at Operating Travel	80gf [2.82oz.]
初期荷重 Initial Force	27gf [0.95oz.]
最大ストローク Max Travel	4.3mm [0.169 inch]
スプリング耐久回数 Life Span at Operating Travel	10 万回 (100K Cycles)
抵抗値 Resistance (Typ.)	60mΩ
最大許容電流値 Current Rating (Typ.)	1.0A
使用温度 Operating Temp.	-45℃~125℃

Material/Finish

Plunger	SK (Steel) / Au
Barrel	Phosphor Bronze / Au
Spring	Music Wire / Au

リセプタクル 品名 Receptacle

K2-0.68S-SP18.3-25.5L-1
(末端加工無し / No Termination)



K2-0.68S-SP18.3-25.5L-2
(末端加工無し / No Termination)



リセプタクル仕様 Receptacle Specifications

Material/Finish	Brass / Au
-----------------	------------

*All specifications are subject to change without notice.