



K2-0.48II Series for 1.0mm [39mil] Pitch

K2-0.48II Series Plunger Tip Styles


Pin Length: 19.0mm [0.748inch.]

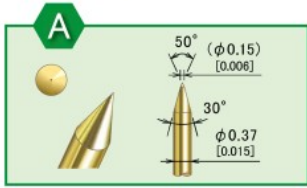


K2-0.48 II A-4M-5 *

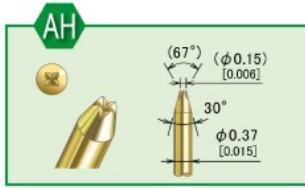


K2-0.48 II AH-4M-4 *

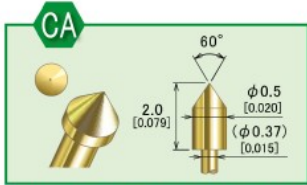


K2-0.48 II CA-4M0.5-5

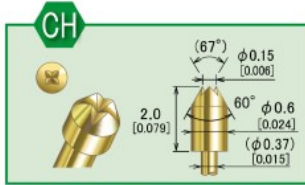


K2-0.48 II CH-4M0.6-5

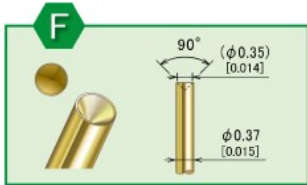


K2-0.48 II F-4M-3 *

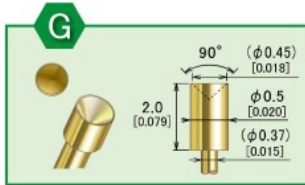


K2-0.48 II G-4M0.5-2

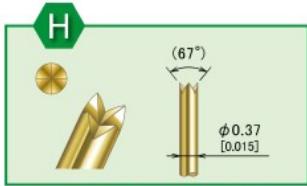


K2-0.48 II H-4M-3 *

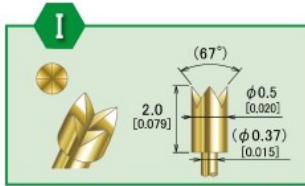


K2-0.48 II I-4M0.5-3

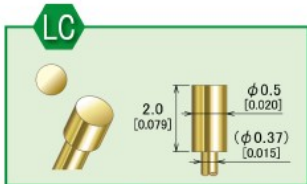

K2-0.48 II LC-4M0.5-4

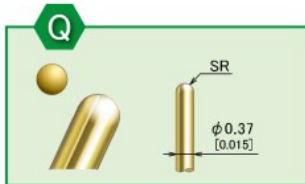

K2-0.48 II Q-4M-5 *

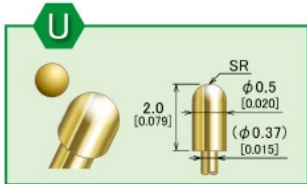


K2-0.48 II U-4M0.5-2

* 最大ストローク Max Travel: 2.3mm [0.091 inch]

スプリングピン仕様 Spring Pin Specifications

推奨ストローク Operating Travel	1.33mm [0.052 inch]
荷重 Spring Force at Operating Travel	50gf [1.76oz.]
初期荷重 Initial Force	26gf [0.92oz.]
最大ストローク Max Travel	2.0mm [0.079 inch]
スプリング耐久回数 Life Span at Operating Travel	100万回 (1,000K Cycles)
抵抗値 Resistance (Typ.)	100mΩ
最大許容電流値 Current Rating (Typ.)	4.2A
使用温度 Operating Temp.	-45°C ~ 125°C
Material/Finish	
Plunger	SK (Steel) / Au
Barrel	Phosphor Bronze / Au
Spring	Music Wire / Au

Spring Pin Receptacle Unit: mm [inch]

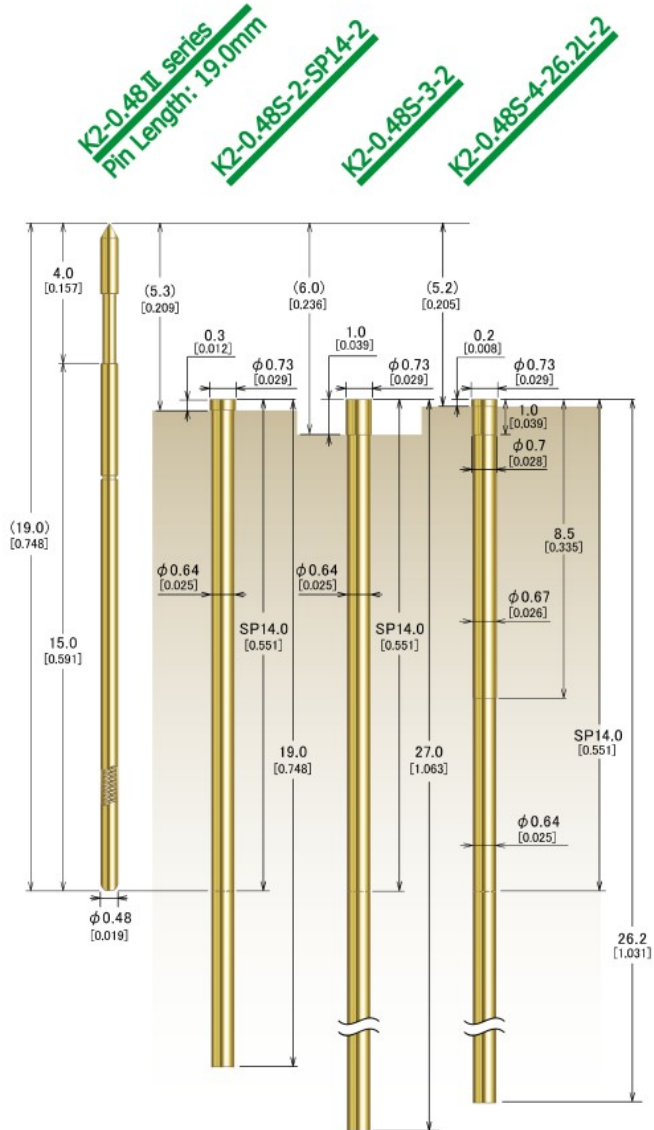

リセプタクル品名 Receptacle

K2-0.48S-2-SP14-2
(末端加工無し / No Termination)



K2-0.48S-3-2
(末端加工無し / No Termination)



K2-0.48S-4-26.2L-2
(末端加工無し / No Termination)



リセプタクル仕様 Receptacle Specifications

Material/Finish Brass / Au