


K2-1.37Ⅲ Series for 2.54mm [100mil] Pitch


K2-1.37Ⅲ Series Plunger Tip Styles

Pin Length: 32.9mm [1.295inch.]


Unit: mm [inch]

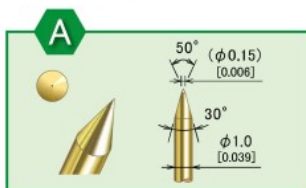


K2-1.37ⅢA-8.4M-15

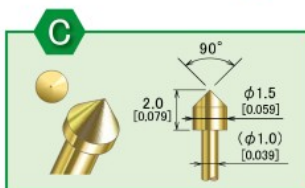


K2-1.37ⅢC-8.4M1.5-4

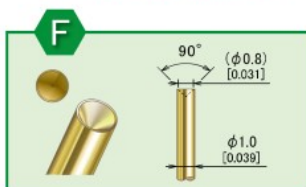


K2-1.37ⅢF-8.4M-4

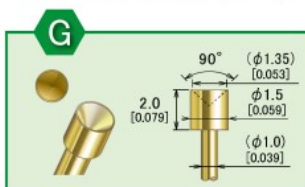


K2-1.37ⅢG-8.4M1.5-7

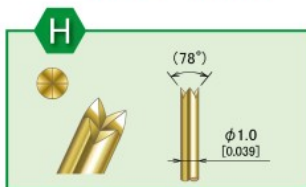


K2-1.37ⅢH-8.4M-6

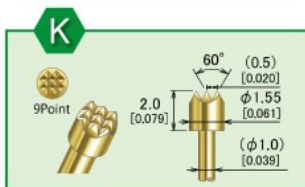


K2-1.37ⅢK-8.4M1.55-6

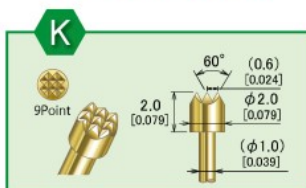

K2-1.37ⅢK-8.4M2.0-6

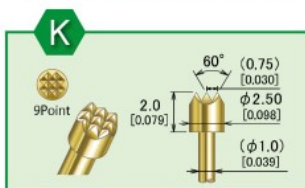


K2-1.37ⅢK-8.4M2.5-3

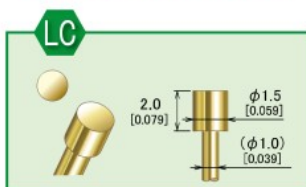

K2-1.37ⅢLC-8.4M1.5-5



K2-1.37ⅢQ-8.4M-7

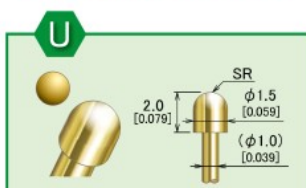

K2-1.37ⅢU-8.4M1.5-6


スプリングピン仕様 Spring Pin Specifications

推奨ストローク Operating Travel	4.27mm [0.168inch]
荷重 Spring Force at Operating Travel	165gf [5.82oz.]
初期荷重 Initial Force	58gf [2.05oz.]
最大ストローク Max Travel	6.4mm [0.252 inch]
スプリング耐久回数 Life Span at Operating Travel	100万回 (1,000K Cycles)
抵抗値 Resistance (Typ.)	35mΩ
最大許容電流値 Current Rating (Typ.)	5.4A
使用温度 Operating Temp.	-45°C~125°C

Material/Finish	
Plunger	BeCu / Au
Barrel	Nickel Silver / Au
Spring	Music Wire / Au
Ball	Brass / Au

Spring Pin

Receptacle

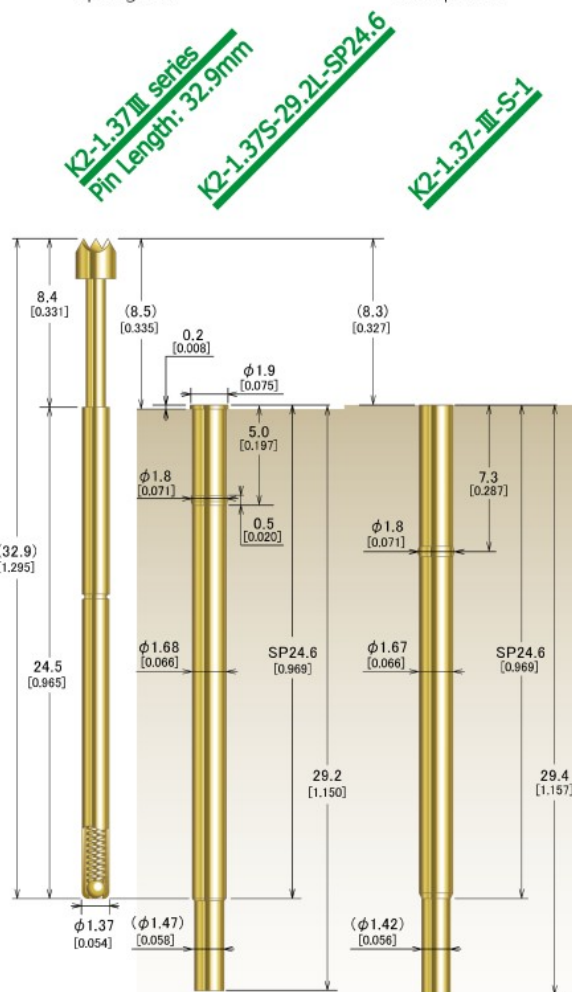

リセプタクル品名 Receptacle

K2-1.37S-29.2L-SP24.6
(末端加工無し / No Termination)

K2-1.37S-29.2L-SP24.6-U
(ソルダーカップ付 / with Solder Cup)

K2-1.37-Ⅲ-S-1
(末端加工無し / No Termination)

K2-1.37-Ⅲ-S-1-U
(ソルダーカップ付 / with Solder Cup)

リセプタクル仕様 Receptacle Specifications

K2-1.37S-29.2L-SP24.6 / K2-1.37S-29.2L-SP24.6-U	
Material/Finish	Brass / Au
K2-1.37-Ⅲ-S-1 / K2-1.37-Ⅲ-S-1-U	
Material/Finish	Nickel Silver / Au

*All specifications are subject to change without notice.