



K039 Series for 1.0mm [39mil] Pitch

K039 Series Plunger Tip Styles


Unit: mm [inch]

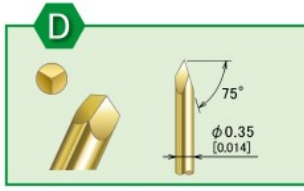


K039-D035090-SKAU
K039-D035130-SKAU

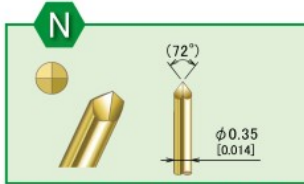

K039-N035090-SKAU
K039-N035130-SKAU

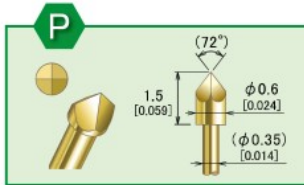

K039-P060090-SKAU
K039-P060130-SKAU

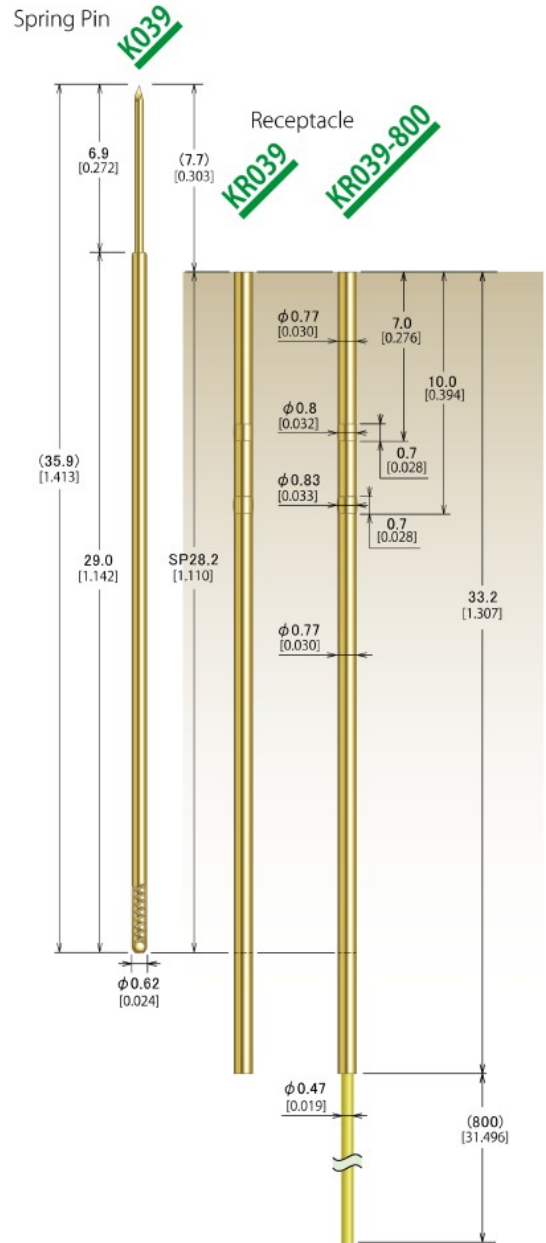

スプリングピン仕様 Spring Pin Specifications

推奨ストローク Operating Travel	4.6mm [0.181 inch]	
荷重 Spring Force at Operating Travel	90gf [3.17oz.]	130gf [4.59oz.]
初期荷重 Initial Force	35gf [1.23oz.]	48gf [1.69oz.]
最大ストローク Max Travel	6.9mm [0.272 inch]*	
スプリング耐久回数 Life Span at Operating Travel	30 万回 (300K Cycles)	
抵抗値 Resistance (Typ.)	50mΩ	
最大許容電流値 Current Rating (Typ.)	3.9A	4.7A
使用温度 Operating Temp.	-45°C ~ 125°C	
Material/Finish		
Plunger	SK (Steel) / Au	
Barrel	Brass / Au	
Spring	Music Wire / Au	
Ball	SUJ (Steel) / Au	

*先端形状：P の最大ストロークは 5.4mm [0.213inch] となります。

*Max Stroke for Tip Style: P is 5.4mm [0.213 inch].

リセプタクル 品名 Receptacle

KR039
(リード線なし / No Wire)

KR039-800
(800mmリード線付 / with 800mm Wire)

KR039 Material / Finish Brass / Au

スプリングピン品名 Spring Pin Item Number

K 039	- D	035	130	- SK	AU
ピッチ Pitch 39mil	先端形状 Tip style	先端外径 Tip diameter φ 0.35mm φ 0.60mm	バネ荷重 Spring force 90gf 130gf	先端材質 Material SK	先端メッキ Plating Au

*All specifications are subject to change without notice.