


エルボ (A形)・ベンド (A形)

受け差しエルボ


L

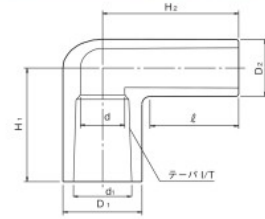

種類	サイズ	コード	価格	梱包	D1	D2	d	d1	H1	H2	I	I/T
HITS	13S×13P	5 224095 -	100	340 (170×2)	25-0	18±0.2	14	18.4±0.2	36	43	28	1/30
HITS	20S×20P	5 224096 -	158	240 (60×4)	34-0	26±0.2	21	26.45±0.2	50	57	37	1/34

45°エルボ (A形)


45L

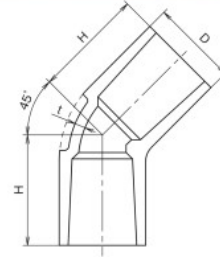

サイズ	TS			HITS			備考	D	t	H
	コード	価格	梱包	コード	価格	梱包				
13	5 220100 -	83	720 (180×4)	5 224101 -	88	720 (180×4)	◎	24-0.6	3-0.3	35+5/-1
16	5 220101 -	88	440 (110×4)	5 224102 -	102	440 (110×4)	◎	29-0.7	3.5-0.3	38+5/-1
20	5 220102 -	141	260 (65×4)	5 224100 -	167	260 (65×4)	◎	33-0.8	3.5-0.3	44+5/-1
25	5 220103 -	154	160 (40×4)	5 224103 -	217	160 (40×4)	◎	40-0.8	4-0.4	53+5/-1
30	5 220104 -	409	100 (25×4)	5 224104 -	616	100 (25×4)	◎	46-1.2	4-0.4	58+5/-1
40	5 220105 -	483	60 (30×2)	5 224105 -	721	60 (30×2)	◎	57-1.2	4.5-0.4	71+5/-1
50	5 220106 -	780	30 (15×2)	5 224106 -	1,163	30 (15×2)	◎	72-0	5-0.5	82+5/-1
65	5 220107 -	1,310	20	5 224107 -	2,030	20	◎	90-1.5	6.6-0.5	91+5/-1
75	5 220108 -	1,580	12	5 224108 -	2,490	12	◎	102-1.5	8.0-0.5	97+5/-1
100	5 220109 -	2,790	8	5 224109 -	4,490	8	◎	130-1.8	10.0-0.6	122+5/-1

45°ベンド (A形)

45B

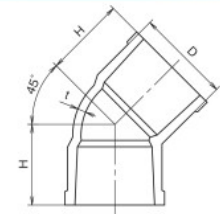

種類	サイズ	コード	価格	梱包	備考	D	t	H
TS	125	5 220153 -	9,320	6	●	156-0	11-0.6	149+5/-1
TS	150	5 220154 -	13,840	4	●	185-0	13-0.8	184+5/-1
TS	200	5 220155 -	21,750	2		236	10	193+5/-1

旭有機材(株)製