



HF 日鋼油圧・エアチャック用

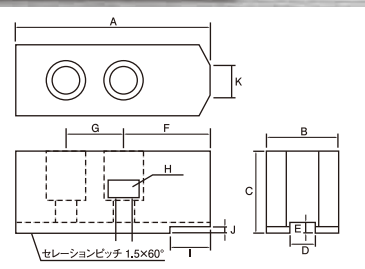

■ 材質：S45C



 爪形状



山取有

取付ボルト

インチ	穴径(mm)
5	13.5
6	13.5
8	17
10	HF10-100:20 その他：19
12	19
14	25
18	32

単位：mm

生爪型式		希望小売価格 (1set3個入/円・税別)	A	B	C	D	E	F	G	H	I	J	K	爪形状	
HF	5	H36	3,800	62	23	36	11	3.5	33	17	M8	21	3.5	3	B
		H60	6,000			60									
	6	H36	3,600	73	27.5	36	11	3.5	38	25	M8	27.5	3.5	7	B
		H48	5,500			48									
		H60	6,500			60									
	8	H80	9,000	95	34	80	14	3.5	45	30	M10	30.5	3.5	10	B
		H42	4,200			42									
		H60	7,000			60									
		H80	9,300			80									
	10	H100	13,000	103		100			49			36	4	12	
		H50	7,400	110	40	50	20	4.5	57	30	M12	38	4.5	15	B
		H60	10,400			60									
		H80	14,800			80									
	H100	20,000	100												
	12	H48	9,000	129	44	48	20	4.5	60	35	M12	39	4.5	15	B
		H60	12,000			60									
		H80	15,400			80									
		H100	22,000			100									
14	H72	22,000	150	48	72	21	5	76	45	M16	48	5	20	B	
16	日鋼「HF-14」をご使用ください														
18	H85	31,800	180	57	85	26	5	100	50	M20	60	5.5	20	B	


※生爪兼用表は56ページを参照ください。

生爪


AL-HFアルミ 日鋼油圧・エアチャック用




■ 材質：アルミ(A2017)

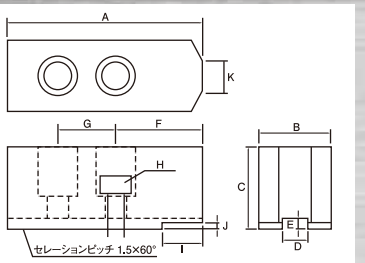

爪形状

 

山取有

 

小径

取付ボルト

インチ	穴径(mm)
6	13.5
8	17

単位：mm

生爪型式		希望小売価格 (1set3個入/円・税別)	A	B	C	D	E	F	G	H	I	J	K	爪形状	
AL-HF	6	H35	11,000	80	27.5	35	11	3.5	43	25	M8	30.5	4	4	C
		H60	15,500			60									C
	8	H40	12,000	103	34	40	14	3.5	49	30	M10	36	4	12	B

※生爪兼用表は56ページを参照ください。