

**Isolierkörpermaterial**

PBT, UL94V-0

**Kontaktmaterial**

Hülse - Messing  
 Clip - Phosphorbronze

**Kontaktfläche**

Ni, Au / Sn

**Kontaktwiderstand**

4mΩ max

**Isolationswiderstand**

10000MΩ min

**Strombelastbarkeit**

3A

**Betriebstemperatur**

-40°C - +105°C

**Betriebsspannung**

100V AC

**Prüfspannung**

500V AC

**Verpackung**

Kunststoffbeutelverpackung

**Insulator material**

PBT, UL94V-0

**Contact material**

Sleeve - Brass  
 Clip - Phosphor bronze

**Plating**

Ni, Au / Sn

**Contact resistance**

4mΩ max

**Insulation resistance**

10000MΩ min

**Current rating**

3A

**Operating temperature**

-40°C - +105°C

**Operating voltage**

 

100V AC

**Test voltage**

500V AC

**Packing**

Polybag packing

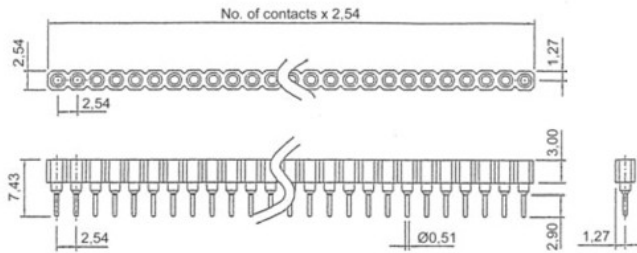

**Bestellcode / Ordercode**

**Polzahl**

01 - 64  
 (Standard = 20 , 32)

**No. of contacts**

01 - 64  
 (Standard = 20 , 32))

**Oberfläche Lötstift**

G - Gold Flash  
 Z - Zinn

**Plating sleeve**

G - Flash Gold  
 Z - Tin

**AW 127 - xx / x - T**

Bitte „x“ durch die geeignete Option ersetzen  
 Please replace „x“ appropriate option

Cable assemblies

D-Sub / Hoods Centronics

Multiflex - DIN41651

Modular

USB IEEE1394

Switches

Powercords Powerinlets

DIN41612 Hardmetric

MiniDIN

Sockets / Strips Jumper

Terminal Blocks

Memory Card

FFC / FPC