


レジャーサの形状・寸法

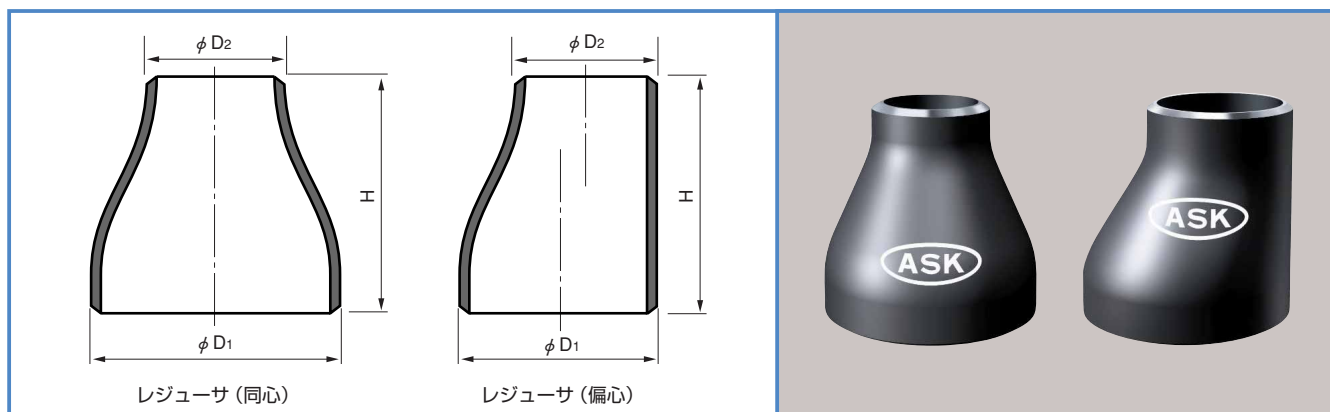

単位：mm

径の呼び		外径		端面から端面までの距離	径の呼び		外径		端面から端面までの距離
A	B	φD ₁	φD ₂	H	A	B	φD ₁	φD ₂	H
20 × 15	¾ × ½	27.2	21.7	38.1	200 × 150	8 × 6	216.3	165.2	152.4
25 × 20	1 × ¾	34.0	27.2	50.8	125	5		139.8	
15	½		21.7		100	4		114.3	
32 × 25	1 ¼ × 1	42.7	34.0	50.8	90	3 ½		101.6	
20	¾		27.2		250 × 200	10 × 8	267.4	216.3	177.8
15	½		21.7		150	6		165.2	
40 × 32	1 ½ × 1 ¼	48.6	42.7	63.5	125	5		139.8	
25	1		34.0		100	4		114.3	
20	¾		27.2		300 × 250	12 × 10	318.5	267.4	203.2
15	½		21.7		200	8		216.3	
50 × 40	2 × 1 ½	60.5	48.6	76.2	150	6		165.2	
32	1 ¼		42.7		125	5		139.8	
25	1		34.0		100	4		114.3	
20	¾		27.2		350 × 300	14 × 12	355.6	318.5	330.2
65 × 50	2 ½ × 2	76.3	60.5	88.9	250	10		267.4	
40	1 ½		48.6		200	8		216.3	
32	1 ¼		42.7		150	6		165.2	
25	1		34.0		400 × 350	16 × 14	406.4	355.6	355.6
80 × 65	3 × 2 ½	89.1	76.3	88.9	300	12		318.5	
50	2		60.5		250	10		267.4	
40	1 ½		48.6		200	8		216.3	
32	1 ¼		42.7		450 × 400	18 × 16	457.2	406.4	381.0
90 × 80	3 ½ × 3	101.6	89.1	101.6	350	14		355.6	
65	2 ½		76.3		300	12		318.5	
50	2		60.5		250	10		267.4	
40	1 ½		48.6		500 × 450	20 × 18	508.0	457.2	508.0
32	1 ¼		42.7		400	16		406.4	
100 × 90	4 × 3 ½	114.3	101.6	101.6	350	14		355.6	
80	3		89.1		300	12		318.5	
65	2 ½		76.3		550 × 500	22 × 20	558.8	508.0	508.0
50	2		60.5		450	18		457.2	
40	1 ½		48.6		400	16		406.4	
125 × 100	5 × 4	139.8	114.3	127.0	350	14		355.6	
90	3 ½		101.6		300	12		318.5	
80	3		89.1		600 × 550	24 × 22	609.6	558.8	508.0
65	2 ½		76.3		500	20		508.0	
50	2		60.5		450	18		457.2	
150 × 125	6 × 5	165.2	139.8	139.7	400	16		406.4	
100	4		114.3						
90	3 ½		101.6						
80	3		89.1						
65	2 ½		76.3						