



# 内面パッキン

型番	JIS 10K	G	N	ゴム種	1	呼び径
	JIS 5K	G	N	ゴム種	5	呼び径
	上水(SBR)	G	A	ゴム種	W	呼び径

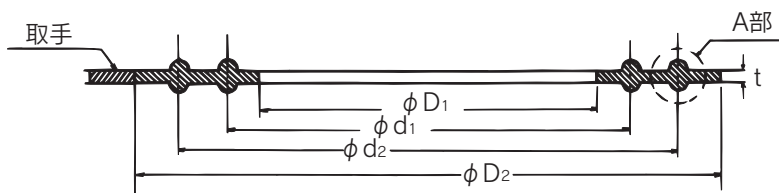

A部詳細

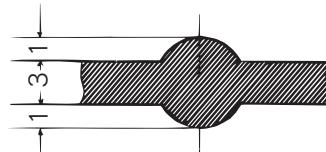

JIS 10K用,5K用 材質：EPDM

## ■ 寸法表

(単位:mm)

呼び径	規格	D <sub>2</sub>	D <sub>1</sub>	d <sub>1</sub>	d <sub>2</sub>	t
15	5K	47	18	26	39	3
	10K	54		26	41	
20	5K	52	22	30	44	3
	10K	59		32	47	
25	5K	62	30	39	53	3
	10K	70		38	53	
32	5K	74	37	45	60	3
	10K	80		50	65	
40	5K	79	43	53	69	3
	10K	85		54	69	
50	5K	89	54	64	79	3
	10K	100		68	83	
65	5K	114	69	82	101	3
	10K	120		86	101	
80	5K	125	80	93	112	3
	10K	130		98	112	
100	5K	145	102	114	133	3
	10K	155		120	138	
125	5K	180	127	142	165	3
	10K	187		145	166	
150	5K	210	150	167	193	3
	10K	217		168	190	
200	5K	257	198	215	240	3
	10K	267		216	247	
250	5K	322	249	270	301	3
	10K	329		270	306	
300	5K	367	300	318	349	3
	10K	374		324	352	

上水用 材質：SBR

## ■ 寸法表

(単位:mm)

呼び径	D <sub>2</sub>	D <sub>1</sub>	d <sub>2</sub>	d <sub>1</sub>	t
40	85	43	69	54	3
50	100	53	83	68	3
75(80)	148	80	110	90	3
100	175	102	135	115	3
125	200	127	160	140	3
150	227	152	187	168	3
200	279	202	236	218	3
250	337	253	288	270	3
300	391	303	340	320	3
350	445	353	400	370	3

- (注) 1. 40mm(1 1/2inch)は上水規格外です。(JIS 10K 規格品)  
 2. AVパッキンに使用されているゴムは、水道用ゴム(JIS K 6353)に準じております。  
 (SBR: スチレンブタジエンゴム)