


# BENKAN ステンレス鋼製T(同径、径違い)

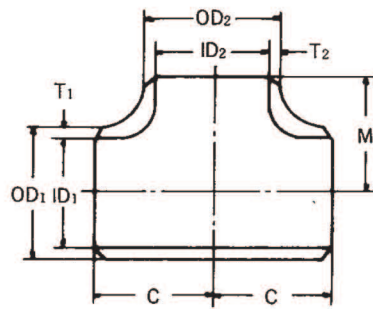

T(同径)

径の呼び (B) 母管×枝管	外径 OD	Sch5S		Sch10S		Sch20S		Sch40		Sch80	
		内径 I D	厚さ T	内径 I D	厚さ T	内径 I D	厚さ T	内径 I D	厚さ T	内径 I D	厚さ T
1/2 × 1/2	21.7	18.4	1.7	17.5	2.1	16.7	2.5	16.1	2.8	14.3	3.7
3/4 × 3/4, 1/2	27.2	23.9	1.7	23.0	2.1	22.2	2.5	21.4	2.9	19.4	3.9
1 × 1, 3/4, 1/2	34.0	30.7	1.7	28.4	2.8	28.0	3.0	27.2	3.4	25.0	4.5
1 1/4 × 1 1/4, 1, 3/4, 1/2	42.7	39.4	1.7	37.1	2.8	36.7	3.0	35.5	3.6	32.9	4.9
1 1/2 × 1 1/2, 1 1/4, 1, 3/4, 1/2	48.6	45.3	1.7	43.0	2.8	42.6	3.0	41.2	3.7	38.4	5.1
2 × 2, 1 1/2, 1 1/4, 1, 3/4	60.5	57.2	1.7	54.9	2.8	53.5	3.5	52.7	3.9	49.5	5.5
2 1/2 × 2 1/2, 2, 1 1/2, 1 1/4, 1	76.3	72.1	2.1	70.3	3.0	69.3	3.5	65.9	5.2	62.3	7.0
3 × 3, 2 1/2, 2, 1 1/2, 1 1/4	89.1	84.9	2.1	83.1	3.0	81.1	4.0	78.1	5.5	73.9	7.6
3 1/2 × 3 1/2, 3, 2 1/2, 2, 1 1/2	101.6	97.4	2.1	95.6	3.0	93.6	4.0	90.2	5.7	85.4	8.1
4 × 4, 3 1/2, 3, 2 1/2, 2, 1 1/2	114.3	110.1	2.1	108.3	3.0	106.3	4.0	102.3	6.0	97.1	8.6
5 × 5, 4, 3 1/2, 3, 2 1/2, 2	139.8	134.2	2.8	133.0	3.4	129.8	5.0	126.6	6.6	120.8	9.5
6 × 6, 5, 4, 3 1/2, 3, 2 1/2	165.2	159.6	2.8	158.4	3.4	155.2	5.0	151.0	7.1	143.2	11.0
8 × 8, 6, 5, 4, 3 1/2	216.3	210.7	2.8	208.3	4.0	203.3	6.5	199.9	8.2	190.9	12.7
10 × 10, 8, 6, 5, 4	267.4	260.6	3.4	259.4	4.0	254.4	6.5	248.8	9.3	237.2	15.1
12 × 12, 10, 8, 6, 5	318.5	310.5	4.0	309.5	4.5	305.5	6.5	297.9	10.3	283.7	17.4

注) 径の呼び12B(300A)迄は通常1シームとなりますので、シームレス品(径の呼び10B(250A)迄)を御希望の場合は事前御打せ願います。

◎ 概略重量は基準寸法による計算値であり、ステンレス鋼(SUS304)の比重 7.93g/cm<sup>3</sup> を使用しています。