


# BOB NUTS

ボブナット

RoHS指令対応品



## 形状・寸法

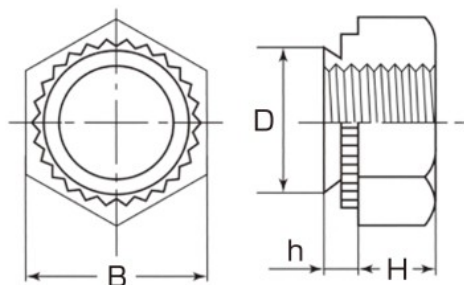

## 製品の呼び方

# BOB - M6 - 1

型式

ねじの呼び

シャンクの区分

- 1 : 最小板厚 1.0mm
- 2 : 最小板厚 1.4mm
- 3 : 最小板厚 2.0mm

## 仕様・機械的特性

### ●ボブナットの寸法表

単位(mm)

ねじの呼び	ピッチ	型式		D (max)	B -0.2	H ±0.1	h (max)	相手材		
		C-Steel	Stainless Steel					最小板厚 (min)	取付穴径 +0.08 0	取付穴位置 <sup>※1</sup> (min)
M2	0.4	BOB-M2-1	BOBS-M2-1	4.45	5.5	2.0	1.0	1.0	4.5	4.5
M2.5	0.45	BOB-M2.5-1	BOBS-M2.5-1							
M2.6		BOB-M2.6-1	BOBS-M2.6-1							
M3	0.5	BOB-M3-1	BOBS-M3-1	4.97	5.5	2.2	1.4	1.4	5.0	5.0
		BOB-M3-2	BOBS-M3-2							
		BOB-M3-1 (TS)	—							
M4	0.7	BOB-M4-1	BOBS-M4-1	5.97	7.0	2.4	1.0	1.0	5.5	5.5
		BOB-M4-2	BOBS-M4-2							
		BOB-M4-1 (TS)	—							
M5	0.8	BOB-M5-1	BOBS-M5-1	6.45	8.0	3.0	1.0	1.0	6.5	6.5
		BOB-M5-2	BOBS-M5-2							
M6	1.0	BOB-M6-1	BOBS-M6-1	7.95	10.0	4.0	1.0	1.0	8.0	8.0
		BOB-M6-2	BOBS-M6-2							
M8	1.25	BOB-M8-2	BOBS-M8-2	9.95	13.0	4.5	1.4	1.4	10.0	10.0
		BOB-M8-3	BOBS-M8-3							

※1 取付穴中心と取付板の端までの最小距離