


PCP

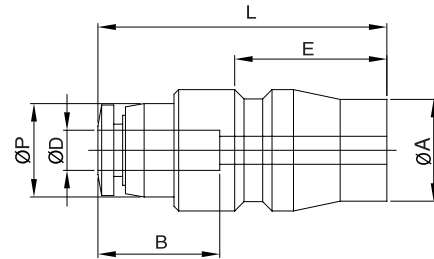

METRIC

MODEL	ØD	ØP	ØC	L	E	B	ORFICE	WEIGHT(g)	BOX(EA)
FCP04	4	10.0	10.9	31.0	16.3	16.3	3.0	19.8	100
FCP06	6	11.9	10.9	31.8	16.3	17.5	5.0	18.8	100
FCP08	8	14.0	10.9	34.9	16.3	18.6	6.0	19.7	100
FCP10	10	16.0	10.9	42.4	20.8	19.8	8.0	28.5	50
FCP12	12	19.0	10.9	45.5	20.8	22.2	8.0	43.3	50
FCP16	16	24.0	10.9	48.9	20.8	24.1	8.0	52.0	25



INCH

MODEL	ØD	ØP	L	E	ØA	B	ORFICE	WEIGHT(g)	BOX(EA)
FCP 5/32	5/32	10.0	31.0	16.3	10.9	16.3	3.0	18.8	100
FCP 3/16	3/16	11.0	31.7	16.3	10.9	16.8	3.0	18.8	100
FCP 1/4	1/4	13.0	31.7	16.3	10.9	17.4	5.0	15.8	100
FCP 5/16	5/16	14.0	34.9	20.8	10.9	18.6	6.0	19.7	50
FCP 3/8	3/8	16.1	41.8	20.8	10.9	19.8	8.0	27.4	50
FCP 1/2	1/2	20.6	46.4	20.8	10.9	23.0	8.0	38.1	25

