



チー【SP-T】・径違いチー【SP-RT】

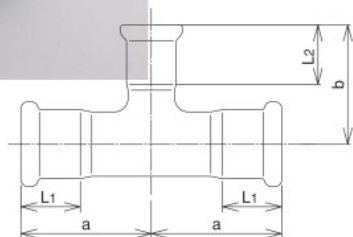


[単位: mm]					
呼び方[Su]	a	b	L ₁	L ₂	
13	38	38	21	21	
20	46	46	24	24	
20×13	46	42	24	21	
25	51	51	24	24	
25×20	51	51	24	24	
25×13	51	53	24	21	
30	99	99	39	39	
30×25	99	70	39	24	
30×20	99	70	39	24	
30×13	99	67	39	21	
40	107	107	47	47	
40×30	107	99	47	39	
40×25	107	72	47	24	
40×20	107	72	47	24	
40×13	107	69	47	21	
50	102	102	52	52	
50×40	102	107	52	47	
50×30	102	109	52	39	
50×25	102	82	52	24	
50×20	102	76	52	24	
50×13	102	73	52	21	
60	127	127	64	64	
60×50	127	112	64	52	
60×40	127	117	64	47	
60×30	127	109	64	39	
60×25	117	84	64	24	
60×20	117	84	64	24	
60×13	117	83	64	21	

ソケット【SP-S】

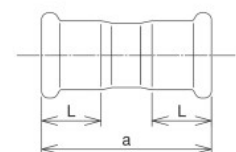

[単位: mm]					
呼び方[Su]	a	L			
13	53	21			
20	60	24			
25	60	24			
30	100	39			
40	116	47			
50	126	52			
60	154	64			

径違いソケット【SP-RS】

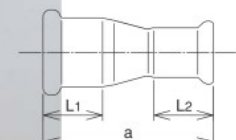

[単位: mm]					
呼び方[Su]	a	L ₁	L ₂		
20×13	60	24	21		
25×20	64	24	24		
25×13	75	24	21		
30×25	90	39	24		
30×20	103	39	24		
30×13	105	39	21		
40×30	122	47	39		
40×25	121	47	24		
40×20	121	47	24		
40×13	123	47	21		
50×40	133	52	47		
50×30	146	52	39		
50×25	131	52	24		
50×20	131	52	24		
50×13	133	52	21		
60×50	157	64	52		
60×40	176	64	47		
60×30	168	64	39		
60×25	153	64	24		
60×20	153	64	24		
60×13	155	64	21		

※このカタログに掲載の商品は、全て発色シールなし品で撮影しております。