


**バッチカルミルスレッド用 仕上げ刃付チップ**

**ISO** **メートルねじ**  
(内径ねじ切り用) **仕上げ刃付 60°**

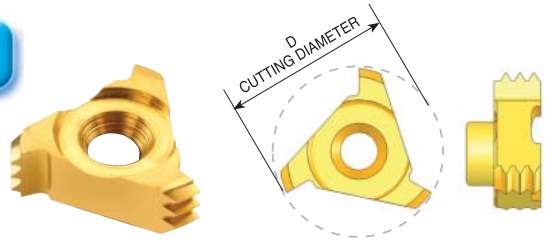

チップタイプ	ピッチ(mm)	M並目	M細目	型番	切刃の山数	D	価格	適用ホルダー	
<b>new</b> C10	0.5	—	$\phi \geq 10$	C10   0.5 ISO	5	9.0	¥7,390	H1、2、12、13	
	1.0		$\phi \geq 12$	C10   1.0 ISO	3	¥6,140			
	1.5		$\phi \geq 13$	C10   1.5 ISO	2	¥6,140			
	2.0	M14	$\phi \geq 14$	C10   2.0 ISO	1	10.0	¥6,140	H1、2、12	
<b>new</b> <b>new</b> C12	0.5	—	$\phi \geq 13$	C12   0.5 ISO	6	12.0	¥7,400	H3、4、5、14	
	0.75		$\phi \geq 13$	C12   0.75 ISO	4		¥6,780		
	1.0		$\phi \geq 14$	C12   1.0 ISO	3		¥6,150		
	1.5		$\phi \geq 15$	C12   1.5 ISO	2		¥6,150		
	2.0	M16	$\phi \geq 16$	C12   2.0 ISO	1	12.4	¥6,150	H3、4、5	
	2.5	M18、M20	$\phi \geq 17$	C12   2.5 ISO	1	12.0	¥6,150		
3.0	—	$\phi \geq 17$	C12   3.0 ISO	1	12.4	¥6,150			
<b>new</b> C18	0.5	—	$\phi \geq 19$	C18   0.5 ISO	9	17.8	¥9,180	H6、7、8、9、15	
	0.75		$\phi \geq 19$	C18   0.75 ISO	6		¥8,460		
	1.0		$\phi \geq 20$	C18   1.0 ISO	5		¥7,680		
	1.5		$\phi \geq 20$	C18   1.5 ISO	3		¥7,680		
	2.0		$\phi \geq 21$	C18   2.0 ISO	2		¥7,680		
	2.5	M22	$\phi \geq 22$	C18   2.5 ISO	2		¥7,680		
	3.0	M24、M27	$\phi \geq 23$	C18   3.0 ISO	1		¥7,680		
3.5	M30、M33	$\phi \geq 24$	C18   3.5 ISO	1	¥7,680				
<b>new</b> C25	3.0	—	$\phi \geq 30$	C25   3.0 ISO	2	25.0	¥8,680	H10、11、16、17	
	4.0		M36、M39	$\phi \geq 32$	C25   4.0 ISO		1		¥8,680
	4.5		M42、M45	$\phi \geq 33$	C25   4.5 ISO		1		¥8,680
	5.0		M48、M52	$\phi \geq 34$	C25   5.0 ISO		1		¥8,680
	5.5		M56、M60	$\phi \geq 35$	C25   5.5 ISO		1		¥8,680
	6.0		M64、M68	$\phi \geq 36$	C25   6.0 ISO		1		¥8,680

**UN** **ユニファイねじ**  
(内径ねじ切り用) **仕上げ刃付 60°**

チップタイプ	ピッチ 山数/インチ	呼 び	UNC	UNF	UNEF	型番	切刃の 山数	D	価格	適用ホルダー
<b>new</b> C10	20	5/8, 11/16, 3/4	9/16			C10   20 UN	2	10.0	¥6,140	H1、2、12、13
	18					C10   18 UN	2		¥6,140	
	12					C10   12 UN	1		¥6,140	H1、2、12
<b>new</b> C12	32	9/16, 5/8	5/8	3/4	9/16, 5/8, 11/16	C12   32 UN	3	12.0	¥6,780	H3、4、5、14
	28	9/16, 5/8, 11/16				C12   28 UN	3		¥6,150	
	24					C12   24 UN	2		¥6,150	
	20	9/16, 5/8, 11/16				C12   20 UN	2		¥6,150	
	18					C12   18 UN	2		¥6,150	
	16	5/8, 11/16				C12   16 UN	1		¥6,150	
	11					C12   11 UN	1		¥6,150	H3、4、5
10		C12   10 UN	1	¥6,150						
<b>new</b> <b>new</b> C18	32	3/4, 13/16, 7/8	7/8	1, 11/8	13/16, 7/8, 15/16	C18   32 UN	6	17.8	¥8,460	H6、7、8、9、15
	28	3/4, 13/16, 7/8				C18   28 UN	5		¥7,680	
	24					C18   24 UN	4		¥7,680	
	20	11/16, 11/8				C18   20 UN	3		¥7,680	
	18					C18   18 UN	3		¥7,680	
	16	7/8, 1				C18   16 UN	3		¥7,680	
	14					C18   14 UN	2		¥7,680	
	12	7/8				C18   12 UN	2		¥7,680	
	11					C18   11 UN	2		¥7,680	
9		C18   9 UN	1	¥7,680						
8		C18   8 UN	1	¥7,680						
<b>new</b> C25	8	13/16, 11/4, 15/16	13/8, 11/2	13/4	21/2, 23/4	C25   8 UN	2	25.0	¥8,680	H10、11、16、17
	7					C25   7 UN	1		¥8,680	
	6	17/16, 19/16				C25   6 UN	1		¥8,680	
	5					C25   5 UN	1		¥8,680	
	4					C25   4 UN	1		¥8,680	

ピンク色の型番表示は、ノガ・ジャパン在庫品です。