



ISO 油穴付 超硬ソリッドミルスレッド

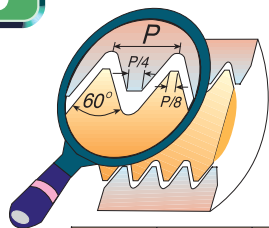


メートルねじ・内径用

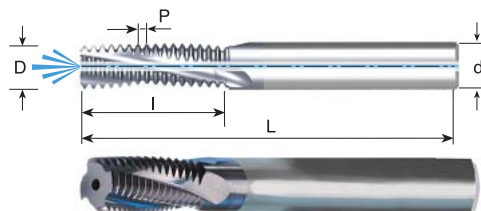


ピッチ mm	M 並目	M 細目	型番	d mm	D mm	刃数	l mm	L mm	価格
0.5		$\phi \geq 5$	B06038C10 0.5 ISO	6	3.8	3	10.3	58	¥34,200
0.7	M4	$\phi \geq 5$	B06031C7 0.7 ISO	6	3.1	3	7.4	58	¥34,200
0.75		$\phi \geq 6$	B06045C10 0.75 ISO	6	4.5	3	10.1	58	¥34,200
0.75		$\phi \geq 12$	B1010D24 0.75 ISO	10	10.0	4	24.4	73	¥45,600
0.8	M5	$\phi \geq 6$	B06038C9 0.8 ISO	6	3.8	3	9.2	58	¥34,200
1.0	M6	$\phi \geq 7$	B06046C10 1.0 ISO	6	4.6	3	10.5	58	¥34,200
1.0	M6	$\phi \geq 7$	B06046C14 1.0 ISO	6	4.6	3	14.5	58	¥41,000
1.0		$\phi \geq 9$	B0606C12 1.0 ISO	6	6.0	3	12.5	58	¥34,200
1.0		$\phi \geq 10$	B0808D16 1.0 ISO	8	8.0	4	16.5	64	¥40,000
1.0		$\phi \geq 12$	B1010D24 1.0 ISO	10	10.0	4	24.5	73	¥45,600
1.25	M8	$\phi \geq 10$	B0606C14 1.25 ISO	6	6.0	3	14.4	58	¥34,200
1.25	M8	$\phi \geq 10$	B0606C19 1.25 ISO	6	6.0	3	19.4	58	¥41,000
1.5	M10	$\phi \geq 12$	B08078C17 1.5 ISO	8	7.8	3	17.0	64	¥40,000
1.5	M10	$\phi \geq 12$	B08078C24 1.5 ISO	8	7.8	3	24.8	76	¥48,200
1.5		$\phi \geq 14$	B1010D21 1.5 ISO	10	10.0	4	21.8	73	¥45,600
1.5		$\phi \geq 16$	B1212D26 1.5 ISO	12	12.0	4	26.3	84	¥52,000
1.5		$\phi \geq 20$	B1616F33 1.5 ISO	16	16.0	6	33.8	105	¥68,400
1.75	M12	$\phi \geq 12$	B1009C20 1.75 ISO	10	9.0	3	20.1	73	¥45,600
1.75	M12	$\phi \geq 12$	B1009C28 1.75 ISO	10	9.0	3	28.9	73	¥54,700
2.0	M14	$\phi \geq 15$	B1010C27 2.0 ISO	10	10.0	3	27.0	73	¥45,600
2.0	M16	$\phi \geq 17$	B12118D27 2.0 ISO	12	11.8	4	27.0	84	¥52,000
2.0	M16	$\phi \geq 17$	B12118D39 2.0 ISO	12	11.8	4	39.0	105	¥62,400
2.0		$\phi \geq 26$	B2020F41 2.0 ISO	20	20.0	6	41.0	105	¥98,700
2.5	M20	$\phi \geq 22$	B1615E33 2.5 ISO	16	15.0	5	33.8	105	¥68,400
2.5	M20	$\phi \geq 22$	B1615E48 2.5 ISO	16	15.0	5	48.8	105	¥82,000
3.0	M24	$\phi \geq 25$	B2018D40 3.0 ISO	20	18.0	4	40.5	105	¥98,700
3.0	M24	$\phi \geq 25$	B2018D58 3.0 ISO	20	18.0	4	58.5	120	¥118,500
3.0	M27	$\phi \geq 27$	B2020D43 3.0 ISO	20	20.0	4	43.5	105	¥98,700

G(55°) 油穴付 超硬ソリッドミルスレッド

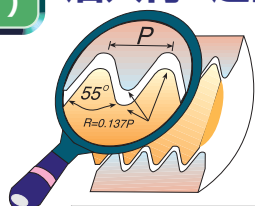


ウィットねじ・内外径共用

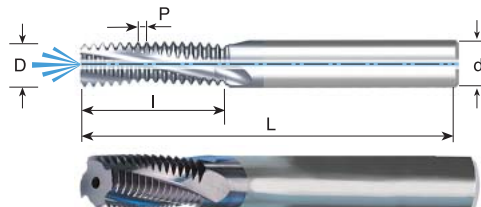


山数/ インチ	Standard	型番	d mm	D mm	刃数	l mm	L mm	価格
28	G 1/8	B08078C14 28W	8	7.8	3	14.1	64	¥40,000
19	G 1/4-3/8	B1010D16 19W	10	10.0	4	16.7	73	¥45,600
14	G 1/2-7/8	B1616E26 14W	16	16.0	5	26.3	105	¥68,400
11	G ≥ 1	B1616D38 11W	16	16.0	4	38.1	105	¥68,400
11	G ≥ 1	B2020E47 11W	20	20.0	5	47.3	105	¥98,700

BSPT 油穴付 超硬ソリッドミルスレッド

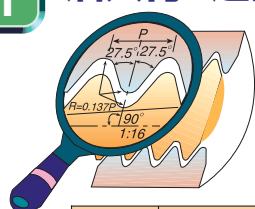

BSPTねじ・内外径共用

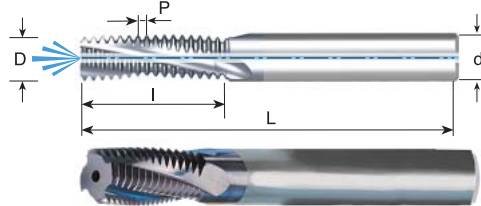

山数/ インチ	Standard	型番	d mm	D mm	刃数	l mm	L mm	価格
28	RC1/8	B08078C14 28 BSPT	8	7.8	3	14.1	64	¥40,000
19	RC1/4-3/8	B1010D16 19 BSPT	10	10.0	4	16.7	73	¥45,600
14	RC1/2-7/8	B1616E26 14 BSPT	16	16.0	5	26.3	105	¥68,400
11	RC1-2	B1616D28 11 BSPT	16	16.0	4	28.9	105	¥68,400

ピンク色の型番表示は、ノガ・ジャパン在庫品です。