



**NPS** 油穴付 超硬ソリッドミルスレッド **新発売**

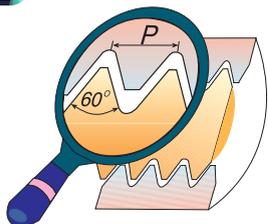

内外径共用・インチシャンク

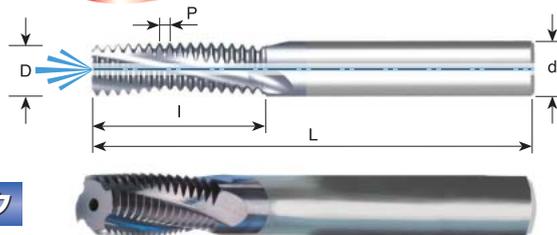


ピッチ 山数/インチ	標準	型番	d インチ	D mm	刃数	I mm	L mm	価格
27	1/8	B0312C04 27 NPS	5/16	7.6	3	10.8	63	¥40,000
18	1/4-3/8	B0375D06 18 NPS	3/8	9.5	4	16.2	76	¥45,600
14	1/2-3/4	B0625D08 14 NPS	5/8	15.5	4	22.7	101	¥68,400
11.5	1-2	B0750D11 11.5 NPS	3/4	19.0	4	29.8	101	¥98,700

**NPSF** 油穴付 超硬ソリッドミルスレッド **新発売**




内外径共用・インチシャンク

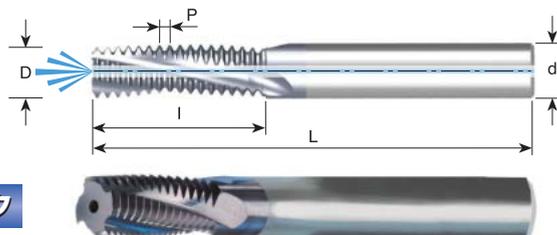


ピッチ 山数/インチ	標準	型番	d インチ	D mm	刃数	I mm	L mm	価格
27	1/8	B0312C04 27 NPSF	5/16	7.6	3	10.8	63	¥40,000
18	1/4-3/8	B0375D06 18 NPSF	3/8	9.5	4	16.2	76	¥45,600
14	1/2-3/4	B0625D08 14 NPSF	5/8	15.5	4	22.7	101	¥68,400
11.5	1-2	B0750D11 11.5 NP(S)F	3/4	19.0	4	29.8	101	¥98,700

**PG** DIN 40430 油穴付 超硬ソリッドミルスレッド **新発売**

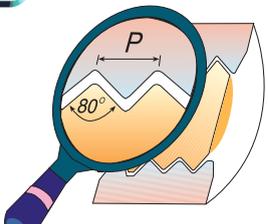

内外径共用

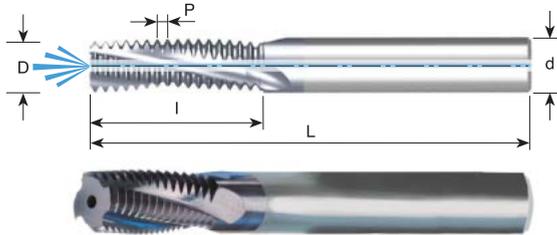

ピッチ 山数/インチ	標準	型番	d mm	D mm	刃数	I mm	L mm	価格
20	Pg7	B1010D19 20PG	10	10.0	4	19.7	73	¥45,600
18	Pg9, 11, 13.5, 16	B1212D20 18PG	12	12.0	4	20.5	84	¥52,000
16	Pg21, 29, 36, 42, 48	B1212D23 16PG	12	12.0	4	23.0	84	¥52,000