


# フリーアングルⅡ

## FREE-ANGLE Ⅱ

### 固定プラグタイプ FIXED TYPE




型式 Model	A	φC	φF	二面幅 Spanner Flats H	L	S	T	重量 Weight (g)
FA2S-2M-P	75.0	17	5.0	14	69.0	11	R1/4	32.0
FA2L-2M-P	87.0	22	7.5	19	81.0	11	R1/4	49.6
FA2L-3M-P	88.0	22	7.5	19	81.6	12	R3/8	56.0

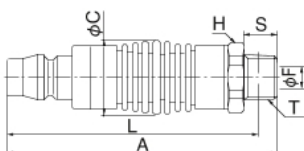

### 回転プラグタイプ ROTATION PLUG TYPE



型式 Model	A	φC	φF	二面幅 Spanner Flats H	L	S	T	重量 Weight (g)
FA2S-2M-PU	89.0	17	5.0	14	83.0	11	R1/4	43.0
FA2L-2M-PU	98.7	22	7.5	19	92.7	11	R1/4	62.8
FA2L-3M-PU	99.7	22	7.5	19	93.3	12	R3/8	70.8

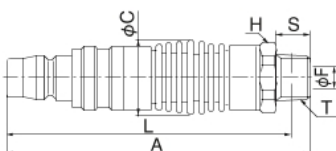

### 回転金具タイプ ROTATION HOSE FITTING TYPE



型式 Model	A	B	φC	φD	E	φF	二面幅 Spanner Flats H			J	L	S	T (T1)	T2	重量 Weight (g)
							H1	H2	H3						
FA2S-2M-5HU	88.0	-	17	5×8	15.0	4.0	14	14	14	-	82.0	11	R1/4	-	53.5
FA2S-2M-6.5HU	90.5	-	17	6.5×10	17.5	4.0	14	17	16	-	84.5	11	R1/4	-	62.7
FA2S-2M-G2FU	79.0	11.0	17	-	-	4.0	14	17	-	9.0	73.0	11	R1/4	G1/4	44.0
FA2L-3M-3FU	93.2	14.0	22	-	-	6.5	19	21	-	12	86.8	12	R3/8	Rc3/8	84.2
FA2L-2M-6.5HU	100.7	-	22	6.5×10	17.5	7.5	19	17	16	-	94.7	11	R1/4	-	86.0
FA2L-2M-8HU	103.2	-	22	8×12	20.0	7.5	19	19	19	-	97.2	11	R1/4	-	96.0
FA2L-3M-8HU	104.2	-	22	8×12	20.0	7.5	19	19	19	-	97.8	12	R3/8	-	102.0
FA2L-2M-G2FU	89.2	11	22	-	-	7.5	19	17	-	9	83.2	11	R1/4	G1/4	66.0

