


ソリッドエンドミル OCFS4-S形

- 4枚刃、標準刃長
ねじれ角30°、コーナC面付き



ソリッドエンドミル OCFS4-L形


- 4枚刃、ロング刃長
ねじれ角30°、コーナC面付き

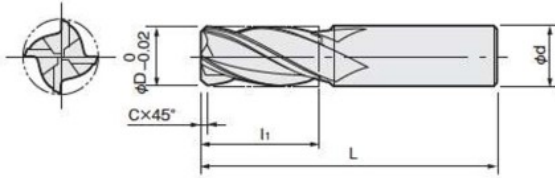

材種: ノンコート超微粒子超硬合金

形番 Cat. No.	在庫 Stock	寸法 (mm) Dimensions (mm)				
		φD	li	L	φd	C
OCFS4-030S	□	3	10	45	6	0.1
OCFS4-035S	□	3.5	11	45	6	0.1
OCFS4-040S	□	4	12	45	6	0.1
OCFS4-045S	□	4.5	14	45	6	0.1
OCFS4-050S	□	5	15	50	6	0.1
OCFS4-055S	□	5.5	15	50	6	0.2
OCFS4-060S	□	6	15	50	6	0.2
OCFS4-065S	□	6.5	15	50	6	0.2
OCFS4-070S	□	7	20	60	8	0.2
OCFS4-075S	□	7.5	20	60	8	0.2
OCFS4-080S	□	8	20	60	8	0.2
OCFS4-085S	□	8.5	20	60	8	0.2
OCFS4-090S	□	9	20	65	10	0.2
OCFS4-095S	□	9.5	20	65	10	0.2
OCFS4-100S	□	10	25	70	10	0.2
OCFS4-105S	□	10.5	25	70	10	0.2
OCFS4-110S	□	11	25	75	12	0.2
OCFS4-115S	□	11.5	25	75	12	0.2
OCFS4-120S	□	12	25	75	12	0.2
OCFS4-125S	□	12.5	30	80	12	0.2
OCFS4-130S	□	13	30	80	12	0.2
OCFS4-135S	□	13.5	35	90	16	0.2
OCFS4-140S	□	14	35	90	16	0.2
OCFS4-145S	□	14.5	35	90	16	0.2
OCFS4-150S	□	15	35	90	16	0.2
OCFS4-155S	□	15.5	35	90	16	0.3
OCFS4-160S	□	16	35	90	16	0.3
OCFS4-165S	□	16.5	40	105	20	0.3
OCFS4-170S	□	17	40	105	20	0.3
OCFS4-175S	□	17.5	40	105	20	0.3
OCFS4-180S	□	18	40	105	20	0.3
OCFS4-185S	□	18.5	40	105	20	0.4
OCFS4-190S	□	19	40	105	20	0.4
OCFS4-195S	□	19.5	40	105	20	0.5
OCFS4-200S	□	20	40	105	20	0.5
OCFS4-210S	□	21	50	120	25	0.5
OCFS4-220S	□	22	50	120	25	0.5
OCFS4-230S	□	23	50	120	25	0.5
OCFS4-240S	□	24	50	120	25	0.5
OCFS4-250S	□	25	50	120	25	0.5
OCFS4-260S	□	26	50	120	25	0.5
OCFS4-270S	□	27	50	120	25	0.5
OCFS4-280S	□	28	60	130	25	0.5
OCFS4-290S	□	29	60	130	25	0.5
OCFS4-300S	□	30	60	130	32	0.5

3541

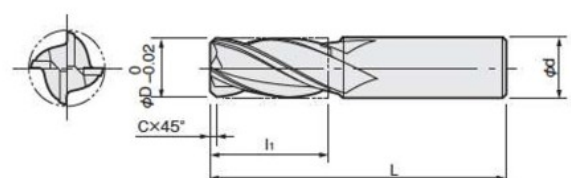

材種: ノンコート超微粒子超硬合金

形番 Cat. No.	在庫 Stock	寸法 (mm) Dimensions (mm)				
		φD	li	L	φd	C
OCFS4-030L	□	3	20	60	6	0.1
OCFS4-035L	□	3.5	22	60	6	0.1
OCFS4-040L	□	4	24	60	6	0.1
OCFS4-045L	□	4.5	28	60	6	0.1
OCFS4-050L	□	5	30	70	6	0.1
OCFS4-055L	□	5.5	30	70	6	0.2
OCFS4-060L	□	6	30	70	6	0.2
OCFS4-065L	□	6.5	40	90	8	0.2
OCFS4-070L	□	7	40	90	8	0.2
OCFS4-075L	□	7.5	40	90	8	0.2
OCFS4-080L	□	8	40	90	8	0.2
OCFS4-085L	□	8.5	40	100	10	0.2
OCFS4-090L	□	9	40	100	10	0.2
OCFS4-095L	□	9.5	40	100	10	0.2
OCFS4-100L	□	10	50	110	10	0.2
OCFS4-105L	□	10.5	50	110	12	0.2
OCFS4-110L	□	11	50	110	12	0.2
OCFS4-115L	□	11.5	50	110	12	0.2
OCFS4-120L	□	12	50	110	12	0.2
OCFS4-125L	□	12.5	60	120	12	0.2
OCFS4-130L	□	13	60	120	12	0.2
OCFS4-135L	□	13.5	70	130	16	0.2
OCFS4-140L	□	14	70	130	16	0.2
OCFS4-145L	□	14.5	70	130	16	0.2
OCFS4-150L	□	15	70	130	16	0.2
OCFS4-155L	□	15.5	70	130	16	0.3
OCFS4-160L	□	16	70	130	16	0.3
OCFS4-165L	□	16.5	70	140	20	0.3
OCFS4-170L	□	17	70	140	20	0.3
OCFS4-175L	□	17.5	70	140	20	0.3
OCFS4-180L	□	18	70	140	20	0.3
OCFS4-185L	□	18.5	70	140	20	0.4
OCFS4-190L	□	19	70	140	20	0.4
OCFS4-195L	□	19.5	70	140	20	0.5
OCFS4-200L	□	20	70	140	20	0.5
OCFS4-210L	□	21	80	150	25	0.5
OCFS4-220L	□	22	80	150	25	0.5
OCFS4-230L	□	23	80	150	25	0.5
OCFS4-240L	□	24	80	150	25	0.5
OCFS4-250L	□	25	80	150	25	0.5

2514