


●EZハードドリル ロングシャンクタイプ

- 高硬度材加工用ソリッドドリル
- 有効加工穴深さ5×Dc
- ねじれ角15°
- ロングシャンク

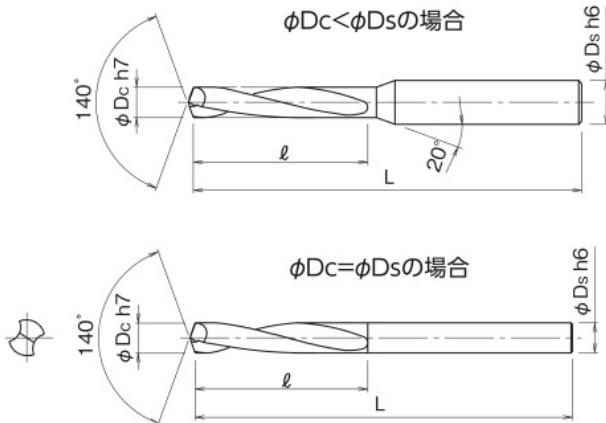

●直径寸法許容差 (mm)

直径φDc	許容差
3以下	0 -0.01
3をこえ6以下	0 -0.012
6をこえ10以下	0 -0.015
10をこえ18以下	0 -0.018

形番	在庫	寸法 (mm)				標準価格 (円)
		φDc	ℓ	L	φDs	
EZH5D0300S04-LS	●	3	25	69	4	8,130
EZH5D0310S04-LS	■	3.1	25	69	4	-
EZH5D0320S04-LS	■	3.2	25	69	4	-
EZH5D0330S04-LS	●	3.3	25	79	4	8,780
EZH5D0340S04-LS	■	3.4	25	79	4	-
EZH5D0350S04-LS	■	3.5	25	79	4	-
EZH5D0360S04-LS	■	3.6	30	79	4	-
EZH5D0370S04-LS	■	3.7	30	79	4	-
EZH5D0380S04-LS	●	3.8	30	79	4	9,500
EZH5D0390S04-LS	■	3.9	30	79	4	-
EZH5D0400S04-LS	●	4	30	79	4	9,500

形番	在庫	寸法 (mm)				標準価格 (円)
		φDc	ℓ	L	φDs	
EZH5D0410S05-LS	■	4.1	30	85	5	-
EZH5D0420S05-LS	■	4.2	30	85	5	-
EZH5D0430S05-LS	■	4.3	30	85	5	-
EZH5D0440S05-LS	■	4.4	30	85	5	-
EZH5D0450S05-LS	■	4.5	30	85	5	-
EZH5D0460S05-LS	■	4.6	35	85	5	-
EZH5D0470S05-LS	■	4.7	35	85	5	-
EZH5D0480S05-LS	■	4.8	35	85	5	-
EZH5D0490S05-LS	■	4.9	35	85	5	-
EZH5D0500S05-LS	■	5	35	85	5	-

●:メーカー在庫 ■:特定代理店在庫

特殊品対応及び、再研削再コート対応致します。
詳細は弊社営業所までお問い合わせください。