


バックングプレート/シムプレート



RoHS 10 **URBP** (バックングプレート)
URSP (シムプレート)

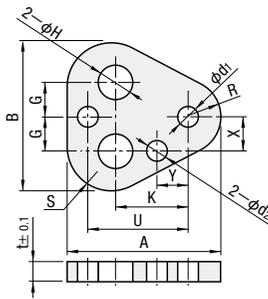

適用リテーナー: **ART・ARTS・ARTST**
SRT・SRTS・SRTSH
ARTF・ARTFS

バックングプレート (URBP)	
厚み記号	t
48	4.8
60	6.0
80	8.0
100	10.0

シムプレート (URSP)	
厚み記号	t
18	1.8

☑ 材質 SCM440相当
☑ 硬度 56~60HRC
(シムプレートは焼入れなし)

型式		A	U	K	B	G	Y	X	S	H	R	d ₁	d ₂
Type	D												
URBP (バックングプレート)	10	44.5	26.925	19.0	43.7	11.1	7.5	9.0	12.0	10	9.5	6.2	7.0
	13	50.8	29.970	19.0	50.0	14.3	6.5	12.0	15.2	10	12.7	6.2	7.0
	16	54.0	31.750	19.0	53.2	15.9	6.0	13.5	16.8	10	14.3	6.2	7.0
URSP (シムプレート)	20	60.3	33.530	19.0	59.5	17.5	5.0	16.5	20.0	12	17.5	6.2	7.0
	25	69.9	40.640	23.8	69.1	19.8	7.0	22.0	24.7	14	22.2	6.2	7.0
	32	69.9	40.640	23.8	69.1	19.8	7.0	22.0	24.7	14	22.2	6.2	7.0



Order
注文例

型式 — 厚み記号

URBP13 — **48**




Delivery
出荷日

 在庫品



RoHS 10 **JRBP** (バックングプレート)
JRSP (シムプレート)

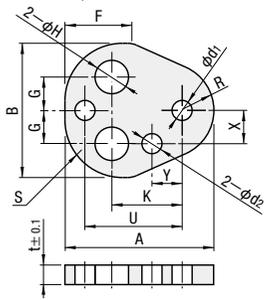

適用リテーナー: **JRT・JRTS・JRTST**
JRTF・JRTFS

バックングプレート (JRBP)	
厚み記号	t
48	4.8
60	6.0
80	8.0
100	10.0

シムプレート (JRSP)	
厚み記号	t
18	1.8

☑ 材質 SCM440相当
☑ 硬度 56~60HRC
(シムプレートは焼入れなし)

型式		A	U	K	B	G	F	Y	X	S	H	R	d ₁	d ₂
Type	D													
JRBP (バックングプレート)	10	44.3	27.0	19.0	40.0	11.1	17.0	7.5	9.0	17.0	10	9.5	6.2	6.4
	13	50.4	30.0	19.0	47.0	14.3	20.0	6.5	12.0	20.0	10	12.6	6.2	6.4
	16	53.5	31.8	19.0	50.0	15.9	22.5	6.0	13.5	21.0	10	14.1	6.2	6.4
	20	60.1	33.5	19.0	55.0	17.5	27.5	5.0	16.5	24.0	12	17.4	6.2	6.4
JRSP (シムプレート)	25	69.7	40.6	24.0	63.0	19.8	31.5	7.0	22.0	27.0	15	22.2	6.2	6.4
	32	69.7	40.6	24.0	63.0	19.8	31.5	7.0	22.0	27.0	15	22.2	6.2	6.4
	38	77.4	44.0	27.0	72.0	24.0	40.0	10.0	26.0	28.0	15	26.0	10.2	6.4
	45	81.4	44.0	27.0	78.0	24.0	42.0	10.0	30.0	35.0	15	30.0	10.2	6.4



Order
注文例

型式 — 厚み記号

JRSP13 — **18**



Delivery
出荷日

 在庫品

プレスマット・ハブナー・摩板
打ち抜き用リテーナー