


銅線用絶縁被覆付圧着端子 丸形端子 (RBV形) (RBP形)

JIS JQ0608003

UL E74917

SF LR66230

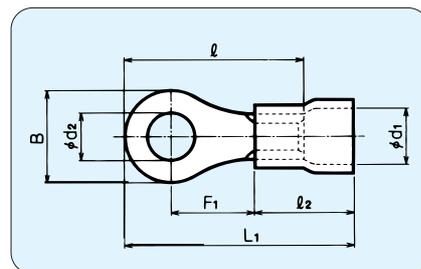

◆拡管形

RoHS 指令対応品

呼 び		呼 び		各 部 の 寸 法								標準色	適合電線範囲		適合工具	一箱入数
規 格	ビニル	規 格	ナイロン	φd ₂	B	φd ₁	F ₁	l ₂	l	L ₁	板厚		撚線mm ²	AWG		
	RBV0.08-3		-	3.2	5.2	3.2	5.9	9.0	12.5	17.5	0.8	黄	0.08	28	DS05N DH-1B	1,000 (100×10)
	RBV0.08-M3.5		-	3.7	5.5		7.7		14.5	19.5						
	RBV0.3-2		-	2.2	5.2	3.2	5.9	9.0	12.5	17.5	0.65	黄	0.1 ∩ 0.3	26-24	DS05N DH-1B AC-5N-D	1,000 (100×10)
	RBV0.3-3		-	3.2												
	RBV0.3-3.5		-	3.7												
	RBV0.3-4		-	4.3												
	RBV0.5-2		-	2.2	5.2	3.2	5.9	9.0	12.5	17.5	0.5	黄	0.3 ∩ 0.5	22-20	DS05N DH-1B AC-5N-D	1,000 (100×10)
	RBV0.5-3		-	3.2												
	RBV0.5-3.5		-	3.7												
	RBV0.5-4		-	4.3												
	RBV0.5-5		-	5.3												
	RBV1.25-2		RBP1.25-2	2.5	5.5	4.1 (4.0)	4.8	9.0	12.0	16.5	0.8	赤	0.5 ∩ 1.65	20-16	3号 D 34号 34S DH-1B AC-5N-D	500 (100×5)
	RBV1.25-3		RBP1.25-3	3.2			6.6		13.8	18.3						
	RBV1.25-M3		RBP1.25-M3	6.6			14.4		18.9							
	RBV1.25-V3		RBP1.25-V3	8.0			7.5		15.5	20.0						
	RBV1.25-L3		RBP1.25-L3	4.8			12.0		16.5							
	RBV1.25-S3.5		RBP1.25-S3.5	5.5			13.8		18.3							
	RBV1.25-M3.5		RBP1.25-M3.5	6.6			14.4		18.9							
	RBV1.25-3.5		RBP1.25-3.5	4.3			7.5		15.5	20.0						
	RBV1.25-S4		RBP1.25-S4	8.0			18.5		23.0							
	RBV1.25-4		RBP1.25-4	5.3			10.0		20.2	24.7						
	RBV1.25-5		RBP1.25-5	6.4			11.5		21.8	26.3						
	RBV1.25-L5		RBP1.25-L5	8.4			13.6		29.5	34.0						
	RBV1.25-6		RBP1.25-6	6.4	11.5	10.5	21.8	26.3								
	RBV1.25-8		RBP1.25-8	8.4	11.5	10.5	21.8	26.3								
	RBV1.25-10		RBP1.25-10	10.5	13.6	14.0	29.5	34.0								
	RBV1.25-12		RBP1.25-12	13.0	22.0	14.0	29.5	34.0								
	RBV2-3		RBP2-3	3.2	6.6	4.7 (4.5)	5.2	9.0	13.0	17.5	0.8	青	1.04 ∩ 2.63	16-14	4号 D 34号 34S DH-1B AC-5N-D	500 (100×5)
	RBV2-M3		RBP2-M3	5.5			12.4		16.9							
	RBV2-L3		RBP2-L3	6.5			13.7		18.2							
	RBV2-M3.5		RBP2-M3.5	5.8			13.9		18.4							
	RBV2-3.5		RBP2-3.5	3.7			5.2		13.0	17.5						
	RBV2-L 3.5		RBP2-L3.5	6.6			8.3		16.0	20.5						
	RBV2-M4		RBP2-M4	6.5			14.3		18.8							
	RBV2-S4		RBP2-S4	4.3			8.3		16.0	20.5						
	RBV2-4		RBP2-4	8.5			7.8		16.5	21.0						
	RBV2-S5		RBP2-S5	5.3			9.5		17.0	21.5						
	RBV2-L 5		RBP2-L 5	6.4			12.0		21.5	26.0						
	RBV2-6		RBP2-6	6.4			12.0		11.0	21.5						
	RBV2-8		RBP2-8	8.4	18.0	14.0	27.5	32.0								
	RBV2-A8		RBP2-A8	16.0	16.0	16.0	28.5	33.0								
	RBV2-B8		RBP2-B8	14.5	12.3	12.3	24.0	28.5								
	RBV2-10		RBP2-10	10.5	18.0	14.0	27.5	32.0								
	RBV2-A10		RBP2-A10	20.0	18.0	18.0	32.5	37.0								
	RBV2-B10		RBP2-B10	17.0	13.9	13.9	26.9	31.4								
	RBV2-12		RBP2-12	13.0	17.0	14.0	29.5	34.0								
	RBV2-A12		RBP2-A12	22.0	22.0	14.0	29.5	34.0								

1. 各呼びの印は、JIS規格品、UL登録品、CSA登録品です。
2. CSA登録品としてご使用の際は、注文時にご指示ください。カートンがCSA品用となります。
3. 上記寸法表にかぎらず特注品もご相談ください。()はRBP形の寸法です。