


パイロット付ザグリカッター ストレートシャンク Counterbore With Straight Shank

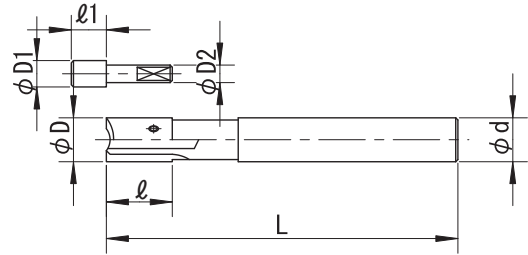

右刃右ネジレ12° 刃数:3 SKH51
Helix Angle-Right12° 3 Flutes HSS

公差(Tolerance)	D : $^{+0.2}_0$	D1 : $^0_{-0.05}$	d : h7
---------------	-----------------	-------------------	--------

刃径 (φD)	案内径 (φD1)	案内軸 (φD2)	案内長 (ℓ1)	刃長 (ℓ)	全長 (L)	シャンク径 (φd)
Dia.	Guide Dia.	Shank Dia. of Guide	Length of Guide	Length of Cut	Overall Length	Shank Dia.
6	3	2.5	5	15	70	6
7	4	3	5	15	70	6
8	4.5	3	5	15	80	8
9	4.5	3	5	15	80	8
	5.5	3	5	15	80	8
10	5.5	4	8	15	80	10
	6	4	8	15	80	10
11	6.8	4	8	15	80	10
12	6.8	5	10	20	90	10
	7.7	5	10	20	90	10
13	8.3	5	10	20	90	12
14	8.8	5	10	25	105	12
15	10.2	5	10	25	105	12
16	10.5	6	10	25	105	12
17	8.8	6	10	25	110	12
	10.5	6	10	25	110	12
	12	6	10	25	110	12
18	6.8	6	10	25	110	12
	8.8	6	10	25	110	12
	13	6	10	25	110	12

刃径 (φD)	案内径 (φD1)	案内軸 (φD2)	案内長 (ℓ1)	刃長 (ℓ)	全長 (L)	シャンク径 (φd)
Dia.	Guide Dia.	Shank Dia. of Guide	Length of Guide	Length of Cut	Overall Length	Shank Dia.
19	13	6	10	30	115	12
	13.7	6	10	30	115	12
20	8.8	6	10	30	120	12
	10.2	6	10	30	120	12
	10.5	6	10	30	120	12
21	14	6	10	30	120	12
	14	6	10	30	120	12
22	10.2	6	10	30	120	12
	14	6	10	30	120	12
23	12	8	12	35	135	12
	15	8	12	35	135	12
24	16	8	12	35	135	12
	16	8	12	35	135	12
25	10.2	8	12	35	135	12
	13	8	12	35	135	12
	13.7	8	12	35	135	12
26	17	8	12	35	135	12
	18	8	12	35	135	12
27	19	8	12	35	135	12
28	15	8	12	40	150	12
	21	8	12	40	150	12

※別売り パイロットのみ有り (P227)