


EA614B-5.5-46 片目片口スパナ

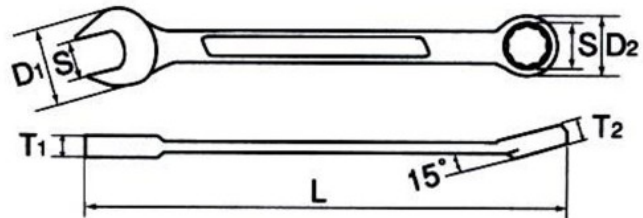

	S	D1	D2	T1	T2	L	▼g
EA614B-5.5	5.5	13	9.5	3	4.5	88	13
-6	6	14	10	3	4.5	90	14
-7	7	16	11	3.5	5	95	20
-8	8	18	13	4	5.5	105	28
-9	9	20	14	4.5	6	110	36
-10	10	21	16	4.5	6.5	120	40
-11	11	24	17	5	7	140	50
-12	12	26	18	5.5	7.5	145	60
-13	13	27	19	6	8.5	155	70
-14	14	30	21	6	9.5	175	90
-15	15	32	23	7	10	185	100
-16	16	34	24	6.5	9.5	200	120
-17	17	36	25	7	10.5	215	160
-18	18	38	27	8	11.5	230	165
-19	19	40	27	7.5	12	245	200
-20	20	42	30	8	12	260	220
-21	21	44	30	8	13	275	260
-22	22	46	32	8.5	13.5	290	295
-23	23	48	34	8.5	14.5	300	320
-24	24	50	35	9	15	315	355
-25	25	52	36	9.5	15.5	335	390
-26	26	54	38	9	16	350	465
-27	27	56	39	9	16.5	370	510
-28	28	58	41	9.5	17	380	555
-29	29	60	42	10.5	17	400	580
-30	30	62	44	10	18	420	720
-32	32	66	47	10.5	18	445	800
取り扱い中止	35	72	51	12.5	21	475	1080
取り扱い中止	38	77	55	13	22.5	495	1350
-41	41	84	59	14	24.5	520	1630
-46	46	94	66	14	26	560	2070