



New
QSY-1/2-10

ワンタッチコネクタ QS (スタンダード)

テクニカルデータ

FESTO

ブランチワイ QSY

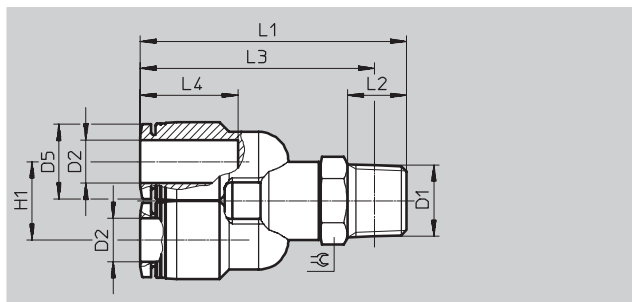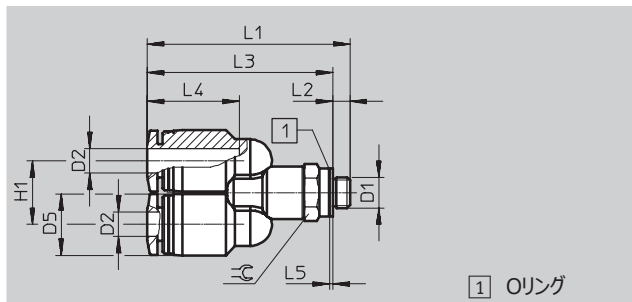

外形寸法と型式データ

接続ポート径	有効径	チューブ外径	D5	H1	L1	L2	L3	L4	L5	質量	製品番号	型式	PU ¹⁾	
D1	[mm]	D2	∅							[g]				
メートルねじ (Oリング付)														
M5	2.4	4	10	10.3	32.9	2.8	30.1	14.9	0.5	8	8	★190673	QSY-M5-4	10
	2.4	6	12.5	12.5	38.3	2.8	35.5	17	0.5	10	13	★190674	QSY-M5-6	10
Rねじ														
R1/8	3.1	4	10	10.3	38.4	8	34.4	14.9	-	10	13	★153138	QSY-1/8-4	10
	4.2	6	12.5	12.5	41.3	8	37.3	17	-	10	15	★153139	QSY-1/8-6	10
	5.9	8	14.5	14.5	46.1	8	42.1	18.1	-	12	20	★153141	QSY-1/8-8	10
R1/4	3.3	4	10	10.3	43.4	11	37.4	14.9	-	14	20	★190675	QSY-1/4-4	10
	4.8	6	12.5	12.5	48.3	11	42.2	17	-	14	22	★153140	QSY-1/4-6	10
	6.2	8	14.5	14.5	49.3	11	43.3	18.1	-	14	25	★153142	QSY-1/4-8	10
R3/8	7.2	10	17.5	17.5	53.6	11	47.6	20.2	-	14	32	★153144	QSY-1/4-10	10
	6.6	8	14.5	14.5	52.5	12	46.2	18.1	-	17	36	★153143	QSY-3/8-8	10
	7.4	10	17.5	17.5	56.7	12	50.4	20.2	-	17	43	★153145	QSY-3/8-10	10
R1/2	8.4	12	21	21	60.6	12	54.3	23.4	-	17	51	★153146	QSY-3/8-12	10
	7.8	10	17.5	17.5	60.2	15	52	20.2	-	21	66	133196	QSY-1/2-10	1
	8.3	12	21	21	64.7	15	56.5	23.4	-	21	74	★153147	QSY-1/2-12	1

1) 最少販売単位

Festo core product range

★受注後、24時間以内に出荷可能
☆在庫から5日以内に出荷可能