



異径ストレートユニオン

F

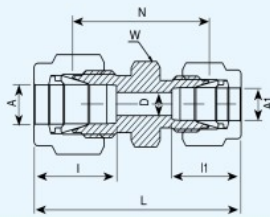

熱電対対応品

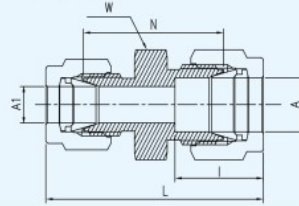

ニュー・ロック 継手 異径ストレートユニオン

チューブ(ミリサイズ)

品番	A	A1	D	W	N	L	I	I1
	呼び径	呼び径						
	mm	mm	mm	mm	mm	mm	mm	mm
VUWF-3X2-V	3	2	1.7	12	22.1	35.3	12.9	12.9
VUWF-4X3-V	4	3	2.3	12	23.9	37.1	13.7	12.9
VUWF-6X2-V	6	2	1.7	14	24.6	38.6	15.3	12.9
VUWF-6X3-V	6	3	2.3	14	24.6	38.6	15.3	12.9
VUWF-6X4-V	6	4	2.3	14	25.4	39.4	15.3	13.7
VUWF-8X4-V	8	4	2.4	15	26.6	40.7	16.2	13.7
VUWF-8X6-V	8	6	4.8	15	27.4	42.3	16.2	15.3
VUWF-10X6-V	10	6	4.8	18	29.5	44.5	17.2	15.3
VUWF-10X8-V	10	8	6.4	18	30	45.1	17.2	16.2
VUWF-12X3-V	12	3	2.4	22	28.5	45.2	22.8	12.9
VUWF-12X6-V	12	6	4.8	22	29.5	47	22.8	15.3
VUWF-12X8-V	12	8	6.4	22	30.2	47.8	22.8	16.2
VUWF-12X10-V	12	10	7.9	22	31	48.7	22.8	17.2
VUWF-14X8-V	14	8	6.4	24	31.8	49.4	24.4	16.2
VUWF-14X12-V	14	12	9.5	24	31.8	52	24.4	22.8
VUWF-16X10-V	16	10	7.9	24	31.8	49.5	24.4	17.2
VUWF-16X12-V	16	12	9.5	24	31.8	52	24.4	22.8
VUWF-18X12-V	18	12	9.5	27	33.3	53.5	24.4	22.8
VUWF-25X18-V	25	18	15.1	35	38.6	60.9	31.3	24.4
VUWF-25X20-V	25	20	15.9	35	39.9	62.2	31.3	26

チューブ(ミリサイズ)とチューブ(インチサイズ)

品番	A		D	W	N	L	I	I1	
	呼び径								
	mm	in							
VUWF-2X1.6-V	2	1/16	1.58	1.3	12	20.6	31	12.9	8.6
VUWF-3.2X2-V	2	1/8	3.17	1.7	12	22	35.2	12.9	12.7
VUWF-3.2X3-V	3	1/8	3.17	2.3	12	22.1	35.3	12.9	12.7
VUWF-4X1.6-V	4	1/16	1.58	1.3	12	21.9	32.3	13.7	8.6
VUWF-4X3.2-V	4	1/8	3.17	2.4	12	23.4	36.6	13.7	12.7
VUWF-6X3.2-V	6	1/8	3.17	2.4	14	24.6	38.5	15.3	12.7
VUWF-6.35X2-V	2	1/4	6.35	1.7	14	24.6	38.6	12.9	15.2
VUWF-6.35X3-V	3	1/4	6.35	2.4	14	24.6	38.6	12.9	15.2
VUWF-6.35X4-V	4	1/4	6.35	2.4	14	25.4	39.4	13.7	15.2
VUWF-6.35X6-V	6	1/4	6.35	4.8	14	26.2	41	15.3	15.2
VUWF-7.93X6-V	6	5/16	7.93	4.8	14	27.4	42.2	15.3	16.3
VUWF-8X3.2-V	8	1/8	3.17	2.3	15	25.7	39.8	16.2	12.7
VUWF-8X6.35-V	8	1/4	6.35	4.8	15	27.4	42.3	16.2	15.2
VUWF-9.52X3-V	3	3/8	9.52	2.4	16	26.9	40.9	16.8	12.9
VUWF-9.52X6-V	6	3/8	9.52	4.8	16	29.5	44.3	15.3	16.8
VUWF-9.52X8-V	8	3/8	9.52	6.4	16	29.5	44.4	16.2	16.8
VUWF-10X3.2-V	10	1/8	3.17	2.3	18	27.7	41.9	17.2	12.7
VUWF-10X6.35-V	10	1/4	6.35	4.8	18	29.5	44.5	17.2	15.2
VUWF-10X7.93-V	10	5/16	7.93	6.4	18	30	45	17.2	16.3
VUWF-10X9.52-V	10	3/8	9.52	7.1	18	31	46	17.2	16.8
VUWF-12X6.35-V	12	1/4	6.35	4.8	22	29.5	47	22.8	15.2
VUWF-12X7.93-V	12	5/16	7.93	6.4	22	30.2	47.7	22.8	16.3
VUWF-12X9.52-V	12	3/8	9.52	7.1	22	31	48.5	22.8	16.8
VUWF-12.7X6-V	6	1/2	12.7	4.8	22	30	47.5	15.3	22.9
VUWF-12.7X8-V	8	1/2	12.7	6.4	22	31	48.6	22.9	16.2
VUWF-12.7X10-V	10	1/2	12.7	7.9	22	31	48.7	17.2	22.9
VUWF-12.7X12-V	12	1/2	12.7	9.5	22	31	51.2	22.8	22.9
VUWF-14X12.7-V	14	1/2	12.7	10.4	24	31.8	52	24.4	22.9
VUWF-15X12.7-V	15	1/2	12.7	10.4	24	31.8	52	24.4	22.9
VUWF-16X15.88-V	16	5/8	15.87	12.7	24	31.8	52	24.4	24.4
VUWF-19.05X18-V	18	3/4	19.05	15.1	27	33.3	53.5	24.4	24.4
VUWF-25.4X25-V	25	1	25.4	21.8	35	40.4	64.8	31.3	31.2

熱電対用タイプも製作できます。

ご注文の際は、選定した継手の品番の最後に-T/Cを付けて下さい。

*D・寸法は最小孔径です。*技術の進歩のために使用材料、寸法など予告なく多少変更することがありますのであらかじめご了承下さい。