


ティーゲージユニオン(NPT)

TG

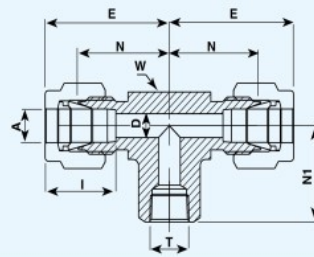

チューブ(ミリサイズ)とNPTめねじ

品番	A 呼び径		T	D		W		N		E		N1		I
	mm			mm	in	mm	mm	mm	mm	mm	mm	mm		
VUWTG-6AN-V	6		1/8NPT	4.8	5/8	15.9	19.6	27	19	15.3				
VUWTG-6BN-V	6		1/4NPT	4.8	13/16	20.6	22.4	29.8	22.4	15.3				
VUWTG-8BN-V	8		1/4NPT	6.4	13/16	20.6	23.1	30.6	22.4	16.2				
VUWTG-10BN-V	10		1/4NPT	7.9	13/16	20.6	25.9	33.5	22.4	17.2				
VUWTG-10CN-V	10		3/8NPT	7.9	15/16	23.8	25.9	33.5	22.4	17.2				
VUWTG-12BN-V	12		1/4NPT	9.5	13/16	20.6	25.9	36	22.4	22.8				
VUWTG-12CN-V	12		3/8NPT	9.5	15/16	23.8	25.9	36	22.4	22.8				
VUWTG-12DN-V	12		1/2NPT	9.5	1 1/16	27	28.7	38.8	28.4	22.8				
VUWTG-16DN-V	16		1/2NPT	12.7	1 1/16	27	28.7	38.8	28.4	24.4				

チューブ(インチサイズ)とNPTめねじ

品番	A 呼び径		T	D		W		N		E		N1		I	
	in	mm		in	mm	in	mm	in	mm	in	mm	in	mm		
VUWTG-3.2AN-V	1/8	3.17	1/8NPT	0.09	2.3	5/8	15.9	0.7	18	0.97	24.6	0.75	19.1	0.5	12.7
VUWTG-6.35AN-V	1/4	6.35	1/8NPT	0.19	4.8	5/8	15.9	0.77	19.6	1.06	27	0.75	19.1	0.6	15.2
VUWTG-6.35BN-V	1/4	6.35	1/4NPT	0.19	4.8	13/16	20.6	0.88	22.4	1.17	29.8	0.88	22.4	0.6	15.2
VUWTG-6.35CN-V	1/4	6.35	3/8NPT	0.19	4.8	15/16	23.8	0.96	24.4	1.25	31.8	0.88	22.4	0.6	15.2
VUWTG-9.52BN-V	3/8	9.52	1/4NPT	0.28	7.1	13/16	20.6	0.94	23.9	1.23	31.3	0.88	22.4	0.66	16.8
VUWTG-9.52CN-V	3/8	9.52	3/8NPT	0.28	7.1	15/16	23.8	1.02	25.9	1.31	33.3	0.88	22.4	0.66	16.8
VUWTG-9.52DN-V	3/8	9.52	1/2NPT	0.28	7.1	1 1/16	27	1.13	28.7	1.42	36.1	1.12	28.5	0.66	16.8
VUWTG-12.7BN-V	1/2	12.7	1/4NPT	0.41	10.4	13/16	20.6	1.02	25.9	1.42	36	0.88	22.4	0.9	22.9
VUWTG-12.7CN-V	1/2	12.7	3/8NPT	0.41	10.4	15/16	23.8	1.02	25.9	1.42	36	0.88	22.4	0.9	22.9
VUWTG-12.7DN-V	1/2	12.7	1/2NPT	0.41	10.4	1 1/16	27	1.13	28.7	1.53	38.8	1.12	28.5	0.9	22.9
VUWTG-15.88DN-V	5/8	15.87	1/2NPT	0.5	12.7	1 1/16	27	1.13	28.7	1.53	38.8	1.12	28.5	0.96	24.4
VUWTG-19.05EN-V	3/4	19.05	3/4NPT	0.62	15.8	1 3/8	34.9	1.36	34.5	1.76	44.6	1.25	31.8	0.96	24.4
VUWTG-25.4EN-V	1	25.4	3/4NPT	0.88	22.3	1 3/8	34.9	1.45	36.8	1.93	49	1.25	31.8	1.23	31.2
VUWTG-25.4FN-V	1	25.4	1NPT	0.88	22.3	1 11/16	42.9	1.63	41.4	2.11	53.6	1.5	38.1	1.23	31.2

参照ねじ規格:

アメリカ管用ねじ

NPTねじ(アメリカ管用ねじ)は

ANSI B1.20.1の仕様で製作されています。

※'D' - 寸法は最小穴径です。 ※技術の進歩のために使用材料、寸法など予告なく多少変更することがありますのであらかじめご了承下さい。