
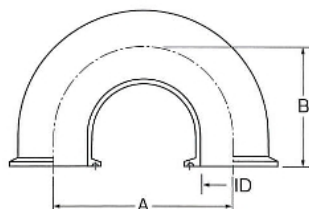




ヘルール継手

ZEU-F ヘルール180° ベンド

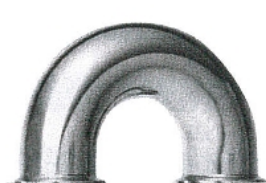


サイズ	ID	A	B
1.5 ^S	35.7	152.4	97.2
2.0 ^S	47.8	152.4	97.2
2.5 ^S	59.5	190.6	116.3
3.0 ^S	72.3	254.0	148.0
4.0 ^S	97.6	254.0	148.0

ZEU-FW ヘルール×溶接180° ベンド

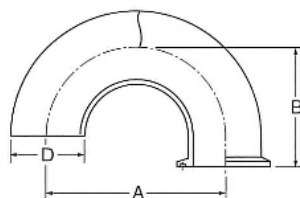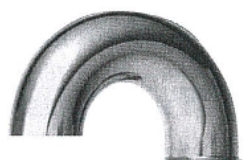

サイズ	D	A	B
1.5 ^S	38.1	152.4	97.2
2.0 ^S	50.8	152.4	97.2
2.5 ^S	63.5	190.6	116.3
3.0 ^S	76.3	254.0	148.0
4.0 ^S	101.6	254.0	148.0

ZRC-F ヘルールレジューサー

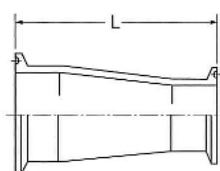

サイズ	L	
	Concentric	Eccentric
1.25 ^S × 1.0 ^S	109	109
1.5 ^S × 1.0 ^S	109	109
1.5 ^S × 1.25 ^S	109	109
2.0 ^S × 1.0 ^S	109	109
2.0 ^S × 1.25 ^S	55	109
2.0 ^S × 1.5 ^S	109	109
2.5 ^S × 1.0 ^S	109	109
2.5 ^S × 1.25 ^S	109	109
2.5 ^S × 1.5 ^S	109	109
2.5 ^S × 2.0 ^S	109	109
3.0 ^S × 1.5 ^S	109	109
3.0 ^S × 2.0 ^S	109	109
3.0 ^S × 2.5 ^S	109	109
4.0 ^S × 2.0 ^S	144	144
4.0 ^S × 2.5 ^S	144	144
4.0 ^S × 3.0 ^S	144	144
4.0 ^S × 3.5 ^S	144	144

ZRE-F ヘルールエキセントレジューサー

