



# ユニオン継手

## ZMS-E エキスパンドシート

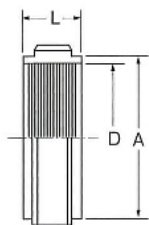


| サイズ              | D    | A    | L    |
|------------------|------|------|------|
| 1.0 <sup>S</sup> | 25.6 | 29.2 | 17.0 |
| 1.5 <sup>S</sup> | 38.3 | 42.5 | 19.5 |
| 2.0 <sup>S</sup> | 51.0 | 56.2 | 19.5 |
| 2.5 <sup>S</sup> | 63.7 | 69.0 | 25.0 |
| 3.0 <sup>S</sup> | 76.5 | 82.0 | 30.0 |

## ZLS-E エキスパンドライナー

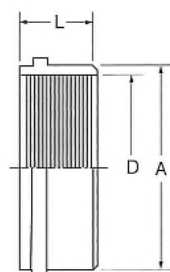


| サイズ              | D    | A    | L    |
|------------------|------|------|------|
| 1.0 <sup>S</sup> | 25.6 | 29.5 | 17.0 |
| 1.5 <sup>S</sup> | 38.3 | 42.5 | 20.0 |
| 2.0 <sup>S</sup> | 51.0 | 56.2 | 20.0 |
| 2.5 <sup>S</sup> | 63.7 | 69.0 | 25.0 |
| 3.0 <sup>S</sup> | 76.5 | 82.0 | 30.0 |

## ZGL パッキン・ガスケット

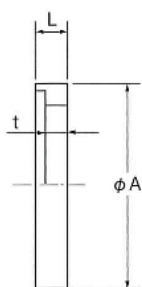

| サイズ              | A     | t   | L   | ガスケット材質                            |
|------------------|-------|-----|-----|------------------------------------|
| 1.0 <sup>S</sup> | 32.5  | 4.0 | 6.0 | <input type="checkbox"/> シリコンゴム    |
| 1.5 <sup>S</sup> | 46.0  | 4.0 | 6.0 | <input type="checkbox"/> NBR       |
| 2.0 <sup>S</sup> | 59.5  | 4.0 | 6.0 | <input type="checkbox"/> EPDM      |
| 2.5 <sup>S</sup> | 73.2  | 4.0 | 6.0 | <input type="checkbox"/> フッ素ゴム     |
| 3.0 <sup>S</sup> | 86.5  | 4.0 | 6.0 | <input type="checkbox"/> PTFE      |
| 4.0 <sup>S</sup> | 112.5 | 4.0 | 6.0 | <input type="checkbox"/> PTFE・SAND |

## ZNH-S 六角ナット

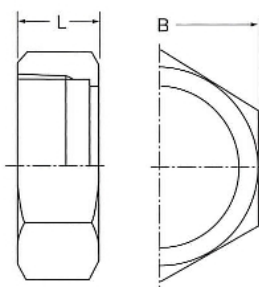

| サイズ              | B   | L  | ZNH-S |
|------------------|-----|----|-------|
| 1.0 <sup>S</sup> | 46  | 30 | —     |
| 1.5 <sup>S</sup> | 56  | 30 | 0.17  |
| 2.0 <sup>S</sup> | 71  | 30 | 0.27  |
| 2.5 <sup>S</sup> | 85  | 30 | 0.35  |
| 3.0 <sup>S</sup> | 100 | 30 | 0.52  |
| 4.0 <sup>S</sup> | 130 | 38 | 1.1   |