


# テークアップ形ユニット

UCT  
円筒穴(止めねじ付き)  
d 12 ~ (60) mm

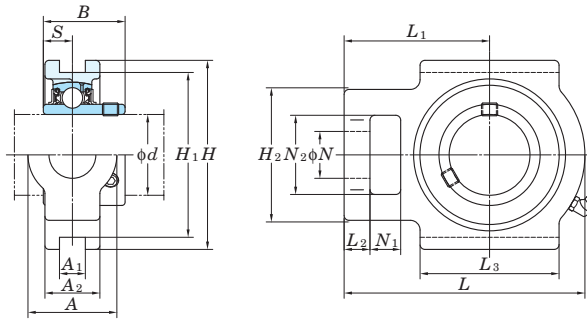

軸径 (mm)	寸 法 (mm)															ユニット 呼び番号	適 用 軸受箱 (普通品)
	A	A <sub>1</sub>	A <sub>2</sub>	H	H <sub>1</sub>	H <sub>2</sub>	L	L <sub>1</sub>	L <sub>2</sub>	L <sub>3</sub>	N	N <sub>1</sub>	N <sub>2</sub>	B	S		
12	32	12	21	89	76	51	94	61	10	51	19	16	32	31	12.7	<b>UCT201</b>	T204
15	32	12	21	89	76	51	94	61	10	51	19	16	32	31	12.7	<b>UCT202</b>	T204
17	32	12	21	89	76	51	94	61	10	51	19	16	32	31	12.7	<b>UCT203</b>	T204
20	32	12	21	89	76	51	94	61	10	51	19	16	32	31	12.7	<b>UCT204</b>	T204
25	32	12	24	89	76	51	97	62	10	51	19	16	32	34.1	14.3	<b>UCT205</b>	T205
	37	12	28	102	89	56	113	70	10	57	22	16	37	38.1	15.9	<b>UCTX05</b>	TX05
	36	12	26	89	80	62	122	76	12	65	26	16	36	38	15	<b>UCT305</b>	T305
30	37	12	28	102	89	56	113	70	10	57	22	16	37	38.1	15.9	<b>UCT206</b>	T206
	37	12	30	102	89	64	129	78	13	64	22	16	37	42.9	17.5	<b>UCTX06</b>	TX06
	41	16	28	100	90	70	137	85	14	74	28	18	41	43	17	<b>UCT306</b>	T306
35	37	12	30	102	89	64	129	78	13	64	22	16	37	42.9	17.5	<b>UCT207</b>	T207
	49	16	36	114	102	83	144	88	15	83	29	19	49	49.2	19	<b>UCTX07</b>	TX07
	45	16	32	111	100	75	150	94	15	80	30	20	45	48	19	<b>UCT307</b>	T307
40	49	16	33	114	102	83	144	88	16	83	29	19	49	49.2	19	<b>UCT208</b>	T208
	49	16	36	117	102	83	144	87	15	83	29	19	49	49.2	19	<b>UCTX08</b>	TX08
	50	18	34	124	112	83	162	100	17	89	32	22	50	52	19	<b>UCT308</b>	T308
45	49	16	35	117	102	83	144	87	16	83	29	19	49	49.2	19	<b>UCT209</b>	T209
	49	16	38	117	102	83	149	90	16	86	29	19	49	51.6	19	<b>UCTX09</b>	TX09
	55	18	38	138	125	90	178	110	18	97	34	24	55	57	22	<b>UCT309</b>	T309
50	49	16	37	117	102	83	149	90	16	86	29	19	49	51.6	19	<b>UCT210</b>	T210
	64	22	42	146	130	102	171	106	19	95	35	25	64	55.6	22.2	<b>UCTX10</b>	TX10
	61	20	40	151	140	98	191	117	20	106	37	27	61	61	22	<b>UCT310</b>	T310
55	64	22	38	146	130	102	171	106	19	95	35	25	64	55.6	22.2	<b>UCT211</b>	T211
	64	22	44	146	130	102	194	119	19	102	35	32	64	65.1	25.4	<b>UCTX11</b>	TX11
	66	22	44	163	150	105	207	127	21	115	39	29	66	66	25	<b>UCT311</b>	T311
60	64	22	42	146	130	102	194	119	19	102	35	32	64	65.1	25.4	<b>UCT212</b>	T212

備考) 1. ユニット呼び番号およびカバー付きユニットの呼び番号には、内径番号の後にはめあい記号が付きます。(62頁の表 10.5 参照)  
 2. 適用するグリースニップルの呼びを次に示します。  
 B-1/4-28UNF.....201~210, X05~X09, 305~308  
 B-R1/8.....211~217, X10~X17, 309~328

UCT