



E-FTS エイトニップルス EIGHTNIPPLE S Fittings

材質：SUS316L
耐腐食性に優れる SUS316L
Material: 316L Steel Use Stainless
Excellent in corrosion resistance

型番：E-FTS- (ホース内径) [Model Number: E-FTS-(I.D.)]

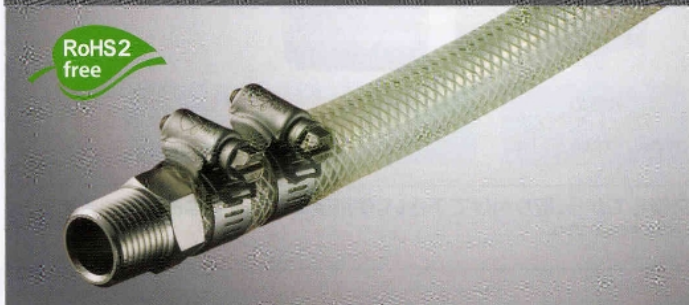


エイトニップル S/B 寸法図
EIGHTNIPPLE S/B Dimension

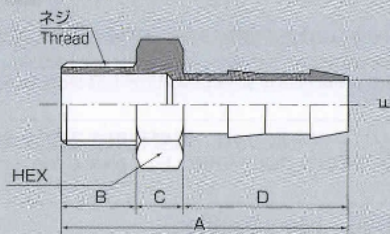

E-FTB エイトニップルB EIGHTNIPPLE B Fittings

材質：真鍮
Material: Brass

型番：E-FTB- (ホース内径) [Model Number: E-FTB-(I.D.)]

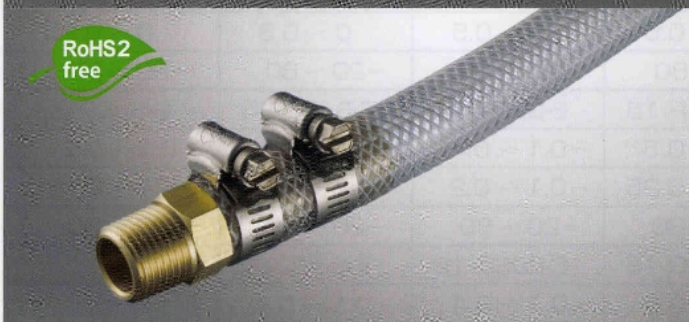

- 専用継手…自社ホースの寸法公差に合わせて開発、選定ミスによる漏れ、抜けの不具合から解消。
- 安全性…各ホースで使用温度範囲と使用圧力を明確化。
- フラット2段構造…ニップルのフラット部でバンドを2本締めることによって、ホース耐圧性能をMAXまで引き上げることができます。
- Original Fittings…Our E-FTS/E-FTB is developed, considering the margin of error of the hose. Thus, you do not have to worry about fluid leaking. Also, hose does not come off.
- Safety…For each hose, we clearly specify working temperature range and working pressure range.
- Flat 2-Stage Structure…Nipple parts are longer than the conventional ones, so they can be tightened firmly with two hose clamps. By tightening reinforced yarns, the lifespan of the hose becomes longer.

規格 (Specification)

エイトニップル S EIGHTNIPPLE S Fittings

型番 Model Number	ネジ規格 Thread	適合ホース内径 Hose Size I.D. (mm)	寸法 Dimensions (mm)						製品重量 Product Weight g/個 Gram/Piece
			A	B	C	D	E	HEX	
E-FTS-9	R 3/8	9	52	13	8	31	φ 7	17	29
E-FTS-12	R 1/2	12	69	17	10	42	φ 10	22	57
E-FTS-15	R 1/2	15	79	17	10	52	φ 12.5	22	64
E-FTS-19	R 3/4	19	89	25	12	52	φ 16	27	122
E-FTS-25	R 1	25	93	25	12	56	φ 19	36	237
E-FTS-32	R1 1/4	32	98	25	12	61	φ 27	46	318
E-FTS-38	R1 1/2	38	104	25	12	67	φ 33	50	374
E-FTS-50	R 2	50	109	30	12	67	φ 44	60	664

エイトニップル B EIGHTNIPPLE B Fittings

型番 Model Number	ネジ規格 Thread	適合ホース内径 Hose Size I.D. (mm)	寸法 Dimensions (mm)						製品重量 Product Weight g/個 Gram/Piece
			A	B	C	D	E	HEX	
E-FTB-6	R 1/4	6	50	13	6	31	φ 4	14	19
E-FTB-8	R 1/4	8	50	13	6	31	φ 6	14	20
E-FTB-9	R 3/8	9	52	13	8	31	φ 7	17	29
E-FTB-10	R 3/8	10	52	13	8	31	φ 8	17	30
E-FTB-12	R 1/2	12	69	17	10	42	φ 10	22	60
E-FTB-15	R 1/2	15	79	17	10	52	φ 12.5	22	69
E-FTB-19	R 3/4	19	89	25	12	52	φ 16	27	132
E-FTB-25	R 1	25	93	25	12	56	φ 19	36	255
E-FTB-32	R1 1/4	32	98	25	12	61	φ 27	46	340
E-FTB-38	R1 1/2	38	104	25	12	67	φ 33	50	396
E-FTB-50	R 2	50	109	30	12	67	φ 44	60	696