

Epoch Power Mill エポックパワーミル

切りくず排出性抜群で高効率が可能。
Excellent chip removal enables high efficiency.

ラジアスはA234頁を参照してください
Please refer to page A234 for Radius

ミディウム刃長 Medium

Medium



外径公差 Dia. tolerance
φ3~φ6 : 0~-0.015
φ7~φ20 : 0~-0.02

h6
6 < Ds ≤ 6 : 0~-0.008
6 < Ds ≤ 10 : 0~-0.009
10 < Ds ≤ 18 : 0~-0.011
18 < Ds : 0~-0.013 (mm)



ロング刃長 Long

Long



外径公差 Dia. tolerance
φ3~φ6 : 0~-0.015
φ7~φ20 : 0~-0.02

h6
6 < Ds ≤ 6 : 0~-0.008
6 < Ds ≤ 10 : 0~-0.009
10 < Ds ≤ 18 : 0~-0.011
18 < Ds : 0~-0.013 (mm)



EPPM4



商品コード Item Code	在庫 Stock	寸法 Size (mm)				希望小売 価格(円) Suggested retail price(¥)
		外径 Tool Dia.	刃長 Flute Length	全長 Overall Length	シャンク径 Shank Dia.	
EPPM4030	●	3	15	60	6	11,330
EPPM4040	●	4	17	60	6	12,040
EPPM4050	●	5	20	60	6	12,750
EPPM4060	●	6	20	60	6	13,980
EPPM4070	□	7	23	75	8	—
EPPM4080	●	8	25	75	8	17,140
EPPM4090	□	9	30	80	10	—
EPPM4100	●	10	33	80	10	22,950
EPPM4110	□	11	33	100	12	—
EPPM4120	●	12	37	100	12	28,970
EPPM4130	□	13	43	100	12	—
EPPM4140	□	14	43	110	16	—
EPPM4150	□	15	47	110	16	—
EPPM4160	●	16	47	110	16	63,040
EPPM4170	□	17	47	110	16	—
EPPM4180	□	18	55	125	20	—
EPPM4190	□	19	55	125	20	—
EPPM4200	●	20	55	125	20	92,210

EPPL4



商品コード Item Code	在庫 Stock	寸法 Size (mm)				希望小売 価格(円) Suggested retail price(¥)
		外径 Tool Dia.	刃長 Flute Length	全長 Overall Length	シャンク径 Shank Dia.	
EPPL4030	□	3	18	65	6	—
EPPL4040	□	4	20	65	6	—
EPPL4050	□	5	25	70	6	—
EPPL4060	●	6	25	70	6	20,610
EPPL4070	□	7	35	90	8	—
EPPL4080	●	8	35	90	8	25,910
EPPL4090	□	9	45	100	10	—
EPPL4100	●	10	45	100	10	34,790
EPPL4110	□	11	55	120	12	—
EPPL4120	●	12	55	120	12	42,640
EPPL4130	□	13	55	120	12	—
EPPL4140	□	14	55	125	16	—
EPPL4150	□	15	65	135	16	—
EPPL4160	●	16	65	135	16	95,170
EPPL4170	□	17	65	145	20	—
EPPL4180	□	18	65	145	20	—
EPPL4190	□	19	75	155	20	—
EPPL4200	●	20	75	155	20	138,720

ロングシャンク Long Shank

Long Shank

 


外径公差 Dia. tolerance
φ3~φ6 : 0~-0.015
φ7~φ20 : 0~-0.02

h6
6 < Ds ≤ 6 : 0~-0.008
6 < Ds ≤ 10 : 0~-0.009
10 < Ds ≤ 18 : 0~-0.011
18 < Ds : 0~-0.013 (mm)




Aタイプ
A type



Bタイプ
B type



Cタイプ
C type

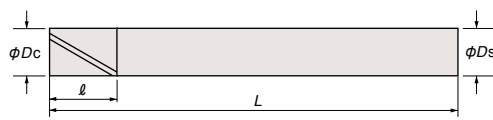

EPPLS4



商品コード Item Code	在庫 Stock	寸法 Size (mm)						形状 Shape	希望小売 価格(円) Suggested retail price(¥)
		外径Dc Tool Dia.	刃長l Flute Length	首径D1 Neck Dia.	首下長l2 Under Neck Length	全長L Overall Length	シャンク径Ds Shank Dia.		
EPPLS4030	●	3	4.5	2.9	10.5	80	6	A	11,430
EPPLS4040	●	4	6	3.8	14	80	6	A	12,040
EPPLS4050	●	5	7.5	4.8	17.5	100	6	A	13,770
EPPLS4060	●	6	9	—	—	120	5	B	15,610
EPPLS4070	●	7	9	—	—	120	6	B	15,610
EPPLS4080	●	8	12	—	—	135	7	B	19,280
EPPLS4090	●	9	12	—	—	135	8	B	19,280
EPPLS4100	●	10	15	—	—	150	9	B	25,810
EPPLS4110	●	11	15	—	—	150	10	B	25,810

商品コード Item Code	在庫 Stock	寸法 Size (mm)				形状 Shape	希望小売 価格(円) Suggested retail price(¥)
		外径Dc Tool Dia.	刃長l Flute Length	全長L Overall Length	シャンク径Ds Shank Dia.		
EPPLS4120	●	12	18	160	11	B	32,440
EPPLS4130	●	13	18	160	12	B	36,720
EPPLS4140	□	14	18	160	13	B	—
EPPLS4150	□	15	22	180	14	B	—
EPPLS4160	●	16	24	180	15	B	68,450
EPPLS4170	●	17	24	180	16	B	68,450
EPPLS4180	□	18	27	180	16	B	—
EPPLS4190	□	19	30	200	18	B	—
EPPLS4200	□	20	30	200	20	C	—

●印：標準在庫品です。 □印：特定代理店在庫です。弊社営業へお問合せください。
● : Stocked Items. □ : Stocked by specified distributor. Contact with our sales department.