


超硬OHノンステップボーラー 8D



h8	φ2~φ3	0~-0.014	シヤング公差 0~-0.01 (mm)
	φ3.1~φ6	0~-0.018	
	φ6.1~φ10	0~-0.022	
	φ10.1~φ13	0~-0.027	

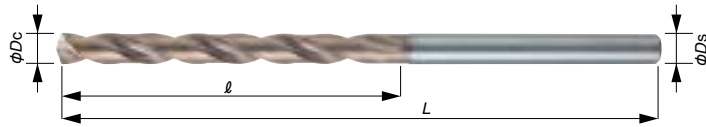

08WHNSB-TH

商品コード Item Code	在庫 Stock	寸法 Size (mm)				希望小売 価格(円) Suggested retail price(¥)
		直径 Dc Tool Dia.	溝長 ℓ Flute Length	全長 L Overall Length	シヤング径 Ds Shank Dia.	
08WHNSB0200-TH	●	2.0	25	75	3.0	17,450
08WHNSB0210-TH	●	2.1	25	75	3.0	17,450
08WHNSB0220-TH	●	2.2	25	75	3.0	17,450
08WHNSB0230-TH	●	2.3	28	75	3.0	17,450
08WHNSB0240-TH	●	2.4	28	75	3.0	17,450
08WHNSB0250-TH	●	2.5	28	75	3.0	17,450
08WHNSB0260-TH	●	2.6	33	80	3.0	17,450
08WHNSB0270-TH	●	2.7	33	80	3.0	17,450
08WHNSB0280-TH	●	2.8	35	83	3.0	17,450
08WHNSB0290-TH	●	2.9	35	83	3.0	17,450
08WHNSB0300-TH	●	3.0	35	83	3.0	17,450
08WHNSB0310-TH	●	3.1	42	94	4.0	17,850
08WHNSB0320-TH	●	3.2	42	94	4.0	17,850
08WHNSB0330-TH	●	3.3	42	94	4.0	17,850
08WHNSB0340-TH	●	3.4	42	94	4.0	17,850
08WHNSB0350-TH	●	3.5	42	94	4.0	17,850
08WHNSB0360-TH	●	3.6	46	94	4.0	18,060
08WHNSB0370-TH	●	3.7	46	94	4.0	18,060
08WHNSB0380-TH	●	3.8	46	94	4.0	18,060
08WHNSB0390-TH	●	3.9	46	94	4.0	18,060
08WHNSB0400-TH	●	4.0	46	94	4.0	18,060
08WHNSB0410-TH	●	4.1	55	110	5.0	18,670
08WHNSB0420-TH	●	4.2	55	110	5.0	18,670
08WHNSB0430-TH	●	4.3	55	110	5.0	18,670
08WHNSB0440-TH	●	4.4	55	110	5.0	18,670
08WHNSB0450-TH	●	4.5	55	110	5.0	18,670
08WHNSB0460-TH	●	4.6	59	110	5.0	18,870
08WHNSB0470-TH	●	4.7	59	110	5.0	18,870
08WHNSB0480-TH	●	4.8	59	110	5.0	18,870
08WHNSB0490-TH	●	4.9	59	110	5.0	18,870
08WHNSB0500-TH	●	5.0	59	110	5.0	18,870
08WHNSB0510-TH	●	5.1	62	118	6.0	19,790
08WHNSB0520-TH	●	5.2	62	118	6.0	19,790
08WHNSB0530-TH	●	5.3	62	118	6.0	19,790
08WHNSB0540-TH	●	5.4	62	118	6.0	19,790
08WHNSB0550-TH	●	5.5	62	118	6.0	19,790
08WHNSB0560-TH	●	5.6	67	118	6.0	20,200
08WHNSB0570-TH	●	5.7	67	118	6.0	20,200
08WHNSB0580-TH	●	5.8	67	118	6.0	20,200
08WHNSB0590-TH	●	5.9	67	118	6.0	20,200
08WHNSB0600-TH	●	6.0	67	118	6.0	20,200
08WHNSB0610-TH	●	6.1	73	132	7.0	21,320
08WHNSB0620-TH	●	6.2	73	132	7.0	21,320
08WHNSB0630-TH	●	6.3	73	132	7.0	21,320
08WHNSB0640-TH	●	6.4	73	132	7.0	21,320
08WHNSB0650-TH	●	6.5	73	132	7.0	21,320
08WHNSB0660-TH	●	6.6	77	132	7.0	21,630

商品コード Item Code	在庫 Stock	寸法 Size (mm)				希望小売 価格(円) Suggested retail price(¥)
		直径 Dc Tool Dia.	溝長 ℓ Flute Length	全長 L Overall Length	シヤング径 Ds Shank Dia.	
08WHNSB0670-TH	●	6.7	77	132	7.0	21,630
08WHNSB0680-TH	●	6.8	77	132	7.0	21,630
08WHNSB0690-TH	●	6.9	77	132	7.0	21,630
08WHNSB0700-TH	●	7.0	77	132	7.0	21,630
08WHNSB0710-TH	●	7.1	84	144	8.0	23,260
08WHNSB0720-TH	●	7.2	84	144	8.0	23,260
08WHNSB0730-TH	●	7.3	84	144	8.0	23,260
08WHNSB0740-TH	●	7.4	84	144	8.0	23,260
08WHNSB0750-TH	●	7.5	84	144	8.0	23,260
08WHNSB0760-TH	●	7.6	88	144	8.0	23,670
08WHNSB0770-TH	●	7.7	88	144	8.0	23,670
08WHNSB0780-TH	●	7.8	88	144	8.0	23,670
08WHNSB0790-TH	●	7.9	88	144	8.0	23,670
08WHNSB0800-TH	●	8.0	88	144	8.0	23,670
08WHNSB0810-TH	□	8.1	94	156	9.0	—
08WHNSB0820-TH	□	8.2	94	156	9.0	—
08WHNSB0830-TH	●	8.3	94	156	9.0	25,500
08WHNSB0840-TH	●	8.4	94	156	9.0	25,500
08WHNSB0850-TH	●	8.5	94	156	9.0	25,500
08WHNSB0860-TH	□	8.6	99	156	9.0	—
08WHNSB0870-TH	□	8.7	99	156	9.0	—
08WHNSB0880-TH	●	8.8	99	156	9.0	26,120
08WHNSB0890-TH	●	8.9	99	156	9.0	26,120
08WHNSB0900-TH	●	9.0	99	156	9.0	26,120
08WHNSB0910-TH	□	9.1	105	168	10.0	—
08WHNSB0920-TH	□	9.2	105	168	10.0	—
08WHNSB0930-TH	●	9.3	105	168	10.0	28,460
08WHNSB0940-TH	●	9.4	105	168	10.0	28,460
08WHNSB0950-TH	●	9.5	105	168	10.0	28,460
08WHNSB0960-TH	□	9.6	110	168	10.0	—
08WHNSB0970-TH	□	9.7	110	168	10.0	—
08WHNSB0980-TH	●	9.8	110	168	10.0	29,070
08WHNSB0990-TH	●	9.9	110	168	10.0	29,070
08WHNSB1000-TH	●	10.0	110	168	10.0	29,070
08WHNSB1010-TH	□	10.1	116	184	11.0	—
08WHNSB1020-TH	●	10.2	116	184	11.0	32,240
08WHNSB1030-TH	●	10.3	116	184	11.0	32,240
08WHNSB1040-TH	●	10.4	116	184	11.0	32,240
08WHNSB1050-TH	●	10.5	116	184	11.0	32,240
08WHNSB1060-TH	□	10.6	121	184	11.0	—
08WHNSB1070-TH	●	10.7	121	184	11.0	32,850
08WHNSB1080-TH	●	10.8	121	184	11.0	32,850
08WHNSB1090-TH	●	10.9	121	184	11.0	32,850
08WHNSB1100-TH	●	11.0	121	184	11.0	32,850
08WHNSB1110-TH	□	11.1	127	195	12.0	—
08WHNSB1120-TH	□	11.2	127	195	12.0	—
08WHNSB1130-TH	●	11.3	127	195	12.0	36,420

●印：標準在庫品です。 □印：特定代理店在庫です。弊社営業へお問い合わせください。
● : Stocked Items. □ : Stocked by specified distributor. Contact with our sales department.