



# 超硬OHノンステップボーラー 15D



自径公差 次頁を参照  
Refer to next page



$D_s \leq 3$  : 0~-0.006  
 $3 < D_s \leq 6$  : 0~-0.008  
 $6 < D_s \leq 10$  : 0~-0.009  
 $10 < D_s$  : 0~-0.011 (mm)

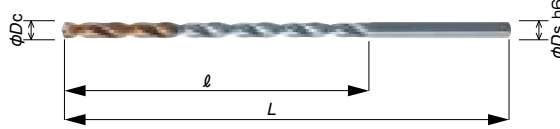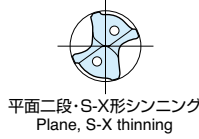

## 15WHNSB-TH



商品コード Item Code	在庫 Stock	寸法 Size (mm)				希望小売 価格(円) Suggested retail price(¥)
		直径 Dc Tool Dia.	溝長 ℓ Flute Length	全長 L Overall Length	シャンク径 Ds Shank Dia.	
15WHNSB0200-TH	●	2.0	40	83	3.0	23,360
15WHNSB0210-TH	●	2.1	44	87	3.0	23,360
15WHNSB0220-TH	●	2.2	44	87	3.0	23,360
15WHNSB0230-TH	●	2.3	50	93	3.0	23,360
15WHNSB0240-TH	●	2.4	50	93	3.0	23,360
15WHNSB0250-TH	●	2.5	50	93	3.0	23,360
15WHNSB0260-TH	●	2.6	54	102	3.0	23,360
15WHNSB0270-TH	●	2.7	54	102	3.0	23,360
15WHNSB0280-TH	●	2.8	54	102	3.0	23,360
15WHNSB0290-TH	●	2.9	54	102	3.0	23,360
15WHNSB0300-TH	●	3.0	54	102	3.0	23,360
15WHNSB0310-TH	●	3.1	63	111	4.0	23,670
15WHNSB0320-TH	●	3.2	63	111	4.0	23,670
15WHNSB0330-TH	●	3.3	63	111	4.0	23,670
15WHNSB0340-TH	●	3.4	63	111	4.0	23,670
15WHNSB0350-TH	●	3.5	63	111	4.0	23,670
15WHNSB0360-TH	●	3.6	72	121	4.0	23,970
15WHNSB0370-TH	●	3.7	72	121	4.0	23,970
15WHNSB0380-TH	●	3.8	72	121	4.0	23,970
15WHNSB0390-TH	●	3.9	72	121	4.0	23,970
15WHNSB0400-TH	●	4.0	72	121	4.0	23,970
15WHNSB0410-TH	●	4.1	81	132	5.0	24,590
15WHNSB0420-TH	●	4.2	81	132	5.0	24,590
15WHNSB0430-TH	●	4.3	81	132	5.0	24,590
15WHNSB0440-TH	●	4.4	81	132	5.0	24,590
15WHNSB0450-TH	●	4.5	81	132	5.0	24,590
15WHNSB0460-TH	●	4.6	91	142	5.0	25,100
15WHNSB0470-TH	●	4.7	91	142	5.0	25,100
15WHNSB0480-TH	●	4.8	91	142	5.0	25,100
15WHNSB0490-TH	●	4.9	91	142	5.0	25,100
15WHNSB0500-TH	●	5.0	91	142	5.0	25,100
15WHNSB0510-TH	●	5.1	100	151	6.0	26,730
15WHNSB0520-TH	●	5.2	100	151	6.0	26,730
15WHNSB0530-TH	●	5.3	100	151	6.0	26,730
15WHNSB0540-TH	●	5.4	100	151	6.0	26,730
15WHNSB0550-TH	●	5.5	100	151	6.0	26,730
15WHNSB0560-TH	●	5.6	109	160	6.0	28,360
15WHNSB0570-TH	●	5.7	109	160	6.0	28,360
15WHNSB0580-TH	●	5.8	109	160	6.0	28,360
15WHNSB0590-TH	●	5.9	109	160	6.0	28,360
15WHNSB0600-TH	●	6.0	109	160	6.0	28,360
15WHNSB0610-TH	●	6.1	118	171	7.0	30,500
15WHNSB0620-TH	●	6.2	118	171	7.0	30,500
15WHNSB0630-TH	●	6.3	118	171	7.0	30,500
15WHNSB0640-TH	●	6.4	118	171	7.0	30,500
15WHNSB0650-TH	●	6.5	118	171	7.0	30,500
15WHNSB0660-TH	●	6.6	127	180	7.0	32,540

商品コード Item Code	在庫 Stock	寸法 Size (mm)				希望小売 価格(円) Suggested retail price(¥)
		直径 Dc Tool Dia.	溝長 ℓ Flute Length	全長 L Overall Length	シャンク径 Ds Shank Dia.	
15WHNSB0670-TH	●	6.7	127	180	7.0	32,540
15WHNSB0680-TH	●	6.8	127	180	7.0	32,540
15WHNSB0690-TH	●	6.9	127	180	7.0	32,540
15WHNSB0700-TH	●	7.0	127	180	7.0	32,540
15WHNSB0710-TH	●	7.1	136	191	8.0	34,280
15WHNSB0720-TH	●	7.2	136	191	8.0	34,280
15WHNSB0730-TH	●	7.3	136	191	8.0	34,280
15WHNSB0740-TH	●	7.4	136	191	8.0	34,280
15WHNSB0750-TH	●	7.5	136	191	8.0	34,280
15WHNSB0760-TH	●	7.6	145	200	8.0	35,910
15WHNSB0770-TH	●	7.7	145	200	8.0	35,910
15WHNSB0780-TH	●	7.8	145	200	8.0	35,910
15WHNSB0790-TH	●	7.9	145	200	8.0	35,910
15WHNSB0800-TH	●	8.0	145	200	8.0	35,910
15WHNSB0810-TH	□	8.1	154	209	9.0	—
15WHNSB0820-TH	□	8.2	154	209	9.0	—
15WHNSB0830-TH	●	8.3	154	209	9.0	37,950
15WHNSB0840-TH	●	8.4	154	209	9.0	37,950
15WHNSB0850-TH	●	8.5	154	209	9.0	37,950
15WHNSB0860-TH	□	8.6	163	218	9.0	—
15WHNSB0870-TH	□	8.7	163	218	9.0	—
15WHNSB0880-TH	●	8.8	163	218	9.0	39,890
15WHNSB0890-TH	●	8.9	163	218	9.0	39,890
15WHNSB0900-TH	●	9.0	163	218	9.0	39,890
15WHNSB0910-TH	□	9.1	172	227	10.0	—
15WHNSB0920-TH	□	9.2	172	227	10.0	—
15WHNSB0930-TH	●	9.3	172	227	10.0	41,310
15WHNSB0940-TH	●	9.4	172	227	10.0	41,310
15WHNSB0950-TH	●	9.5	172	227	10.0	41,310
15WHNSB0960-TH	□	9.6	181	236	10.0	—
15WHNSB0970-TH	□	9.7	181	236	10.0	—
15WHNSB0980-TH	●	9.8	181	236	10.0	43,350
15WHNSB0990-TH	●	9.9	181	236	10.0	43,350
15WHNSB1000-TH	●	10.0	181	236	10.0	43,350
15WHNSB1010-TH	□	10.1	190	245	11.0	—
15WHNSB1020-TH	□	10.2	190	245	11.0	—
15WHNSB1030-TH	●	10.3	190	245	11.0	53,760
15WHNSB1040-TH	●	10.4	190	245	11.0	53,760
15WHNSB1050-TH	●	10.5	190	245	11.0	53,760
15WHNSB1060-TH	□	10.6	199	260	11.0	—
15WHNSB1070-TH	□	10.7	199	260	11.0	—
15WHNSB1080-TH	●	10.8	199	260	11.0	55,800
15WHNSB1090-TH	●	10.9	199	260	11.0	55,800
15WHNSB1100-TH	●	11.0	199	260	11.0	55,800
15WHNSB1110-TH	□	11.1	208	269	12.0	—
15WHNSB1120-TH	□	11.2	208	269	12.0	—
15WHNSB1130-TH	●	11.3	208	269	12.0	60,690

●印：標準在庫品です。 □印：特定代理店在庫です。弊社営業へお問い合わせください。  
● : Stocked Items. □ : Stocked by specified distributor. Contact with our sales department.