



7 めすおすバンド
Bends, 90°, male and female, plain (MBE)

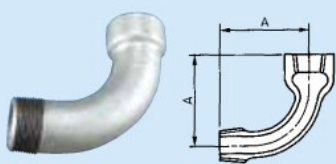


(呼び $\frac{1}{2}$ ~2)

8 めすおすバンド(バンド付)
Bends, 90°, male and female, banded (BMBE)

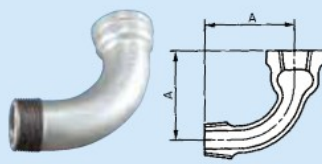

(呼び $\frac{1}{4}$ ~ $\frac{3}{8}$)

9 45°めすおすバンド(バンド付)
Bends, 45°, male and female, banded (BMBE45)

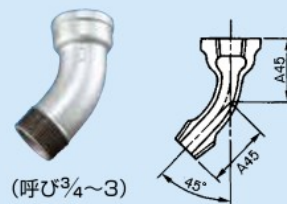

(呼び $\frac{3}{4}$ ~3)


単位 mm

呼び径(A)	呼 び	品 名			中心から端面までの距離	
		MBE	BMBE	BMBE45	A	A45
8	$\frac{1}{4}$		●		38	—
10	$\frac{3}{8}$		●		44	—
15	$\frac{1}{2}$	●			52	—
20	$\frac{3}{4}$	●		●	65	45
25	1	●		●	82	55

単位 mm


呼び径(A)	呼 び	品 名			中心から端面までの距離	
		MBE	BMBE	BMBE45	A	A45
32	$1\frac{1}{4}$	●		●	100	63
40	$1\frac{1}{2}$	●		●	115	70
50	2	●		●	140	85
65	$2\frac{1}{2}$			●	175	100
80	3			●	205	115

10 めすバンド(バンド付)
Bends, 90°, female banded (BIBE)

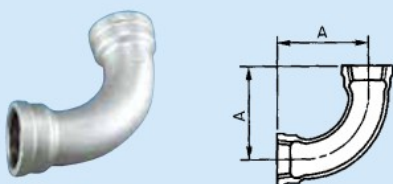

(呼び $\frac{1}{2}$ ~2)

11 おすバンド
Bends, 90°, male (OBE)

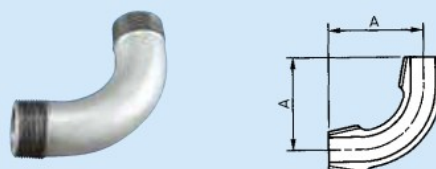

(呼び $\frac{1}{4}$ ~2)


単位 mm

呼び径(A)	呼 び	品 名		中心から端面までの距離
		BIBE	OBE	
8	$\frac{1}{4}$		●	A
10	$\frac{3}{8}$		●	44
15	$\frac{1}{2}$	●	●	52
20	$\frac{3}{4}$	●	●	65

単位 mm


呼び径(A)	呼 び	品 名		中心から端面までの距離
		BIBE	OBE	
25	1	●	●	82
32	$1\frac{1}{4}$	●	●	100
40	$1\frac{1}{2}$	●	●	115
50	2	●	●	140

12 ソケット(リブ)
Sockets, plain, with ribs (S)

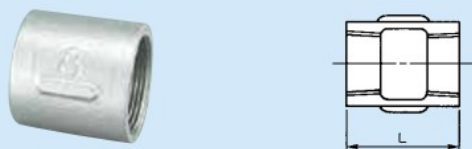

(呼び $\frac{1}{8}$ ~2)

13 ソケット(バンド付)
Sockets, banded, with ribs (BS)

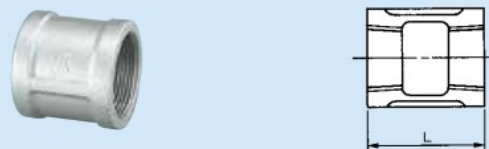

(呼び $\frac{1}{8}$ ~6)

単位 mm

呼び径(A)	呼 び	品 名		L
		S	BS	
6	$\frac{1}{8}$	●	●	22
8	$\frac{1}{4}$	●	●	25
10	$\frac{3}{8}$	●	●	30
15	$\frac{1}{2}$	●	●	35
20	$\frac{3}{4}$	●	●	40
25	1	●	●	45
32	$1\frac{1}{4}$	●	●	50

単位 mm

呼び径(A)	呼 び	品 名		L
		S	BS	
40	$1\frac{1}{2}$	●	●	55
50	2	●	●	60
65	$2\frac{1}{2}$		●	70
80	3		●	75
100	4		●	85
125	5		●	95
150	6		●	105