


17 径違いエルボ

Elbows, 90°, plain, reducing (RL)

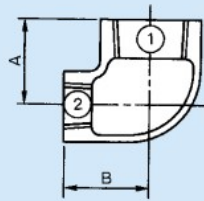

(呼び $\frac{3}{4}$ ~2)




18 径違いエルボ(バンド付)

Elbows, 90°, banded, reducing (BRL)



(呼び $\frac{1}{4}$ ~6)

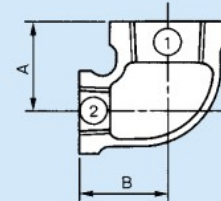

単位 mm

呼び径(A)	呼 び ①×②	品 名		中心から端面までの距離	
		RL	BRL	A	B
※ 8×6	$\frac{1}{4} \times \frac{1}{8}$		●	18	18
10×6	$\frac{3}{8} \times \frac{1}{8}$		●	19	21
10×8	$\frac{3}{8} \times \frac{1}{4}$		●	20	22
※ 15×6	$\frac{1}{2} \times \frac{1}{8}$		●	22	23
15×8	$\frac{1}{2} \times \frac{1}{4}$		●	24	24
15×10	$\frac{1}{2} \times \frac{3}{8}$		●	26	25
※ 20×8	$\frac{3}{4} \times \frac{1}{4}$		●	25	27
20×10	$\frac{3}{4} \times \frac{3}{8}$		●	28	28
20×15	$\frac{3}{4} \times \frac{1}{2}$	●	●	29	30
※ 25×8	$1 \times \frac{1}{4}$		●	27	31
25×10	$1 \times \frac{3}{8}$		●	30	31
25×15	$1 \times \frac{1}{2}$	●	●	32	33
25×20	$1 \times \frac{3}{4}$	●	●	34	35
32×15	$1\frac{1}{4} \times \frac{1}{2}$		●	34	38
32×20	$1\frac{1}{4} \times \frac{3}{4}$	●	●	38	40
32×25	$1\frac{1}{4} \times 1$	●	●	40	42
40×15	$1\frac{1}{2} \times \frac{1}{2}$		●	35	42
40×20	$1\frac{1}{2} \times \frac{3}{4}$		●	38	43
40×25	$1\frac{1}{2} \times 1$	●	●	41	45
40×32	$1\frac{1}{2} \times 1\frac{1}{4}$	●	●	45	48
50×15	$2 \times \frac{1}{2}$		●	38	48
50×20	$2 \times \frac{3}{4}$		●	41	49
50×25	2×1		●	44	51
50×32	$2 \times 1\frac{1}{4}$	●	●	48	54
50×40	$2 \times 1\frac{1}{2}$	●	●	52	55

単位 mm


呼び径(A)	呼 び ①×②	品 名		中心から端面までの距離	
		RL	BRL	A	B
△□ 65×15	$2\frac{1}{2} \times \frac{1}{2}$		●	41	57
△□ 65×20	$2\frac{1}{2} \times \frac{3}{4}$		●	44	58
65×25	$2\frac{1}{2} \times 1$		●	48	60
65×32	$2\frac{1}{2} \times 1\frac{1}{4}$		●	52	62
65×40	$2\frac{1}{2} \times 1\frac{1}{2}$		●	55	62
65×50	$2\frac{1}{2} \times 2$		●	60	65
△□ 80×15	$3 \times \frac{1}{2}$		●	44	64
△□ 80×20	$3 \times \frac{3}{4}$		●	46	66
△□ 80×25	3×1		●	50	68
80×32	$3 \times 1\frac{1}{4}$		●	55	70
80×40	$3 \times 1\frac{1}{2}$		●	58	72
80×50	3×2		●	62	72
80×65	$3 \times 2\frac{1}{2}$		●	72	75
△□ 100×25	4×1		●	57	83
△□ 100×32	$4 \times 1\frac{1}{4}$		●	61	86
△□ 100×40	$4 \times 1\frac{1}{2}$		●	63	86
100×50	4×2		●	69	87
100×65	$4 \times 2\frac{1}{2}$		●	78	90
100×80	4×3		●	83	91
125×80	5×3		●	87	107
125×100	5×4		●	100	111
□ 150×80	6×3		●	92	120
150×100	6×4		●	102	125
150×125	6×5		●	116	128

19 T

Tees, plain, equal (T)



(呼び $\frac{1}{8}$ ~2)

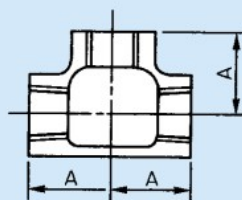


20 T(バンド付)

Tees, banded, equal (BT)



(呼び $\frac{1}{8}$ ~6)

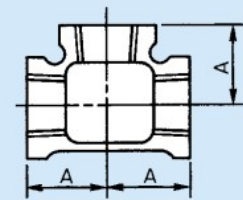

単位 mm

呼び径(A)	呼 び	品 名		中心から端面までの距離
		T	BT	A
6	$\frac{1}{8}$	●	●	17
8	$\frac{1}{4}$	●	●	19
10	$\frac{3}{8}$	●	●	23
15	$\frac{1}{2}$	●	●	27
20	$\frac{3}{4}$	●	●	32
25	1	●	●	38
32	$1\frac{1}{4}$	●	●	46

単位 mm

呼び径(A)	呼 び	品 名		中心から端面までの距離
		T	BT	A
40	$1\frac{1}{2}$	●	●	48
50	2	●	●	57
65	$2\frac{1}{2}$		●	69
80	3		●	78
100	4		●	97
125	5		●	113
150	6		●	132