


21 三方径違いT(バンド付)


Tees, banded, reducing (BRT)



(呼び $\frac{3}{8}$ ~4)

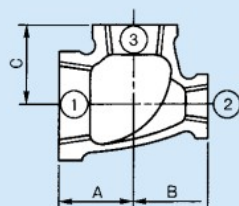

呼び径および呼び順位

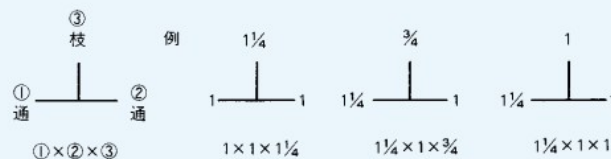

呼び径(A)	呼 び ①×②×③	単位 mm 中心から端面までの距離		
		A	B	C
10×10×15	$\frac{3}{8}$ × $\frac{3}{8}$ × $\frac{1}{2}$	25	25	26
15×15×20	$\frac{1}{2}$ × $\frac{1}{2}$ × $\frac{3}{4}$	30	30	30
15×15×25	$\frac{1}{2}$ × $\frac{1}{2}$ ×1	33	33	32
□20×10×20	$\frac{3}{4}$ × $\frac{3}{8}$ × $\frac{3}{4}$	32	28	32
20×15×15	$\frac{3}{4}$ × $\frac{1}{2}$ × $\frac{1}{2}$	30	27	30
20×15×20	$\frac{3}{4}$ × $\frac{1}{2}$ × $\frac{3}{4}$	32	30	32
△□20×15×25	$\frac{3}{4}$ × $\frac{1}{2}$ ×1	35	33	34
20×20×25	$\frac{3}{4}$ × $\frac{3}{4}$ ×1	35	35	34
20×20×32	$\frac{3}{4}$ × $\frac{3}{4}$ ×1 $\frac{1}{4}$	40	40	38
25×15×15	1× $\frac{1}{2}$ × $\frac{1}{2}$	32	27	33
25×15×20	1× $\frac{1}{2}$ × $\frac{3}{4}$	34	30	35
25×15×25	1× $\frac{1}{2}$ ×1	38	34	38
25×20×15	1× $\frac{3}{4}$ × $\frac{1}{2}$	32	29	33
25×20×20	1× $\frac{3}{4}$ × $\frac{3}{4}$	34	32	35
25×20×25	1× $\frac{3}{4}$ ×1	38	35	38
25×25×32	1×1×1 $\frac{1}{4}$	42	42	40
25×25×40	1×1×1 $\frac{1}{2}$	45	45	42
△□25×25×50	1×1×2	51	51	44
△□32×20×15	1 $\frac{1}{4}$ × $\frac{3}{4}$ × $\frac{1}{2}$	34	29	38
32×20×20	1 $\frac{1}{4}$ × $\frac{3}{4}$ × $\frac{3}{4}$	37	32	40
32×20×32	1 $\frac{1}{4}$ × $\frac{3}{4}$ ×1 $\frac{1}{4}$	46	40	46
□32×25×15	1 $\frac{1}{4}$ ×1× $\frac{1}{2}$	34	32	38
32×25×20	1 $\frac{1}{4}$ ×1× $\frac{3}{4}$	37	34	40
32×25×25	1 $\frac{1}{4}$ ×1×1	40	38	42
32×25×32	1 $\frac{1}{4}$ ×1×1 $\frac{1}{4}$	46	42	46
△□32×25×40	1 $\frac{1}{4}$ ×1×1 $\frac{1}{2}$	48	45	45

呼び径(A)	呼 び ①×②×③	単位 mm 中心から端面までの距離		
		A	B	C
32×32×40	1 $\frac{1}{4}$ ×1 $\frac{1}{4}$ ×1 $\frac{1}{2}$	48	48	45
32×32×50	1 $\frac{1}{4}$ ×1 $\frac{1}{4}$ ×2	52	52	48
△□40×20×20	1 $\frac{1}{2}$ × $\frac{3}{4}$ × $\frac{3}{4}$	38	32	43
△□40×25×20	1 $\frac{1}{2}$ ×1× $\frac{3}{4}$	38	34	43
40×25×25	1 $\frac{1}{2}$ ×1×1	41	37	45
40×25×32	1 $\frac{1}{2}$ ×1×1 $\frac{1}{4}$	45	42	48
40×25×40	1 $\frac{1}{2}$ ×1×1 $\frac{1}{2}$	48	45	48
△◇40×25×50	1 $\frac{1}{2}$ ×1×2	53	50	51
40×32×15	1 $\frac{1}{2}$ ×1 $\frac{1}{4}$ × $\frac{1}{2}$	35	34	42
40×32×20	1 $\frac{1}{2}$ ×1 $\frac{1}{4}$ × $\frac{3}{4}$	38	38	43
40×32×25	1 $\frac{1}{2}$ ×1 $\frac{1}{4}$ ×1	41	40	45
40×32×32	1 $\frac{1}{2}$ ×1 $\frac{1}{4}$ ×1 $\frac{1}{4}$	45	44	48
40×32×40	1 $\frac{1}{2}$ ×1 $\frac{1}{4}$ ×1 $\frac{1}{2}$	48	48	48
△□40×32×50	1 $\frac{1}{2}$ ×1 $\frac{1}{4}$ ×2	55	54	52
40×40×50	1 $\frac{1}{2}$ ×1 $\frac{1}{2}$ ×2	54	54	52
△□40×40×65	1 $\frac{1}{2}$ ×1 $\frac{1}{2}$ ×2 $\frac{1}{2}$	62	62	55
50×20×50	2× $\frac{3}{4}$ ×2	57	49	57
△◇50×25×25	2×1×1	45	38	52
△□50×25×32	2×1×1 $\frac{1}{4}$	48	42	54
△□50×25×40	2×1×1 $\frac{1}{2}$	52	45	55
50×25×50	2×1×2	57	52	57
△※50×32×15	2×1 $\frac{1}{4}$ × $\frac{1}{2}$	38	34	48
△◇50×32×25	2×1 $\frac{1}{4}$ ×1	45	41	52
50×32×32	2×1 $\frac{1}{4}$ ×1 $\frac{1}{4}$	48	46	54
50×32×40	2×1 $\frac{1}{4}$ ×1 $\frac{1}{2}$	52	48	55
50×32×50	2×1 $\frac{1}{4}$ ×2	57	54	57

呼び径(A)	呼 び ①×②×③	単位 mm 中心から端面までの距離		
		A	B	C
□50×32×65	2×1 $\frac{1}{4}$ ×2 $\frac{1}{2}$	65	62	60
△□50×40×15	2×1 $\frac{1}{2}$ × $\frac{1}{2}$	38	35	48
50×40×20	2×1 $\frac{1}{2}$ × $\frac{3}{4}$	41	38	50
50×40×25	2×1 $\frac{1}{2}$ ×1	45	42	52
50×40×32	2×1 $\frac{1}{2}$ ×1 $\frac{1}{4}$	49	46	54
50×40×40	2×1 $\frac{1}{2}$ ×1 $\frac{1}{2}$	52	48	55
50×40×50	2×1 $\frac{1}{2}$ ×2	57	55	57
50×50×65	2×2×2 $\frac{1}{2}$	65	65	60
50×50×80	2×2×3	72	72	62
△□65×40×40	2 $\frac{1}{2}$ ×1 $\frac{1}{2}$ ×1 $\frac{1}{2}$	55	48	62
△□65×40×50	2 $\frac{1}{2}$ ×1 $\frac{1}{2}$ ×2	60	55	65
△□65×40×65	2 $\frac{1}{2}$ ×1 $\frac{1}{2}$ ×2 $\frac{1}{2}$	69	62	69
△◇65×50×25	2 $\frac{1}{2}$ ×2×1	48	45	61
△□65×50×32	2 $\frac{1}{2}$ ×2×1 $\frac{1}{4}$	52	48	62
△□65×50×40	2 $\frac{1}{2}$ ×2×1 $\frac{1}{2}$	55	52	62
△□65×50×50	2 $\frac{1}{2}$ ×2×2	60	57	65
△□65×50×65	2 $\frac{1}{2}$ ×2×2 $\frac{1}{2}$	69	65	69
65×65×80	2 $\frac{1}{2}$ ×2 $\frac{1}{2}$ ×3	75	75	70
△□80×50×50	3×2×2	62	57	72
△□80×50×80	3×2×3	78	72	78
△◇80×65×40	3×2 $\frac{1}{2}$ ×1 $\frac{1}{2}$	57	54	71
△◇80×65×50	3×2 $\frac{1}{2}$ ×2	62	59	72
△□80×65×65	3×2 $\frac{1}{2}$ ×2 $\frac{1}{2}$	72	69	75
80×80×100	3×3×4	92	92	85
△□100×80×100	4×3×4	97	91	97