




## ACバンド

…ハンドグラインダー …電気ドリル …ボール盤



品番	直径×幅 (mm)	粒度分布													包装 単位	希望小売価格	
		24	36	40	60	80	100	120	150	180	240	320	400	600	800	1000	
AC310	3×10			●	●	●	●	●	●	●	●	●	●	●	●	50	70円
AC610	6×10			●	●	●	●	●	●	●	●	●	●	●	●	50	70円
AC820	8×20		●	●	●	●	●	●	●	●	●	●	●	●	●	50	80円
AC1020	10×20		●	●	●	●	●	●	●	●	●	●	●	●	●	50	80円
AC1220	12×20		●	●	●	●	●	●	●	●	●	●	●	●	●	50	80円
AC1520	15×20		●	●	●	●	●	●	●	●	●	●	●	●	●	50	80円
AC1920	19×20		●	●	●	●	●	●	●	●	●	●	●	●	●	50	80円
AC2220	22×20		●	●	●	●	●	●	●	●	●	●	●	●	●	50	90円
AC2525	25×25		●	●	●	●	●	●	●	●	●	●	●	●	●	50	100円
AC3030	30×30		●	●	●	●	●	●	●	●	●	●	●	●	●	50	110円
AC4530	45×30		●	●	●	●	●	●	●	●	●	●	●	●	●	50	150円
AC6030	60×30		●	●	●	●	●	●	●	●	●	●	●	●	●	10	260円
AC7530	75×30		●	●	●	●	●	●	●	●	●	●	●	●	●	10	280円

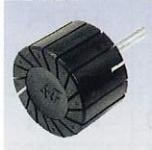

## ACドラム

…ハンドグラインダー …電気ドリル …ボール盤

品番	直径×幅 (mm)	軸径×軸長 (mm)	最高使用回転数	包装 単位	希望小売価格
AD310	3×10	3×35	25,000r.p.m.	10	280円
AD610	6×10	3×35	25,000r.p.m.	10	700円
AD8203	8×20	3×35	25,000r.p.m.	10	830円
AD8206	8×20	6×35	25,000r.p.m.	10	1,050円
AD10203	10×20	3×35	25,000r.p.m.	10	830円
AD10206	10×20	6×35	25,000r.p.m.	10	1,050円
AD12203	12×20	3×35	25,000r.p.m.	10	830円
AD12204	12×20	4×35	25,000r.p.m.	10	830円
AD12206	12×20	6×35	25,000r.p.m.	10	830円
AD1520	15×20	6×35	20,000r.p.m.	10	830円
AD1920	19×20	6×35	20,000r.p.m.	10	830円
AD2220	22×20	6×35	18,000r.p.m.	10	1,100円
AD2525	25×25	6×35	18,000r.p.m.	10	1,260円
AD3030	30×30	6×40	13,000r.p.m.	10	1,380円
AD4530	45×30	6×40	9,000r.p.m.	10	1,650円
AD6030	★60×30×(9.6穴)	6×30	9,000r.p.m.	1	2,200円
AD7530	★75×30×(12.7穴)	6×30	9,000r.p.m.	1	2,750円

★…AD6030(9.6穴)、AD7530(12.7穴)は、穴開きでも使用できます。