


PICCO CUT

PICCO R/L 010/610
小径ソリッドバー、
端面加工用

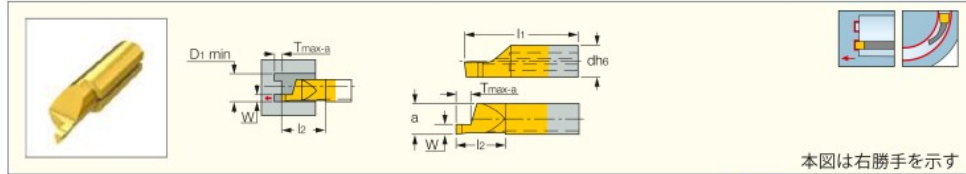


本図は右勝手を示す

型番	寸法								PVD コーティング		推奨加工条件 f 端面溝入 (mm/rev)
	D1 min	W0 ^{+0.05}	Tmax-a	d	a	l2	l1	IC228			
								R	L		
PICCO R 010.1006-10	6.0	1.00	1.50	6.00	5.20	11.0	26.00	●		0.01-0.04	
PICCO R 010.1506-10	6.0	1.50	2.00	6.00	5.20	11.0	26.00	●		0.01-0.04	
PICCO R 010.1008-10	8.0	1.00	1.50	7.00	5.90	11.0	26.00	●		0.01-0.04	
PICCO R 010.1008-20	8.0	1.00	1.50	7.00	5.90	21.0	35.00	●		0.01-0.04	
PICCO R 010.1008-30	8.0	1.00	1.50	7.00	5.90	30.0	45.00	●		0.01-0.04	
PICCO R 610.1008-10	8.0	1.00	1.50	6.00	5.20	11.0	26.00	●		0.01-0.04	
PICCO R 610.1008-20	8.0	1.00	1.50	6.00	5.20	20.0	35.00	●		0.01-0.04	
PICCO R 010.1508-10	8.0	1.50	2.50	7.00	5.90	11.0	26.00	●		0.01-0.04	
PICCO R/L 010.1508-20	8.0	1.50	2.50	7.00	5.90	21.0	35.00	●	●	0.01-0.04	
PICCO R/L 010.1508-30	8.0	1.50	2.50	7.00	5.90	30.0	45.00	●	●	0.01-0.04	
PICCO R 610.1508-10	8.0	1.50	2.50	6.00	5.20	11.0	26.00	●		0.01-0.04	
PICCO R 610.1508-20	8.0	1.50	2.50	6.00	5.20	20.0	35.00	●		0.01-0.04	
PICCO R 010.2008-10	8.0	2.00	3.00	7.00	5.90	11.0	26.00	●		0.02-0.05	
PICCO R 010.2008-20	8.0	2.00	3.00	7.00	5.90	21.0	35.00	●		0.02-0.05	
PICCO R/L 010.2008-30	8.0	2.00	3.00	7.00	5.90	30.0	45.00	●	●	0.02-0.05	
PICCO R 610.2008-10	8.0	2.00	3.00	6.00	5.20	11.0	26.00	●		0.02-0.05	
PICCO R 610.2008-20	8.0	2.00	3.00	6.00	5.20	20.0	35.00	●		0.02-0.05	
PICCO R 010.2508-10	8.0	2.50	3.50	7.00	5.90	11.0	26.00	●		0.02-0.05	
PICCO R 010.2508-20	8.0	2.50	3.50	7.00	5.90	21.0	35.00	●		0.02-0.05	
PICCO R 010.2508-30	8.0	2.50	3.50	7.00	5.90	30.0	45.00	●		0.02-0.05	
PICCO R 610.2508-10	8.0	2.50	3.50	6.00	5.20	11.0	26.00	●		0.02-0.05	
PICCO R 610.2508-20	8.0	2.50	3.50	6.00	5.20	20.0	35.00	●		0.02-0.05	
PICCO R 010.3008-10	8.0	3.00	3.50	7.00	5.90	11.0	26.00	●		0.02-0.06	
PICCO R 010.3008-20	8.0	3.00	3.50	7.00	5.90	21.0	35.00	●		0.02-0.06	
PICCO R 010.3008-30	8.0	3.00	3.50	7.00	5.90	30.0	45.00	●		0.02-0.06	
PICCO R 610.3008-10	8.0	3.00	3.50	6.00	5.20	11.0	26.00	●		0.02-0.06	
PICCO R 610.3008-20	8.0	3.00	3.50	6.00	5.20	20.0	35.00	●		0.02-0.06	

- シャープコーナータイプ
- 推奨加工条件は、D40-D41頁をご参照下さい。

PICCO CUT

PICCO R/L 010 (フルR)
小径ソリッドバー、
端面加工用、フルR

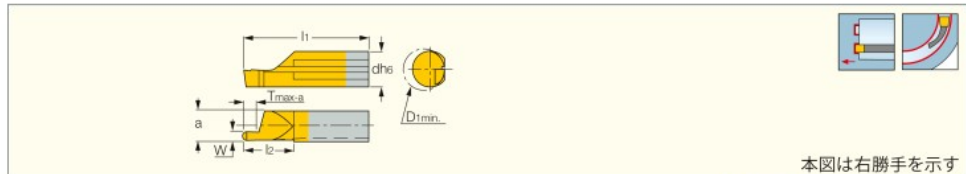

本図は右勝手を示す

型番	寸法								PVD コーティング		推奨加工条件 f 端面溝入 (mm/rev)
	D1 min	W0 ^{+0.05}	R	Tmax-a	d	a	l2	l1	IC1008		
									R	L	
PICCO R 010.1005-10	8.0	1.00	0.50	2.00	7.00	5.90	11.0	26.00	●		0.01-0.04
PICCO R 010.1005-20	8.0	1.00	0.50	2.00	7.00	5.90	20.0	35.00	●		0.01-0.04
PICCO R 010.1608-10	8.0	1.60	0.80	3.00	7.00	5.90	11.0	26.00	●		0.01-0.05
PICCO R 010.1608-20	8.0	1.60	0.80	3.00	7.00	5.90	20.0	35.00	●		0.01-0.05
PICCO R 010.2010-10	8.0	2.00	1.00	4.00	7.00	5.90	11.0	26.00	●		0.02-0.05
PICCO R 010.2010-20	8.0	2.00	1.00	4.00	7.00	5.90	20.0	35.00	●		0.02-0.05
PICCO R 010.2512-10	8.0	2.50	1.25	5.00	7.00	5.90	11.0	26.00	●		0.02-0.05
PICCO R 010.2512-20	8.0	2.50	1.25	5.00	7.00	5.90	20.0	35.00	●		0.02-0.05
PICCO R 010.3015-10	8.0	3.00	1.50	6.00	7.00	5.90	11.0	26.00	●		0.02-0.05
PICCO R 010.3015-20	8.0	3.00	1.50	6.00	7.00	5.90	20.0	35.00	●		0.02-0.05

- 左勝手は受注生産
- 推奨加工条件は、D40-D41頁をご参照下さい。