


SELF-GRIP

SGB

突切・溝加工用アダプター
セルフグリップチップ用(Fカット)

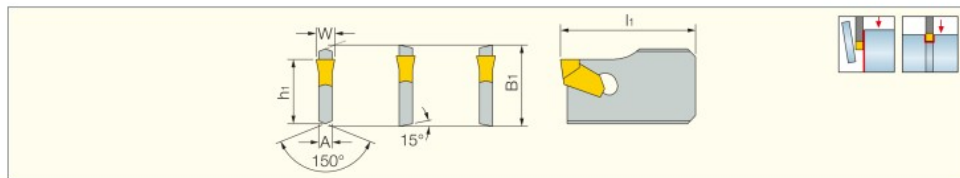

型番	在庫	W _{min}	W _{max}	B ₁	A	l ₁	D _{max}	h ₁	取外し レンチ
SGB 19-1.2	●	1.20	1.20	19.0	0.93 *	32.0	18.0	15.6	ESG-0.5
SGB 19-1.6	●	1.60	1.60	19.0	1.20 *	32.0	36.0	15.6	ESG-1
SGB 19-2	●	1.80	2.69	19.0	1.60	32.0	36.0	15.6	ESG-1
SGB 19-3	●	2.70	3.53	19.0	2.40	32.0	36.0	15.6	ESG-1
SGB 19R-4	①	3.54	4.52	19.0	3.20	32.0	36.0	15.6	ESG-1
SGB 19L-4	①	3.54	4.52	19.0	3.20	32.0	36.0	15.6	ESG-1

* 切込部の寸法。

● 取外しレンチESGは付属致しません。別途ご注文下さい。

適合チップ: GFN/R/L (C46-C47頁)


適合ツールブロック: C#-TBK-R/L (E7頁) • HSK A-WH-TBK-R/L (E12頁) • SGTBF (E3頁) • SGTBK (E3頁) • SGTBR/L (E3頁) • SGTBU/SGTBN (E2頁)

• UBHCR/L (E3頁)

SELF-GRIP

SGBHR/L

突切・溝加工用
アダプター交換式ホルダー

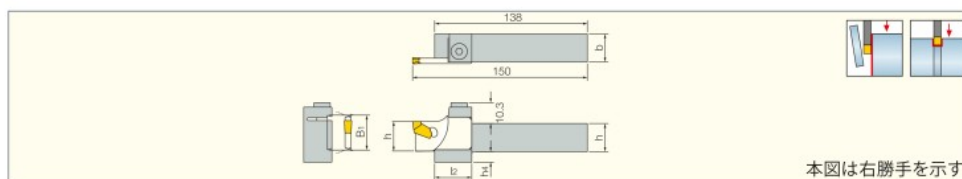

本図は右勝手を示す

型番	在庫	h	b	h ₄	B ₁	l ₂	スクリュー	レンチ
SGBHR/L 1010	① ①	10.0	10.0	10.0	19.0	20.0	SR M5X25DIN912	HW 4.0
SGBHR 1212	①	12.0	12.0	8.0	19.0	20.0	SR M5X25DIN912	HW 4.0
SGBHR 1414	①	14.0	14.0	6.0	19.0	20.0	SR M5X25DIN912	HW 4.0
SGBHR/L 1616	① ①	16.0	16.0	6.0	19.0	20.0	SR M5X25DIN912	HW 4.0
SGBHR/L 2020	● ●	20.0	20.0	2.0	19.0	20.0	SR M5X25DIN912	HW 4.0
SGBHR/L 2525	● ①	25.0	25.0	-	19.0	20.0	SR M5X25DIN912	HW 4.0


● アダプターは付属致しません。別途ご注文下さい。

適合アダプター: TGFH-S (C30頁) • SGB (C46頁)

SELF-GRIP

GFN

突切・溝加工用
1コーナー使いチップ(Fカット)

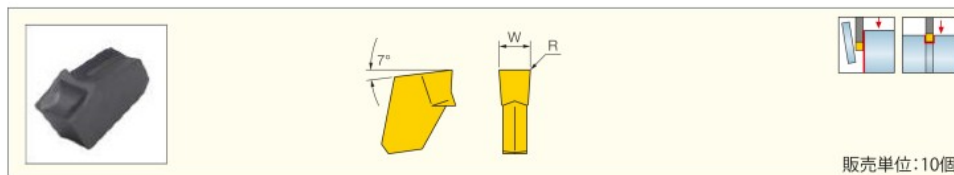

販売単位: 10個

型番	寸法			韌性 ↔ 耐摩耗性							
	W	W±公差	R±0.05	PVDコーティング					超硬		サーメット
				IC328	IC1028	IC354	IC308	IC908	IC54	IC20	
GFN 1.2J	1.20	0.03	0.14	●		●				●	
GFN 1.2JS	1.20	0.03	0.02	●		●				●	
GFN 1.6J	1.60	0.03	0.16	●	●	●		●		●	
GFN 1.6	1.60	0.03	0.16	●	●	●		●	●	●	
GFN 2J	1.99	0.03	0.16	●	●	●		●	①	●	
GFN 2	2.20	0.03	0.16	●	●	●		●	●	●	●
GFN 2E	2.20	0.03	0.16	●		●					●
GFN 2W	2.20	0.03	0.16	●		●					
GFN 2B	2.20	0.03	0.20	●	①	●		●			
GFN 2.4	2.40	0.03	0.16	●		●			①	●	
GFN 3J	3.00	0.03	0.25	●	●	●		●	①	●	
GFN 3	3.03	0.04	0.20	●	●	●		●	●	●	●
GFN 3E	3.00	0.04	0.20	●		●					●
GFN 3W	3.00	0.10	0.20	●		●			●	①	
GFN 3U	3.00	0.10	0.00	●		●					
GFN 3B	3.02	0.04	0.30	●	①	●	●	●	①		
GFN 4J	4.00	0.04	0.25	●	①	●		●		●	
GFN 4	4.05	0.04	0.24	●	●	●		●	●	●	①
GFN 4W	4.10	0.04	0.24	●		●			①		
GFN 4B	4.10	0.04	0.40	●	①	●	①	●			
GFN 5J	5.02	0.04	0.25	●		●		●		●	
GFN 5	5.11	0.04	0.28	●		●		●	①	●	
GFN 5B	5.08	0.04	0.40	●							

適合ホルダー: SGFH (C45頁) • SGTFR/L (C45頁) • SGAFR/L (C45頁) • SGB (C46頁)

ISCAR