

MBSC, MBSSC スロットクランプ

標準在庫品



RoHS

イマオ
WEB 製品ムービー公開

IMAO

MBSC-A
(黒皮面用)MBSC-B
(仕上面用)MBSC-C
(仕上面用)MBSSC
(セルフカット)

タイプ	本体
MBSC-A	SKD12 焼入焼戻 四三酸化鉄皮膜 HRC45~48
MBSC-B	SKD12 焼入焼戻 HRC45~48
MBSC-C	黄銅(カドミウム低減材)
MBSSC	SKD12 HRC43

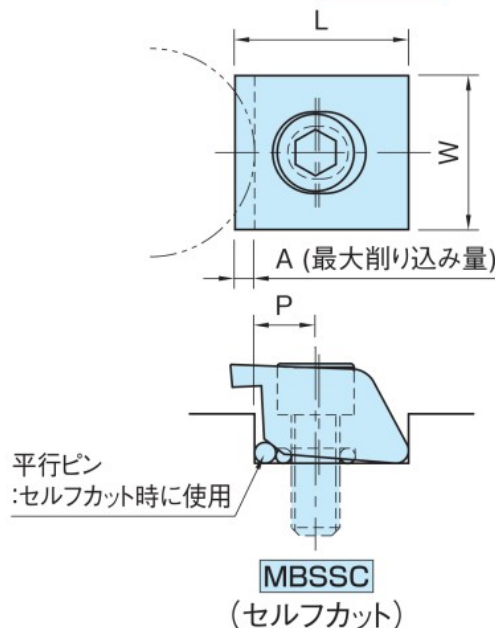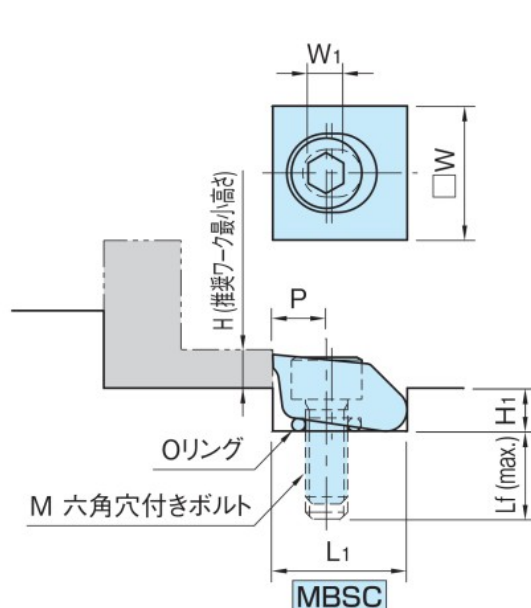

MBSC -A(黒皮面用)

品番	W	H	ストローク	H ₁	L ₁	P	Lf	M	W ₁	クランプ力 (kN)	許容締付トルク (N・m)	質量 (g)
MBSC025A	9.5	1.9	0.19	3.6	9.5	3.8	7	M 2.5×0.45- 8L	2	2.8	1.8	3
MBSC04A	12.7	2.5	0.4	4.8	12.7	5.1	10	M 4 ×0.7 -12L	3	6.6	5.6	7
MBSC06A	19.1	3.8	0.6	7.1	19.1	7.6	13	M 6 ×1 -16L	5	16	22.5	21
MBSC10A	25.4	6.4	1.2	11.4	25.4	10.2	20	M10 ×1.5 -25L	8	17	40.6	65
MBSC12A	38.1	9.5	1.9	16.3	38.1	15.2		M12 ×1.75-30L	10	50	145	200

MBSC -B(仕上面用)

品番	W	H	ストローク	H ₁	L ₁	P	Lf	M	W ₁	クランプ力 (kN)	許容締付トルク (N・m)	質量 (g)
MBSC025B	9.5	1.9	0.19	3.6	9.5	3.8	7	M 2.5×0.45- 8L	2	2.8	1.8	3
MBSC04B	12.7	2.5	0.4	4.8	12.7	5.1	10	M 4 ×0.7 -12L	3	6.6	5.6	7
MBSC06B	19.1	3.8	0.6	7.1	19.1	7.6	13	M 6 ×1 -16L	5	16	22.5	21
MBSC10B	25.4	6.4	1.2	11.4	25.4	10.2	20	M10 ×1.5 -25L	8	17	40.6	65
MBSC12B	38.1	9.5	1.9	16.3	38.1	15.2		M12 ×1.75-30L	10	50	145	200

MBSC -C(仕上面用)

品番	W	H	ストローク	H ₁	L ₁	P	Lf	M	W ₁	クランプ力 (kN)	許容締付トルク (N・m)	質量 (g)
MBSC025C	9.5	1.9	0.19	3.6	9.5	3.8	5	M2.5×0.45- 8L	1.5	0.8	0.6	3
MBSC04C	12.7	2.5	0.4	4.8	12.7	5.1	10	M4 ×0.7 -12L	2.5	1.7	2.8	7
MBSC06C	19.1	3.8	0.6	7.1	19.1	7.6	11	M6 ×1 -16L	4	4.2	5.6	23