

MHS, MCT, MFSC アングルグリッパー

標準 在庫品 **RoHS**

**Fairlane**


★One Point  
MCT, MFSC:  
超硬チップタイプ



MHS-127-4



MHS-127-12

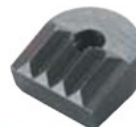

MHS-130-4



MCT-127-4




MCT-127-12



MCT-130-4



MFSC-127-4

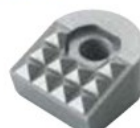


MFSC-127-10




MFSC-130-4


タイプ	本体	チップ
MHS	SKH51 焼入焼戻 四三酸化鉄皮膜 HRC62	
MCT	SKH51 焼入焼戻 四三酸化鉄皮膜 HRC62	超硬 HRC72
MFSC		超硬 HRC72

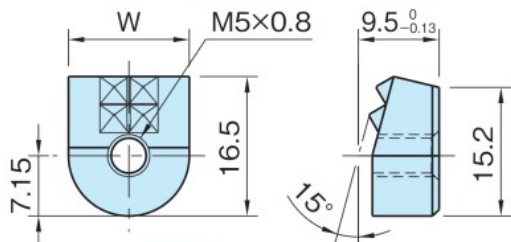


MHS-127-4, 127-4-10

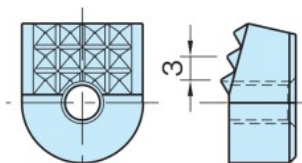


MHS-127-12

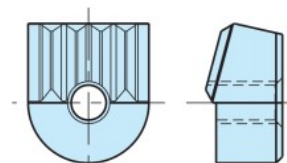


MHS-130-4

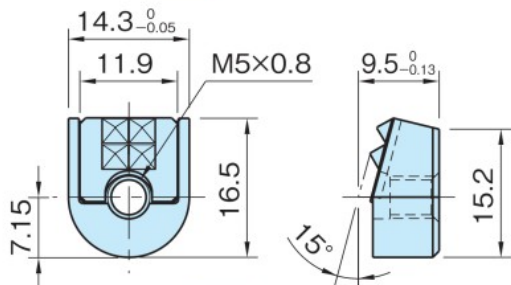


MCT-127-4

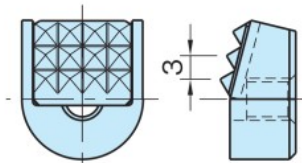


MCT-127-12

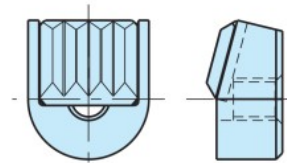


MCT-130-4

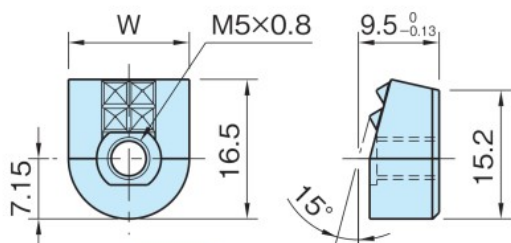

MFSC-127-4, 127-4-10

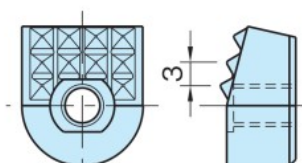

MFSC-127-10

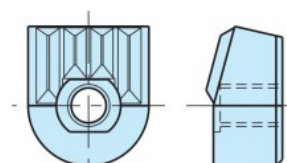

MFSC-130-4

MHS

品番	W ( $\pm 0.05$ )	質量 (g)
MHS-127- 4-10	10	7
MHS-127- 4	14.3	11
MHS-127-12		12
MHS-130- 4		

MCT

品番	質量 (g)
MCT-127- 4	12
MCT-127-12	13
MCT-130- 4	

MFSC

品番	W ( $\pm 0.05$ )	質量 (g)
MFSC-127- 4-10	10	13
MFSC-127- 4	14.3	
MFSC-127-10		20
MFSC-130- 4		