


BJ745

スタッドボルト

標準在庫品 

IMAO

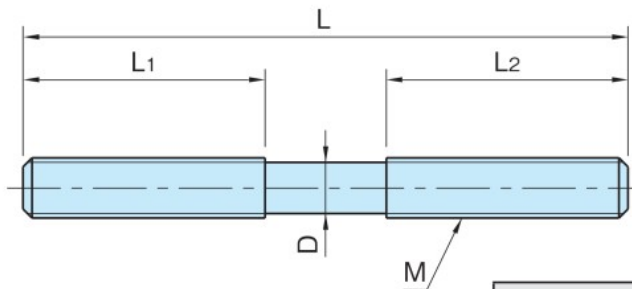

BJ745-08~20 BJ745-24

タイプ	本体
BJ745-08~20	SCM435 焼入焼戻 四三酸化鉄皮膜 HRC33~39
BJ745-24	スチール 焼入焼戻 四三酸化鉄皮膜 HRC23~34

品番	M	L	L ₁	L ₂	D	質量 (g)
BJ745-08050	M 8×1.25	50	20	20	7.1	20
BJ745-08063		63	25	25		25
BJ745-08080		80	32	32		35
BJ745-08100		100				40
BJ745-08125		125				45
BJ745-08160		160				55
BJ745-10050	M10×1.5	50	20	20	8.9	30
BJ745-10063		63	25	25		40
BJ745-10080		80	32	32		45
BJ745-10100		100	40	40		55
BJ745-10125		125				70
BJ745-10160		160				90
BJ745-10200	200	110				
BJ745-12050	M12×1.75	50	20	20	10.7	40
BJ745-12063		63	25	25		50
BJ745-12080		80	32	32		65
BJ745-12100		100	40	40		80
BJ745-12125		125				100
BJ745-12160		160				125
BJ745-12200	200	160				