


## SQL-DS

## デュアルステーション ジョーセット

標準  
在庫品


CHICK

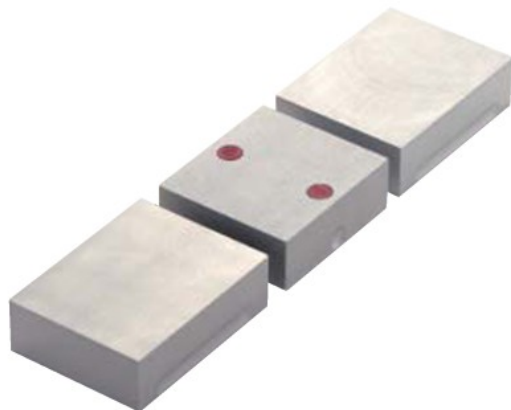

本体

A7075  
ナチュラル

M 六角穴付きボルト用

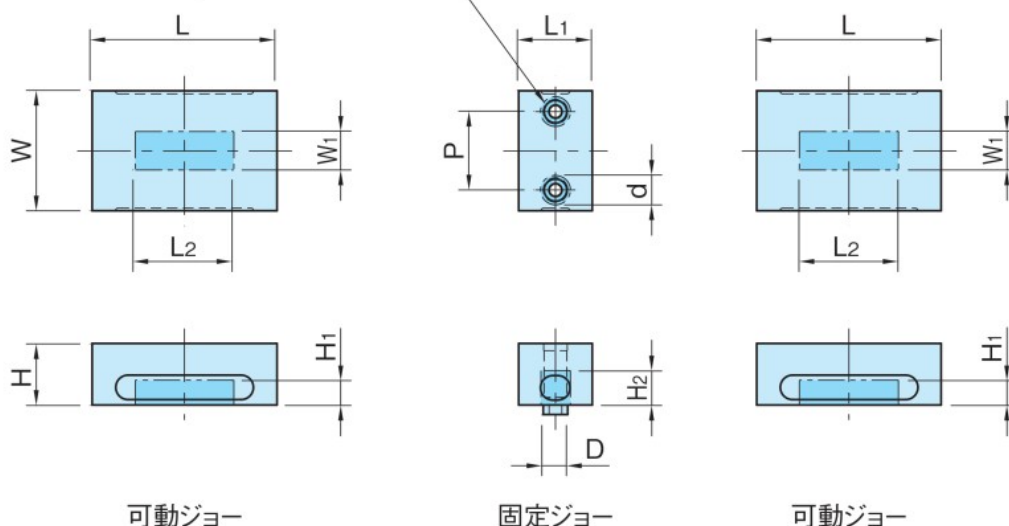

=セルフカット不可範囲

品番	W	L	H	W <sub>1</sub>	L <sub>1</sub>	L <sub>2</sub>	H <sub>1</sub>	H <sub>2</sub>	P	D	d	M	質量 (kg)	適用本体サイズ
SQL0520-DS05	49	75	25	29	36	55	14	10.5	32	10	15	M 5	0.73	0520
SQL0525-DS05					76								0.87	0525
SQL1030-DS10	99	105	40	42	70	70	17	17	70	14	18	M 8	2.83	1030
SQL1030-DS15	148				4.95									
SQL1040-DS10	99	130	50	56	110	90	21	20	100	18	20	M10	3.6	1040
SQL1040-DS15	148				6.13									
SQL1540-DS15	148	135	50	56	100	90	21	20	100	18	20	M10	7.08	1540
SQL1540-DS20	198				9.74									
SQL1550-DS15	148	160	50	56	140	90	21	20	100	18	20	M10	8.32	1550
SQL1550-DS20	198				11.4									