


形状・寸法

■ 径違い六角ニップル

STNR

304 (SUS304 または SCS13A)

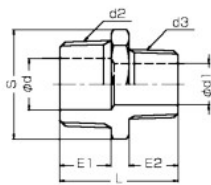


呼び径		ねじ		寸法(mm)							304 在庫
A (mm)	B (inch)	d2	d3	L	E1	E2	d	d1	S		
									六角	八角	
8×6	$\frac{1}{4} \times \frac{1}{8}$	R $\frac{1}{4}$	R $\frac{1}{8}$	32	13	10	7	5	14	—	●
10×6	$\frac{3}{8} \times \frac{1}{8}$	R $\frac{3}{8}$	R $\frac{1}{8}$	34	13	10	8.5	5	17	—	●
10×8	$\frac{3}{8} \times \frac{1}{4}$	R $\frac{3}{8}$	R $\frac{1}{4}$	35	13	13	8.5	7	17	—	●
15×8	$\frac{1}{2} \times \frac{1}{4}$	R $\frac{1}{2}$	R $\frac{1}{4}$	38	17	13	12	7	22	—	●
15×10	$\frac{1}{2} \times \frac{3}{8}$	R $\frac{1}{2}$	R $\frac{3}{8}$	39	17	13	12	8.5	22	—	●
20×10	$\frac{3}{4} \times \frac{3}{8}$	R $\frac{3}{4}$	R $\frac{3}{8}$	42	19.5	14.5	19.5	11	29	—	●
20×15	$\frac{3}{4} \times \frac{1}{2}$	R $\frac{3}{4}$	R $\frac{1}{2}$	45	19.5	17.5	19.5	14.5	29	—	●
25×15	1× $\frac{1}{2}$	R1	R $\frac{1}{2}$	48	21.5	17.5	25	14.5	36	—	●
25×20	1× $\frac{3}{4}$	R1	R $\frac{3}{4}$	50	21.5	19.5	25	19.5	36	—	●
32×20	1 $\frac{1}{4}$ × $\frac{3}{4}$	R1 $\frac{1}{4}$	R $\frac{3}{4}$	52	23.5	19.5	33.5	19.5	—	43.5	●
32×25	1 $\frac{1}{4}$ ×1	R1 $\frac{1}{4}$	R1	54	23.5	21.5	33.5	25	—	43.5	●
40×25	1 $\frac{1}{2}$ ×1	R1 $\frac{1}{2}$	R1	57	24.5	21.5	39	25	—	49.5	●
40×32	1 $\frac{1}{2}$ ×1 $\frac{1}{4}$	R1 $\frac{1}{2}$	R1 $\frac{1}{4}$	59	24.5	23.5	39	33.5	—	49.5	●
50×25	2×1	R2	R1	61	27.5	21.5	50	25	—	61.5	●
50×32	2×1 $\frac{1}{4}$	R2	R1 $\frac{1}{4}$	63	27.5	23.5	50	33.5	—	61.5	●
50×40	2×1 $\frac{1}{2}$	R2	R1 $\frac{1}{2}$	64	27.5	24.5	50	39	—	61.5	●

2 ステンレス製ねじ込み式管継手

■ ホースニップル

HN

304 (SUS 304 TP)

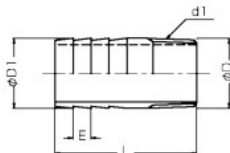


呼び径		ねじ	寸法(mm)				304 在庫
A (mm)	B (inch)	d1	D	D1 (ホース外径)	L	E	
8	$\frac{1}{4}$	R $\frac{1}{4}$	13.8	13.6	41	4.3	●
10	$\frac{3}{8}$	R $\frac{3}{8}$	17.3	17.1	42	4.3	●
15	$\frac{1}{2}$	R $\frac{1}{2}$	21.7	21.5	52	6	●
20	$\frac{3}{4}$	R $\frac{3}{4}$	27.2	27.0	55	7	●
25	1	R1	34.0	33.7	60	7	●
32	1 $\frac{1}{4}$	R1 $\frac{1}{4}$	42.7	42.4	66	8	●
40	1 $\frac{1}{2}$	R1 $\frac{1}{2}$	48.6	48.2	70	8	●
50	2	R2	60.5	60.1	80	9	●

■ 六角ホースニップル

STHN

304 (SUS 304 または SCS 13A)

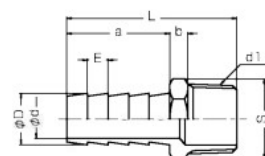

呼び径		ねじ	寸法 (mm)								304 在庫
A (mm)	B (inch)	d1	L	a	b	E	D	d	S		
									六角	八角	
8	$\frac{1}{4}$	R $\frac{1}{4}$	39	20	7	4	8	5	14	—	●
10	$\frac{3}{8}$	R $\frac{3}{8}$	45	25	7	5	10.5	7	17	—	●
15	$\frac{1}{2}$	R $\frac{1}{2}$	51	30	5	6	14	9	22	—	●
20	$\frac{3}{4}$	R $\frac{3}{4}$	64	40	6	8	20	14	—	27.5	●
25	1	R1	72	45	7	9	26.5	20	—	34.5	●
32	1 $\frac{1}{4}$	R1 $\frac{1}{4}$	80	50	8	10	34	27	—	43.5	●
40	1 $\frac{1}{2}$	R1 $\frac{1}{2}$	87	55	9	11	40.5	32.5	—	49.5	●
50	2	R2	95.5	60	10	12	52.5	44	—	61.5	●