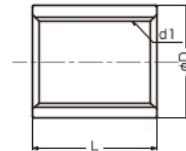


形状・寸法

■ ソケットストレート(厚口)

SJ

304 (SUS 304 TP)

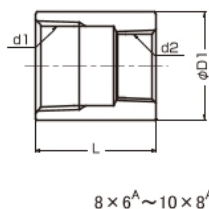
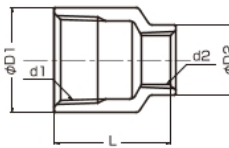


呼び径		ねじ	寸法(mm)		304 在庫
A (mm)	B (inch)	d1	D	L	
8	$\frac{1}{4}$	Rp $\frac{1}{4}$	19	27	●
10	$\frac{3}{8}$	Rp $\frac{3}{8}$	23	28	●
15	$\frac{1}{2}$	Rp $\frac{1}{2}$	28	37	●
20	$\frac{3}{4}$	Rp $\frac{3}{4}$	34.5	39	●
25	1	Rp1	41.5	46	●
32	$1\frac{1}{4}$	Rp $1\frac{1}{4}$	51	51	●
40	$1\frac{1}{2}$	Rp $1\frac{1}{2}$	58	51	●
50	2	Rp2	70	60	●

■ 径違いソケット

RS

304 (SUS 304 または SCS 13A)

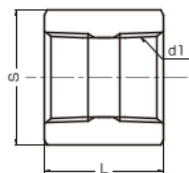
 $8 \times 6^A \sim 10 \times 8^A$  $15 \times 8^A \sim 50 \times 40^A$

呼び径		ねじ		寸法(mm)			304 在庫
A (mm)	B (inch)	d1	d2	D1	D2	L	
8 × 6	$\frac{1}{4} \times \frac{1}{8}$	Rc $\frac{1}{4}$	Rc $\frac{1}{8}$	19	—	29	●
10 × 6	$\frac{3}{8} \times \frac{1}{8}$	Rc $\frac{3}{8}$	Rc $\frac{1}{8}$	22	—	30	●
10 × 8	$\frac{3}{8} \times \frac{1}{4}$	Rc $\frac{3}{8}$	Rc $\frac{1}{4}$	22	—	30	●
15 × 8	$\frac{1}{2} \times \frac{1}{4}$	Rc $\frac{1}{2}$	Rc $\frac{1}{4}$	26	19	38	●
15 × 10	$\frac{1}{2} \times \frac{3}{8}$	Rc $\frac{1}{2}$	Rc $\frac{3}{8}$	26	21.5	38	●
20 × 10	$\frac{3}{4} \times \frac{3}{8}$	Rc $\frac{3}{4}$	Rc $\frac{3}{8}$	32	21.5	40	●
20 × 15	$\frac{3}{4} \times \frac{1}{2}$	Rc $\frac{3}{4}$	Rc $\frac{1}{2}$	32	26	40	●
25 × 15	$1 \times \frac{1}{2}$	Rc1	Rc $\frac{1}{2}$	39	26	45	●
25 × 20	$1 \times \frac{3}{4}$	Rc1	Rc $\frac{3}{4}$	39	32	45	●
32 × 20	$1\frac{1}{4} \times \frac{3}{4}$	Rc $1\frac{1}{4}$	Rc $\frac{3}{4}$	48.5	32	51	●
32 × 25	$1\frac{1}{4} \times 1$	Rc $1\frac{1}{4}$	Rc1	48.5	39	51	●
40 × 25	$1\frac{1}{2} \times 1$	Rc $1\frac{1}{2}$	Rc1	54.5	39	54	●
40 × 32	$1\frac{1}{2} \times 1\frac{1}{4}$	Rc $1\frac{1}{2}$	Rc $1\frac{1}{4}$	54.5	48.5	54	●
50 × 25	2×1	Rc2	Rc1	67	39	64	●
50 × 32	$2 \times 1\frac{1}{4}$	Rc2	Rc $1\frac{1}{4}$	67	48.5	64	●
50 × 40	$2 \times 1\frac{1}{2}$	Rc2	Rc $1\frac{1}{2}$	67	54.5	64	●

■ 六角ソケット

STS

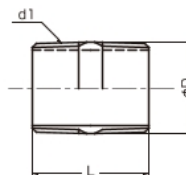
304 (SUS 304)



呼び径		ねじ	寸法 (mm)			304 在庫
A (mm)	B (inch)	d1	L	S		
				六角	八角	
8	$\frac{1}{4}$	Rc $\frac{1}{4}$	25	19	—	●
10	$\frac{3}{8}$	Rc $\frac{3}{8}$	28	23	—	●
15	$\frac{1}{2}$	Rc $\frac{1}{2}$	34	29	—	●
20	$\frac{3}{4}$	Rc $\frac{3}{4}$	38	—	34	●
25	1	Rc1	44	46	—	●

■ 両ニップル

N

304 (SUS 304 TP)
316 (SUS 316 TP)

呼び径		ねじ	寸法(mm)		304 在庫	316 在庫
A (mm)	B (inch)	d1	D	L		
6	$\frac{1}{8}$	R $\frac{1}{8}$	10.5	20	●	●
8	$\frac{1}{4}$	R $\frac{1}{4}$	13.8	26	●	●
10	$\frac{3}{8}$	R $\frac{3}{8}$	17.3	28	●	●
15	$\frac{1}{2}$	R $\frac{1}{2}$	21.7	34	●	●
20	$\frac{3}{4}$	R $\frac{3}{4}$	27.2	38	●	●
25	1	R1	34.0	43	●	●
32	$1\frac{1}{4}$	R $1\frac{1}{4}$	42.7	50	●	●
40	$1\frac{1}{2}$	R $1\frac{1}{2}$	48.6	50	●	●
50	2	R2	60.5	58	●	●
65	$2\frac{1}{2}$	R $2\frac{1}{2}$	76.3	70	●	—
80	3	R3	89.1	78	●	—
100	4	R4	114.3	90	●	—

(注) 316の寸法についてはお問い合わせ下さい。