


■ 配管用銅板製突合せ溶接式管継手

形状・寸法

■ 径違いチーズ

T(R)

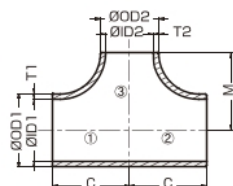

単位:mm

単位:mm

径の呼び ① × ② × ③		外径		中心から端面 までの距離	
A	B	OD 1	OD 2	C	M
20×20×15	$\frac{3}{4} \times \frac{3}{4} \times \frac{1}{2}$	27.2	21.7	28.6	28.6
25×25×20	$1 \times 1 \times \frac{3}{4}$	34.0	27.2	38.1	38.1
25×25×15	$1 \times 1 \times \frac{1}{2}$	34.0	21.7	38.1	38.1
32×32×25	$1\frac{1}{4} \times 1\frac{1}{4} \times 1$	42.7	34.0	47.6	47.6
32×32×20	$1\frac{1}{4} \times 1\frac{1}{4} \times \frac{3}{4}$	42.7	27.2	47.6	47.6
32×32×15	$1\frac{1}{4} \times 1\frac{1}{4} \times \frac{1}{2}$	42.7	21.7	47.6	47.6
40×40×32	$1\frac{1}{2} \times 1\frac{1}{2} \times 1\frac{1}{4}$	48.6	42.7	57.2	57.2
40×40×25	$1\frac{1}{2} \times 1\frac{1}{2} \times 1$	48.6	34.0	57.2	57.2
40×40×20	$1\frac{1}{2} \times 1\frac{1}{2} \times \frac{3}{4}$	48.6	27.2	57.2	57.2
40×40×15	$1\frac{1}{2} \times 1\frac{1}{2} \times \frac{1}{2}$	48.6	21.7	57.2	57.2
50×50×40	$2 \times 2 \times 1\frac{1}{2}$	60.5	48.6	63.5	60.3
50×50×32	$2 \times 2 \times 1\frac{1}{4}$	60.5	42.7	63.5	57.2
50×50×25	$2 \times 2 \times 1$	60.5	34.0	63.5	50.8
50×50×20	$2 \times 2 \times \frac{3}{4}$	60.5	27.2	63.5	44.5
50×50×15	$2 \times 2 \times \frac{1}{2}$	60.5	21.7	63.5	44.5
65×65×50	$2\frac{1}{2} \times 2\frac{1}{2} \times 2$	76.3	60.5	76.2	69.9
65×65×40	$2\frac{1}{2} \times 2\frac{1}{2} \times 1\frac{1}{2}$	76.3	48.6	76.2	66.7
65×65×32	$2\frac{1}{2} \times 2\frac{1}{2} \times 1\frac{1}{4}$	76.3	42.7	76.2	63.5
65×65×25	$2\frac{1}{2} \times 2\frac{1}{2} \times 1$	76.3	34.0	76.2	57.2
80×80×65	$3 \times 3 \times 2\frac{1}{2}$	89.1	76.3	85.7	82.6
80×80×50	$3 \times 3 \times 2$	89.1	60.5	85.7	76.2
80×80×40	$3 \times 3 \times 1\frac{1}{2}$	89.1	48.6	85.7	73.0
80×80×32	$3 \times 3 \times 1\frac{1}{4}$	89.1	42.7	85.7	69.9
80×80×25	$3 \times 3 \times 1$	89.1	34.0	85.7	65.7
100×100×80	$4 \times 4 \times 3$	114.3	89.1	104.8	98.4
100×100×65	$4 \times 4 \times 2\frac{1}{2}$	114.3	76.3	104.8	95.3
100×100×50	$4 \times 4 \times 2$	114.3	60.5	104.8	88.9
100×100×40	$4 \times 4 \times 1\frac{1}{2}$	114.3	48.6	104.8	85.7
125×125×100	$5 \times 5 \times 4$	139.8	114.3	123.8	117.5
125×125×80	$5 \times 5 \times 3$	139.8	89.1	123.8	111.1
125×125×65	$5 \times 5 \times 2\frac{1}{2}$	139.8	76.3	123.8	108.0
125×125×50	$5 \times 5 \times 2$	139.8	60.5	123.8	104.8
150×150×125	$6 \times 6 \times 5$	165.2	139.8	142.9	136.5
150×150×100	$6 \times 6 \times 4$	165.2	114.3	142.9	130.2
150×150×80	$6 \times 6 \times 3$	165.2	89.1	142.9	123.8
150×150×65	$6 \times 6 \times 2\frac{1}{2}$	165.2	76.3	142.9	120.7
150×150×50	$6 \times 6 \times 2$	165.2	60.5	142.9	115.9
200×200×150	$8 \times 8 \times 6$	216.3	165.2	177.8	168.3
200×200×125	$8 \times 8 \times 5$	216.3	139.8	177.8	161.9
200×200×100	$8 \times 8 \times 4$	216.3	114.3	177.8	155.6
250×250×200	$10 \times 10 \times 8$	267.4	216.3	215.9	203.2
250×250×150	$10 \times 10 \times 6$	267.4	165.2	215.9	193.7
250×250×125	$10 \times 10 \times 5$	267.4	139.8	215.9	190.5
250×250×100	$10 \times 10 \times 4$	267.4	114.3	215.9	184.2

備考：径の呼び 50×50×15^A、80×80×25^A及び 150×150×50^Aはイソノック標準寸法です。

径の呼び ① × ② × ③		外径		中心から端面 までの距離	
A	B	OD 1	OD 2	C	M
300×300×250	12×12×10	318.5	267.4	254.0	241.3
300×300×200	12×12×8	318.5	216.3	254.0	228.6
300×300×150	12×12×6	318.5	165.2	254.0	219.1
300×300×125	12×12×5	318.5	139.8	254.0	215.9
350×350×300	14×14×12	355.6	318.5	279.4	269.9
350×350×250	14×14×10	355.6	267.4	279.4	257.2
350×350×200	14×14×8	355.6	216.3	279.4	247.7
350×350×150	14×14×6	355.6	165.2	279.4	238.1
400×400×350	16×16×14	406.4	355.6	304.8	304.8
400×400×300	16×16×12	406.4	318.5	304.8	295.3
400×400×250	16×16×10	406.4	267.4	304.8	282.6
400×400×200	16×16×8	406.4	216.3	304.8	273.1
400×400×150	16×16×6	406.4	165.2	304.8	263.5
450×450×400	18×18×16	457.2	406.4	342.9	330.2
450×450×350	18×18×14	457.2	355.6	342.9	330.2
450×450×300	18×18×12	457.2	318.5	342.9	320.7
450×450×250	18×18×10	457.2	267.4	342.9	308.0
450×450×200	18×18×8	457.2	216.3	342.9	298.5
500×500×450	20×20×18	508.0	457.2	381.0	368.3
500×500×400	20×20×16	508.0	406.4	381.0	355.6
500×500×350	20×20×14	508.0	355.6	381.0	355.6
500×500×300	20×20×12	508.0	318.5	381.0	346.1
500×500×250	20×20×10	508.0	267.4	381.0	333.4
500×500×200	20×20×8	508.0	216.3	381.0	323.9
550×550×500	22×22×20	558.8	508.0	419.1	406.4
550×550×450	22×22×18	558.8	457.2	419.1	393.7
550×550×400	22×22×16	558.8	406.4	419.1	381.0
600×600×550	24×24×22	609.6	558.8	431.8	431.8
600×600×500	24×24×20	609.6	508.0	431.8	431.8
600×600×450	24×24×18	609.6	457.2	431.8	419.1
650×650×600	26×26×24	660.4	609.6	495.3	482.6
650×650×550	26×26×22	660.4	558.8	495.3	469.9
650×650×500	26×26×20	660.4	508.0	495.3	457.2
700×700×650	28×28×26	711.2	660.4	520.7	520.7
700×700×600	28×28×24	711.2	609.6	520.7	508.0
700×700×550	28×28×22	711.2	558.8	520.7	495.3
750×750×700	30×30×28	762.0	711.2	558.8	546.1
750×750×650	30×30×26	762.0	660.4	558.8	546.1
750×750×600	30×30×24	762.0	609.6	558.8	533.4
800×800×750	32×32×30	812.8	762.0	596.9	584.2
800×800×700	32×32×28	812.8	711.2	596.9	571.5
800×800×650	32×32×26	812.8	660.4	596.9	571.5
850×850×800	34×34×32	863.6	812.8	635.0	622.3
850×850×750	34×34×30	863.6	762.0	635.0	609.6
850×850×700	34×34×28	863.6	711.2	635.0	596.9
900×900×850	36×36×34	914.4	863.6	673.1	660.4
900×900×800	36×36×32	914.4	812.8	673.1	647.7
900×900×750	36×36×30	914.4	762.0	673.1	635.0
1000×1000×900	40×40×36	1016.0	914.4	749.3	736.6
1000×1000×850	40×40×34	1016.0	863.6	749.3	723.9