


形状・寸法

■ 同心レジューサ


R (C)

■ 偏心レジューサ


R (E)

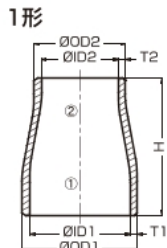


300^A(大径側)以下

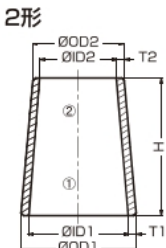

350^A(大径側)以上

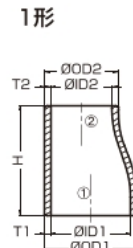

300^A(大径側)以下

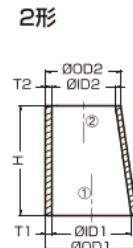

350^A(大径側)以上

単位:mm

単位:mm

単位:mm

径の呼び ① × ②		外径		端面から端面 までの距離 H
A	B	OD 1	OD 2	
20 × 15	3/4 × 1/2	27.2	21.7	38.1
25 × 20	1 × 3/4	34.0	27.2	50.8
25 × 15	1 × 1/2	34.0	21.7	50.8
32 × 25	1 1/4 × 1	42.7	34.0	50.8
32 × 20	1 1/4 × 3/4	42.7	27.2	50.8
32 × 15	1 1/4 × 1/2	42.7	21.7	50.8
40 × 32	1 1/2 × 1 1/4	48.6	42.7	63.5
40 × 25	1 1/2 × 1	48.6	34.0	63.5
40 × 20	1 1/2 × 3/4	48.6	27.2	63.5
40 × 15	1 1/2 × 1/2	48.6	21.7	63.5
50 × 40	2 × 1 1/2	60.5	48.6	76.2
50 × 32	2 × 1 1/4	60.5	42.7	76.2
50 × 25	2 × 1	60.5	34.0	76.2
50 × 20	2 × 3/4	60.5	27.2	76.2
50 × 15	2 × 1/2	60.5	21.7	76.2
65 × 50	2 1/2 × 2	76.3	60.5	88.9
65 × 40	2 1/2 × 1 1/2	76.3	48.6	88.9
65 × 32	2 1/2 × 1 1/4	76.3	42.7	88.9
65 × 25	2 1/2 × 1	76.3	34.0	88.9
80 × 65	3 × 2 1/2	89.1	76.3	88.9
80 × 50	3 × 2	89.1	60.5	88.9
80 × 40	3 × 1 1/2	89.1	48.6	88.9
80 × 32	3 × 1 1/4	89.1	42.7	88.9
80 × 25	3 × 1	89.1	34.0	88.9
100 × 80	4 × 3	114.3	89.1	101.6
100 × 65	4 × 2 1/2	114.3	76.3	101.6
100 × 50	4 × 2	114.3	60.5	101.6
100 × 40	4 × 1 1/2	114.3	48.6	101.6
125 × 100	5 × 4	139.8	114.3	127.0
125 × 80	5 × 3	139.8	89.1	127.0
125 × 65	5 × 2 1/2	139.8	76.3	127.0
125 × 50	5 × 2	139.8	60.5	127.0
150 × 125	6 × 5	165.2	139.8	139.7
150 × 100	6 × 4	165.2	114.3	139.7
150 × 80	6 × 3	165.2	89.1	139.7
150 × 65	6 × 2 1/2	165.2	76.3	139.7
150 × 50	6 × 2	165.2	60.5	139.7

径の呼び ① × ②		外径		端面から端面 までの距離 H
A	B	OD 1	OD 2	
200 × 150	8 × 6	216.3	165.2	152.4
200 × 125	8 × 5	216.3	139.8	152.4
200 × 100	8 × 4	216.3	114.3	152.4
250 × 200	10 × 8	267.4	216.3	177.8
250 × 150	10 × 6	267.4	165.2	177.8
250 × 125	10 × 5	267.4	139.8	177.8
250 × 100	10 × 4	267.4	114.3	177.8
300 × 250	12 × 10	318.5	267.4	203.2
300 × 200	12 × 8	318.5	216.3	203.2
300 × 150	12 × 6	318.5	165.2	203.2
300 × 125	12 × 5	318.5	139.8	203.2
350 × 300	14 × 12	355.6	318.5	330.2
350 × 250	14 × 10	355.6	267.4	330.2
350 × 200	14 × 8	355.6	216.3	330.2
350 × 150	14 × 6	355.6	165.2	330.2
400 × 350	16 × 14	406.4	355.6	355.6
400 × 300	16 × 12	406.4	318.5	355.6
400 × 250	16 × 10	406.4	267.4	355.6
400 × 200	16 × 8	406.4	216.3	355.6
450 × 400	18 × 16	457.2	406.4	381.0
450 × 350	18 × 14	457.2	355.6	381.0
450 × 300	18 × 12	457.2	318.5	381.0
450 × 250	18 × 10	457.2	267.4	381.0
500 × 450	20 × 18	508.0	457.2	508.0
500 × 400	20 × 16	508.0	406.4	508.0
500 × 350	20 × 14	508.0	355.6	508.0
500 × 300	20 × 12	508.0	318.5	508.0
550 × 500	22 × 20	558.8	508.0	508.0
550 × 450	22 × 18	558.8	457.2	508.0
550 × 400	22 × 16	558.8	406.4	508.0
550 × 350	22 × 14	558.8	355.6	508.0
600 × 550	24 × 22	609.6	558.8	508.0
600 × 500	24 × 20	609.6	508.0	508.0
600 × 450	24 × 18	609.6	457.2	508.0
600 × 400	24 × 16	609.6	406.4	508.0

径の呼び ① × ②		外径		端面から端面 までの距離 H
A	B	OD 1	OD 2	
650 × 600	26 × 24	660.4	609.6	609.6
650 × 550	26 × 22	660.4	558.8	609.6
650 × 500	26 × 20	660.4	508.0	609.6
650 × 450	26 × 18	660.4	457.2	609.6
700 × 650	28 × 26	711.2	660.4	609.6
700 × 600	28 × 24	711.2	609.6	609.6
700 × 550	28 × 22	711.2	558.8	609.6
700 × 500	28 × 20	711.2	508.0	609.6
750 × 700	30 × 28	762.0	711.2	609.6
750 × 650	30 × 26	762.0	660.4	609.6
750 × 600	30 × 24	762.0	609.6	609.6
750 × 550	30 × 22	762.0	558.8	609.6
750 × 500	30 × 20	762.0	508.0	609.6
800 × 750	32 × 30	812.8	762.0	609.6
800 × 700	32 × 28	812.8	711.2	609.6
800 × 650	32 × 26	812.8	660.4	609.6
800 × 600	32 × 24	812.8	609.6	609.6
850 × 800	34 × 32	863.6	812.8	609.6
850 × 750	34 × 30	863.6	762.0	609.6
850 × 700	34 × 28	863.6	711.2	609.6
850 × 650	34 × 26	863.6	660.4	609.6
900 × 850	36 × 34	914.4	863.6	609.6
900 × 800	36 × 32	914.4	812.8	609.6
900 × 750	36 × 30	914.4	762.0	609.6
900 × 700	36 × 28	914.4	711.2	609.6
1000 × 900	40 × 36	1016.0	914.4	609.6
1000 × 850	40 × 34	1016.0	863.6	609.6
1000 × 800	40 × 32	1016.0	812.8	609.6

備考：径の呼び 50 × 15^A、80 × 25^A 及び 150 × 50^A はイソック標準寸法です。